

# Stanilite®

## Platinum Spitfire® LED surface mount non-maintained



### Range

Platinum range

### Product group


Spitfire LED



### Features

- Superior photometric classification
- COB LED technology 100,000 hours plus lamp life
- Wide area coverage optics
- Low power consumption and COB LED light source for reduced operation and maintenance costs
- LiFePO4 (Lithium iron phosphate) battery combined with advanced battery charging technology for longer life
- Surface mount
- Low maintenance - ideal for factories and warehouses

Catalogue no.	Description
<b>EM products</b>	
SFB1LEDP	Platinum Spitfire D40 COB LED WA optics surface mount
SFB2LEDP	Platinum Spitfire D63 COB LED WA optics surface mount
<b>Spare parts</b>	
03-01301P	Battery pack 1LED 2wr LiFePO4 3.2V 3.2Ah
03-01303P	Battery pack 2LED 2wr LiFePO4 3.2V 4.5Ah
03-01310PB	Battery pack_V2 1LED/COB 3wr LiFePO4 3.2V 3.2Ah
03-01311PB	Battery pack_V2 2LED/COB 3wr LiFePO4 3.2V 4.5Ah

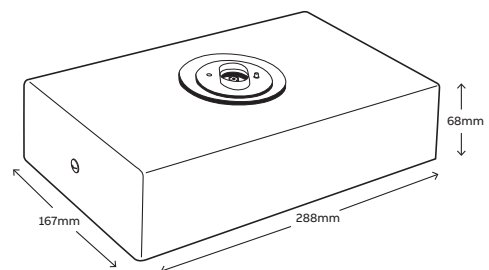

Dimensions		
Length	Width	Height
288mm	167mm	68mm
Weight		
Model	Weight	
EM	2.2kg	
Construction		
Part	Construction	
Lamp head	White polycarbonate	
Surface mount box	White powder coated steel	

<b>Light source</b>		
	<b>Model</b>	<b>Light source</b>
	D40 COB LED	2W
	D63 COB LED	3W

<b>Power consumption</b>		
	<b>Model</b>	<b>Power consumption</b>
	EM	1.0W

Note: Preliminary results

<b>Photometrics</b>			
	<b>Model</b>	<b>Class</b>	<b>Classification</b>
	D40 COB LED	C0	D40
		C90	D40
	D63 COB LED	C0	D63
		C90	D63

Note:

- Designed to comply with AS2293 and meet relevant Australian EMC standards