


Non-Metallic Systems Accessories - End Boot - Type GZ

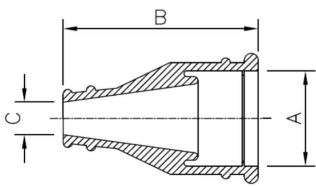

End boot, to provide a neat conduit termination and limit ingress where a conduit fitting is not required

Features

- Tapered rubber sealing system, black only
- Degree of mechanical protection is low
- Temperature range up to -30°C to +120°C
- UV protection is high

Conformity
N/A

Approvals
N/A

Fire Performance	
Test Standard	Performance Rating
Not Rated	Not Rated

Degree of Mechanical Protection
Low

IP Rating	Appropriate Fitting
For use with: see below	
IP54	As Standard

UV Protection
High

Temperature Range	
Static Application: -30°C to +120°C	
Dynamic Application: -30°C to +120°C	
Use of Ty-Rap Recommended	

For Use With - Conduit Series
Light, Standard and Heavyweight variants of type PA, PI, CP, PR, PADL & PF

Type of Material	Finish
Polychloroprene Rubber	Black Only

Testing Data
N/A

Fitting Characteristics
Tapered rubber sealing system

Part No	For Nominal Conduit Size	Dimensions mm	Cable Clamping Range Dry \varnothing	Cable Clamping Range with Grease \varnothing
	A	B	C	C
GZ09	13	28.0	4-6	4-10
GZ11	16	35.0	5-9	5-12
GZ16	21	42.0	7-14	7-15
GZ21	28	51.0	14-22	14-23
GZ29	34	53.0	16-22	16-28
GZ36	42	55.0	16-29	16-33

