



INSTALLATION INSTRUCTION

Handles


OH45-275

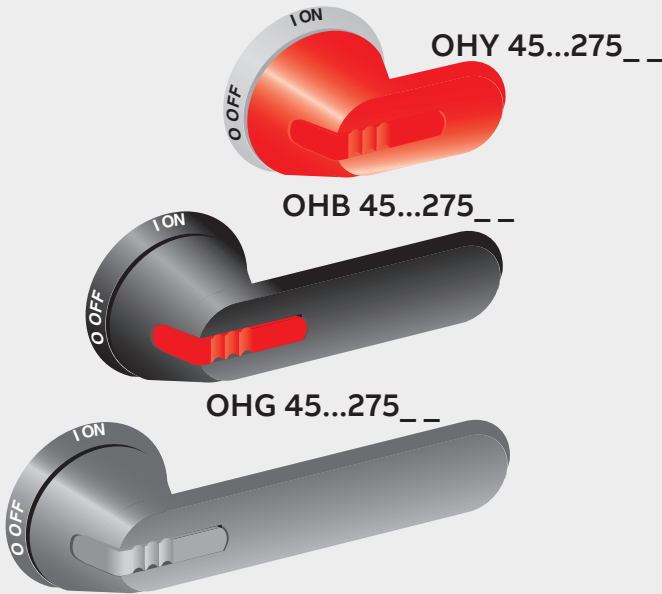



OH45-275

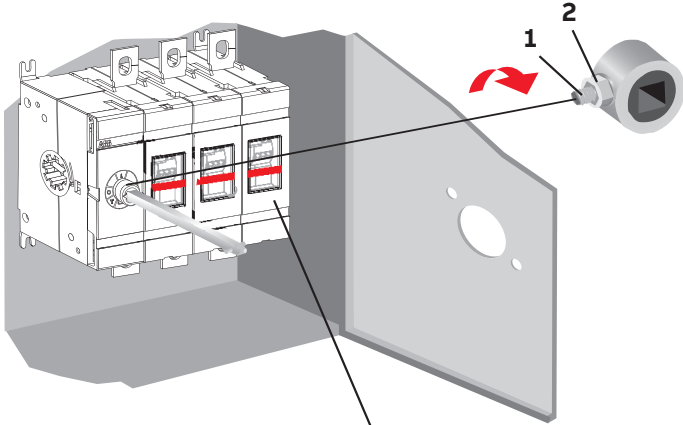

	1 Nm / lb.in	2 Nm / lb.in
OETL 200-315	1 / 8.9	1 / 8.9
OETL 400-1600	5 / 44.5	4 / 35.6
OESA 32-160	1 / 8.9	
OESA 200-800	5 / 44.5	4 / 35.6
OS 20-160	1.6-1.8 / 14-16	
OT 16-125	0.8 / 7.1	
OT 16-125 E6-8	1,6 - 1,8 / 14-16	
OT 160	1 / 8.9	

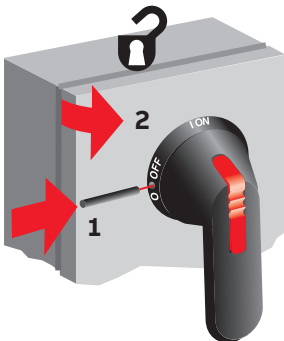


OH45-275

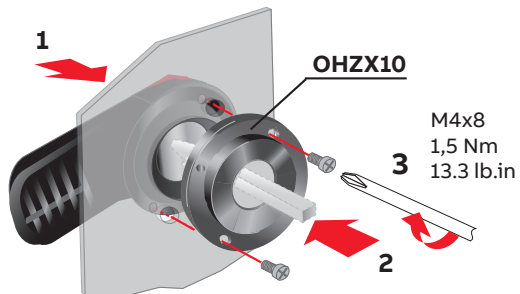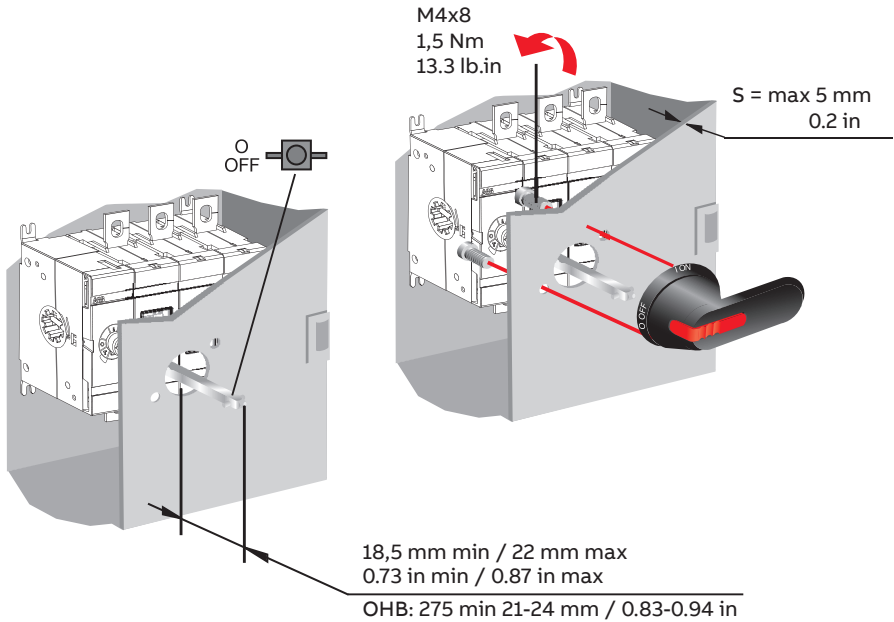




OH45-275

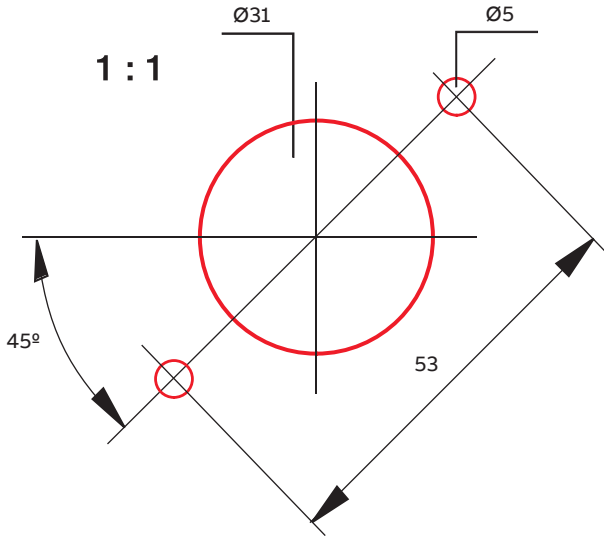

OH45-275

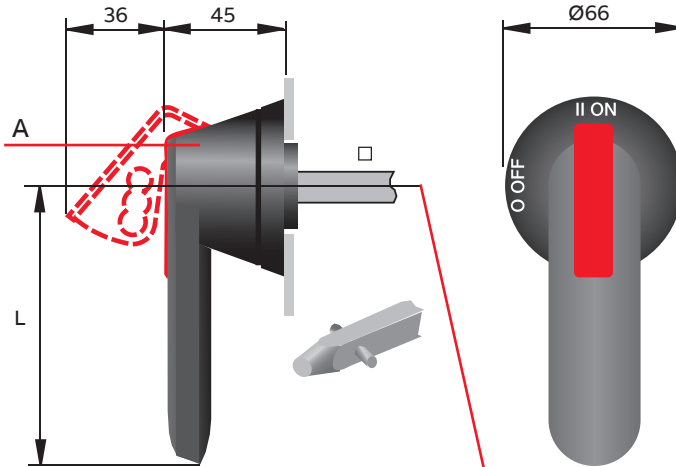

A	L	□
OHB 45J6	45	6
OHB 45J10	45	10
OHB 65J6	65	6
OHB 65J8	65	8
OHB 65J10	65	10
OHB 80J6	80	6
OHB 80J8	80	8
OHB 80J10	80	10
OHB 95J10	95	10
OHB 95J12	95	12
OHB 125J10	125	10
OHB 125J12	125	12
OHB 145J12	145	12
OHB 175J12	175	12
OHB 275J12	275	12

J = IP65, UL/NEMA Type 1, 3R, 12
 H = IP54, L = UL/NEMA Type 4, 4X

B = ■ Y = ■ G = ■



Contact us

ABB Oy
Protection and Connection
P.O. Box 622
FI-65101 Vaasa
Finland

abb.com/lowvoltage