

PANEL MARKS:

RNSB06B6040R

TECHNICAL SPECIFICATIONS

PANEL TYPE: ReliaGear neXT SuperBox
 QUANTITY: 1
 AMPS: 600A
 VOLTAGE: Up to 600V
 SYSTEM: 3P3W or 3P4W
 KAIC: Up to 200 KAIC SC FULLY RATED
 MATERIAL: COPPER BUS
 PLATE: SILVER PLATE
 ENCLOSURE: NEMA 3R
 MOUNTING: SURFACE

MAIN DISCONNECT DEVICE

FEED DIR. Bottom
 TYPE: Breaker
 AMPS: 600A
 POLES: 3

INTERIOR X-VALUES



TOTAL X BUS AVAILABLE X BUS
 16 16

OPTIONS INCLUDED

QTY	DESCRIPTION
1	Copper Bus Heat Rated
1	47 Ckt bonded grd

BOM

QTY	CAT #	DESCRIPTION
1	GDBG47AL	Ground
1	IN1606NN3H2	Bus
1	NL1210NSTNDAL	Neutral
1	ER6040R	Enclosure
1	IF1640F	Frame
1	FT40S00135	Front 1 of 2
1	FT40S00205	Front 2 of 2
1	GC40F16NNA	Gutter
3	SR03BF	Spacer
3	SR03BB	Spacer
3	SR02BF	Spacer
3	SR02BB	Spacer
1	SR01BF	Spacer
1	SR01BB	Spacer

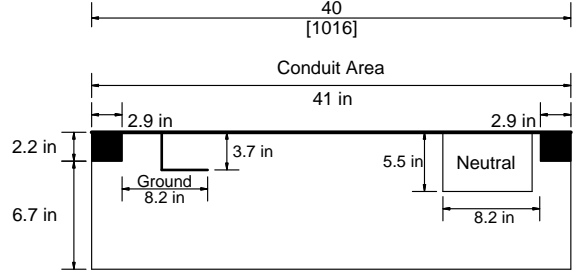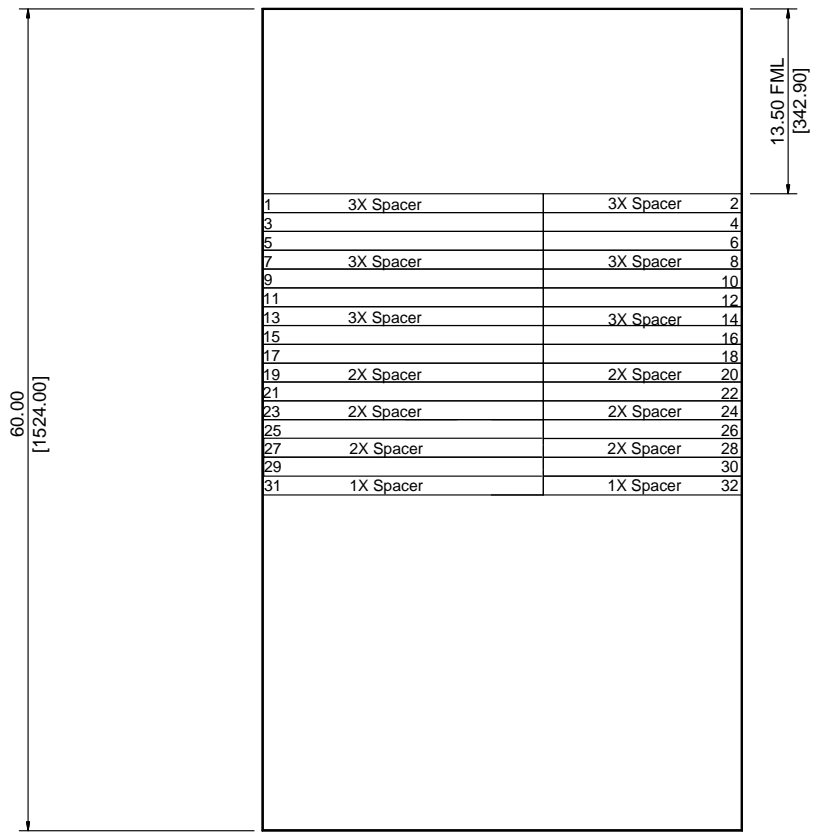

PANEL INFORMATION	
INTERNAL DIMENSIONS	60"X42"X11"
NOTES	
EXTERNAL DIMENSIONS	61"X43.5"X16.7"

1. FML - FRAME MOUNTING LOCATION.
2. DRAWING NOT TO SCALE.
3. DIMENSIONS ARE IN INCHES[mm].

NEUTRAL ARE PRESSURE LUGS.

PROJECT NAME :
 CUSTOMER:



PANEL ID:
 CREATED BY:
 DATE:
 REVISION NO.

PRODUCT NAME:
**ReliaGear neXT
 PANELBOARD**

DRAWING NO:
 ITEM NO:
 MARKS:
 QUOTE NO:
 SHEET: