

Stanilite®

Platinum batten LED weatherproof - 2 foot



Range

Platinum range

Product group

Batten LED




Features



- Typically 2,500 lumens on mains AC operation, 455 lumens in emergency operation
- Weatherproof rating IP65
- IK08 impact rating
- Ceiling, wall mount or suspension mounting (wall mount requires optional 45° mounting brackets)
- Higher wall mount classification using optional wall mount brackets
- Long LED life 75,000 hours
- Colour temperature 4,000K
- High colour rendering index CRI>80
- Mains terminal block accepts up to 2.5mm² cable
- Advanced charging technology combined with Lithium iron phosphate battery for long life and low maintenance
- External mounting clips for ease of installation
- Stainless steel diffuser clips
- High efficiency frosted polycarbonate diffuser
- AC efficacy typically 105 lumens/watt
- Ambient operating temperature; AC -20°C to +40°C and EM +10°C to +40°C

Catalogue no.	Description
EM products	
PBLWAC25L	Platinum batten LED weatherproof AC 2500 lumens
PBLWEM25LM	Platinum batten LED weatherproof EM 2500 lumens maintained
Accessories	
21-PCCSBLW	Polycarbonate clips
26-PBMD001	Wall mount bracket pair 45°
PBLWSS316-KIT	SS316 marine grade accessory kit (includes diffuser clips x 10, suspension clips x 2, mounting bracket x 2 and M4 x 8 screws x 2)
Spare parts	
03-01307P	Battery LiFePO4 6.4V 3.2Ah

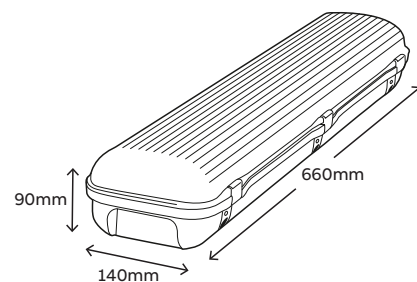

Dimensions			
	Length	Width	Bare height
	660mm	140mm	90mm
Weight			
Model	Weight		
AC	1.7kg		
EM	2.0kg		
Construction			
Part	Construction		
Reflector	Powder coated steel		
Body and diffuser	Polycarbonate		
Clips	Stainless steel		

Light source				
	Model	Light source		
	AC/EM	LED strips		

Power consumption				
	Model	Normal	S/A off	Standby
	AC	24W	0W	N/A
	EM	25W	1W	N/A

Note: Preliminary results

Photometrics			
	Model	Class	Classification
	EM ceiling mount	C0	D40
		C90	D63

Note: Preliminary results

Note:

- AC designed to comply with AS/NZS60598.2.1 and meet relevant Australian EMC standards
- EM designed to comply with AS2293.3 and meet relevant Australian EMC standards