


On-load tap-changer type UBBD, 27 tap positions, coarse/fine-switching.
 Max effective No. of turns in pos 1.
 The tap-changer is delivered set in pos 14, the preceding pos. was 13.

Lindningskopplare typ UBBD, 27 lägen, grov/fin-koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 14, föregående läge var 13.

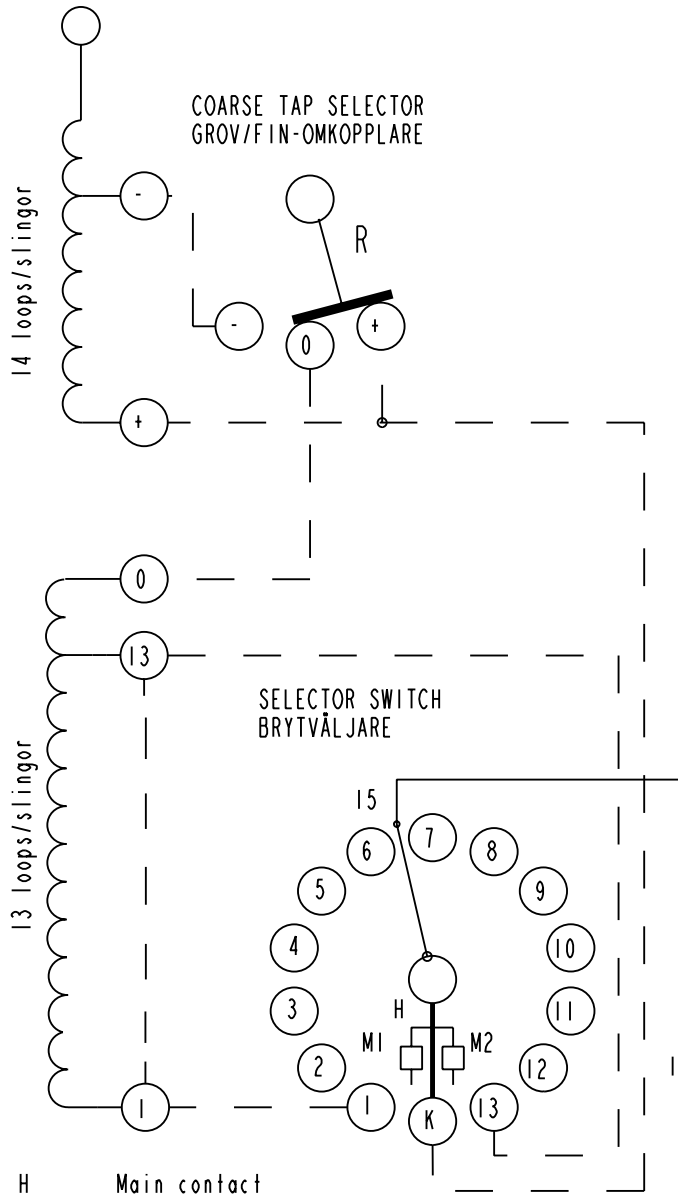

H Main contact
Huvudkontakt

M1, M2 Transition contacts
Motståndskontakter

Pos Läge	R connects förbinder	H connects förbinder
1		1 - 15
2		2 - 15
3		3 - 15
4		4 - 15
5		5 - 15
6		6 - 15
7	0+	7 - 15
8		8 - 15
9		9 - 15
10		10 - 15
11		11 - 15
12		12 - 15
13		13 - 15
14		K - 15
15		1 - 15
16		2 - 15
17		3 - 15
18	0-	4 - 15
19		5 - 15
20		6 - 15
21		7 - 15
22		8 - 15
23		9 - 15
24		10 - 15
25		11 - 15
26		12 - 15
27		13 - 15

1) OUTPUT TERMINAL
STRÖMAVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Dashed lines show in delivery not included leads belonging to cleats and leads.

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktsutförande. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19

Sheet Cont
Year Week
Dept
Form No.
Design checked by

Rev	In	Revision	Appd	Year	Week
-	-				

Accepted by qual control R. Yngvesson	Accepted for prod by	Description (English) CONNECTION DIAGRAM UBBD	DATA ORIGINAL
Design checked by B-O. Stenestam	Drawn by L. Bergman	Description (own language) KOPPLINGSSCHEMA UBBD	File name 0389-11
Drawing checked by M. Hedlund	Issued by Dept COM/TKO 97 32	5492 0389-11	Lang Sheet 1
Asea Brown Boveri			RevInd Cont -