

Stanilite®

Platinum exit LED Quickfit® vandal resistant DALI



Catalogue no.	Description
DALI products	
VPQDALEDP	Platinum exit LED Quickfit vandal resistant DALI pictograph
Spare parts	
03-01309P	Battery LiFePO4 3.2V 3.2Ah

Range

Platinum range


Product group

Exit LED



Features

- LED technology 100,000 hours plus lamp life
- Low power consumption and LED light source for reduced operation and maintenance costs
- IK09 mechanical impact resistance
- Vermin resistance
- Advanced charging technology combined with Lithium iron phosphate battery for long life and low maintenance
- DALI lighting system
- Unique internal steel slide connect bracket for quick installation and easy maintenance
- Strong steel body and end cap
- Anti-tamper cover screws
- Universal wall/ceiling mounting
- Includes all pictograph diffuser options for single or double sided installation

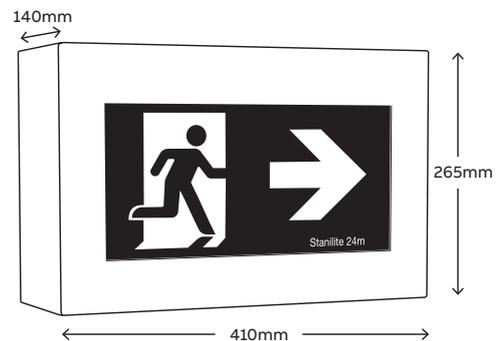

Dimensions		
Length	Width	Height
410mm	140mm	265mm
Weight		
Model	Weight	
DALI	7.8kg	
Construction		
Part	Construction	
Body and end cap	Steel body and end cap with anti-tamper cover screws White powder coated finish	
Diffuser	Extra tough UV stabilised polycarbonate	

Light source		
Model	Light source	
DALI	Multiple LED 1.6W	

Power consumption		
Model	Power consumption	
DALI	3.2W	

Note: Preliminary results

Photometrics			
Model	Class	Classification	
DALI	C0	E1.25	
	C90	E1.25	

Note: Preliminary results

Note:

- Designed to comply with AS2293 and meet relevant Australian EMC standards