

EF12D-LED Series

Thermoplastic square LED outdoor remote heads



Features


- Multi-volt 3.6, 6 or 12V, 3W in total
- Thermoplastic housing and aluminum canopy with fully adjustable LED heads
- Suitable for outdoor, wet location applications
- Wall or ceiling mount
- -4°F to 122°F (-20°C to 50°C)
- UL 924 Listed

Warranty (subject to proper installation and maintenance)


- Unit has a three-year warranty
- Detailed warranty terms located on page 178 or online at: www.emergi-lite.com/usa/files/EL_Warranty.pdf

Dimensions

Dimensions are approximate and subject to change.

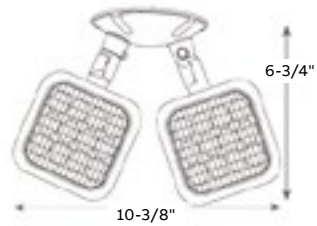


EF12D-LED Series

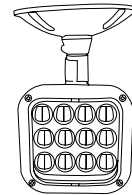

Photometric performance

Lamp	Spacing center-to-center (feet)	
	7' mounting height	15' mounting height
EF12	13'	4'

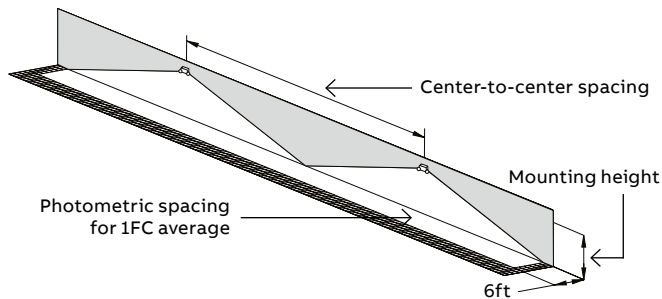

How to order

Series	# of lamp	Options	Color
EF12	Blank= Single head D= Double head	-LED= Thermoplastic square LED head	Blank= Gray Bk= Black

Example: EF12D-LED