

Local safety and selector switch kit -

NEW!

kit technics for flexible local assembly

- Small size IP54 and IP65 enclosures
- Snap on mounting of the handle and switch
- Versatile selection of handles
- Standard and special cam switches available for two different enclosure depths



**Kit technics for local assembly -
Economical mini-enclosure**

Local safety switch kit - kit technics for local assembly

Safety and cam switch enclosures



Ordering information

Enclosures for OT 16 E3 and E4 -switches and cam switches up to 4 contacts (2 blocks)

ø 20 knock outs (2+2)

	Type	Order number
enclosure IP54	OTC25M20	1SCA022745R4500
enclosure IP65	OTC26M20	1SCA022745R4680


Enclosures for cam switches ON_ up to 8 contacts (4 blocks)

ø 25 knock outs (2+2)


	Type	Order number
enclosure IP54	OTC45M25	1SCA022745R4760
enclosure IP65	OTC46M25	1SCA022745R4840

Dimension drawings

OTC25M20, OTC26M20

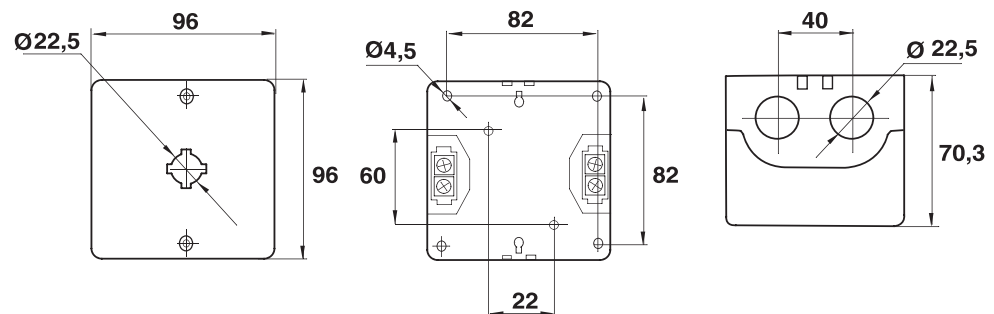

OTC45M25, OTC46M25

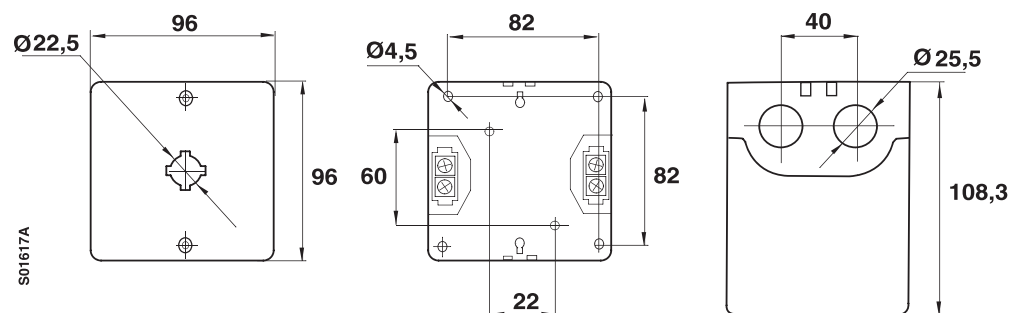

Ordering information

This is a selection of switches and accessories, more information in catalogue OT/OETL 1GB.
Suitable for enclosures OTC25M20 and OTC26M20.

Selector type handles

Indication I-O and ON-OFF, shaft (diameter 5 mm) has to be ordered separately page 22, door drilling 22.5 mm, NEMA 1.

Shaft

Diameter 5 mm
For OH1 and 3 handles, length 45 mm
For OH2 handle, length 57 mm

Interlocking ring

For replacement of red knob on OT switch

Door mounted switch-disconnectors



Suitable for enclosures OTC25M20 and OTC26M20.

Alternative handles

Other accessories for OT 16E 3/ 4 and OT 16ET3/ 4 switch-disconnectors

Base mounted switch-disconnectors

Door mounted switch-disconnectors

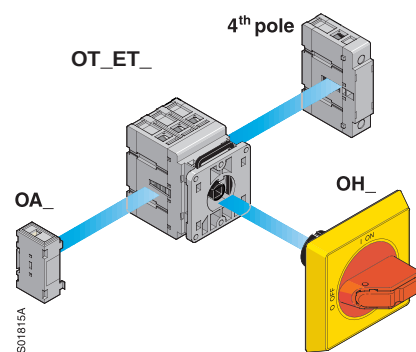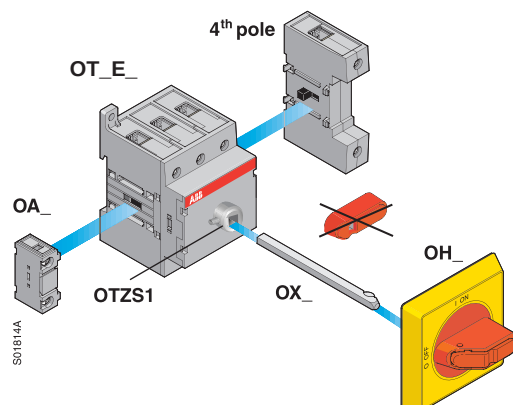

Local safety switch kit - kit technics for local assembly

Cam switches

Ordering information

ON-OFF Switches, door mounted, rotating angle 90°

These types are examples, more types in catalogue OM/ON 1 GB. Cam switches include handle. Standard and special type ON __PB with max. 4 contacts, see catalogue OM/ON 1 GB for more information.

Black handle and frontplate with standard text are included. The type and the ordering number are for one piece, package quantity is 10 pcs. Special engraved frontplates to be ordered as separate items.

Function	Number of contacts	Rated thermal current [A]	Type	Order number	Weight [kg]
----------	--------------------	---------------------------	------	--------------	-------------

O-position: 9 o'clock

Normal

Suitable for enclosures OTC25M20 and OTC26M20.

0 - 1	1	25	ONA1PB	1SCA022531R4920	0.08
	2	25	ONA2PB	1SCA022531R5060	0.09
	3	25	ONA3PB	1SCA022531R5140	0.10
	4	25	ONA4PB	1SCA022531R5220	0.11

Suitable for enclosures OTC45M25 and OTC46M25.

	5	25	ONA5PB	1SCA022531R5310	0.12
	6	25	ONA6PB	1SCA022531R5490	0.12

Key operated

Key withdrawable in OFF position.

0 - 1	1	25	ONA1KB	1SCA022531R5570	0.11
	3	25	ONA3KB	1SCA022531R5650	0.13

O-position: 12 o'clock

Normal

Suitable for enclosures OTC25M20 and OTC26M20.

0 - 1	1	25	ONA01PB	1SCA022570R7220	0.08
	2	25	ONA02PB	1SCA022570R7310	0.09
	3	25	ONA03PB	1SCA022570R7490	
	4	25	ONA04PB	1SCA022570R7570	0.11

Suitable for enclosures OTC45M25 and OTC46M25.

	5	25	ONA05PB	1SCA022570R7650	0.12
	6	25	ONA06PB	1SCA022570R7730	0.12

Key operated

Key withdrawable both positions.

0 - 1	1	25	ONA01KB	1SCA022570R8030	0.11
	3	25	ONA03KB	1SCA022570R8110	0.13

Accessories

Colour	For cam switches type	Type	Order number	Packing quantities	Weight [kg]
--------	-----------------------	------	--------------	--------------------	-------------

Handle with blanco front plate without engraving

Black	ON_, Normal	ONPB1	1SCA022553R7550	5	0.08
Grey	ON_, Normal	ONPG1	1SCA022553R7630	5	0.08

Padlockable handle

For max 2 padlocks with 6 mm bail diameter or for max 3 padlocks with 4 mm bail diameter, 90 degrees.

Black	ON_, Normal	ONZ20B	1SCA022621R1810	5	0.06
Red yellow	ON_, Normal	ONZ20RY	1SCA022621R1900	5	0.06

Additional lettering plate, without engraving, black engraving from front side

Black frame	ON_, Normal	ONFB72	1SCA022555R5020	5	0.01
Grey frame	ON_, Normal	ONFG72	1SCA022556R1930	5	0.01



Normal



Key operated



ONPB1



ONPG1



ONZ20B



ONZ20RY



ONFB72