

FLYER

## Twist Tail™ cable tie

No tool needed





- New all-plastic cable tie, with unique, patent pending design
- Quick and easy to install, no tools required
- Strong, made of Polyamide 6.6, with 133N minimum tensile strength
- Safe, tail breaks off neat and clean, with no sharp edges
- General purpose applications, indoor and outdoor
- UL recognized
- Available in 3 different lengths and 2 colors (white and UV-resistant black)

# Polyamide 6.6 Twist Tail™ cable tie

## All plastic cable tie – no tool needed

How does it work? Wrap the Twist Tail™ cable tie around the bundle of cables, bend the excess tail in two directions and twist! The tail breaks right off, leaving no sharp edges to scratch your hands or your cables. It's as simple as that.

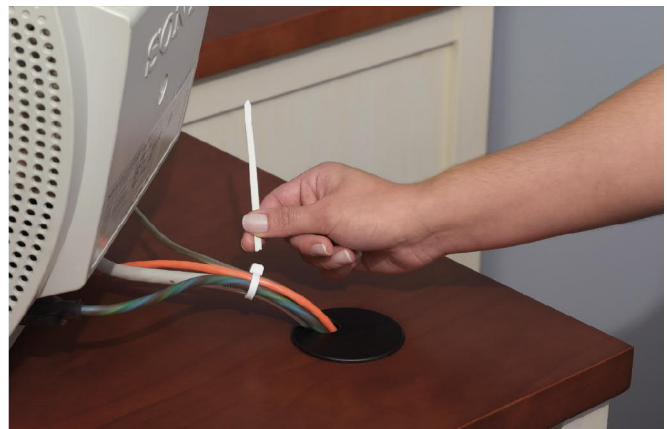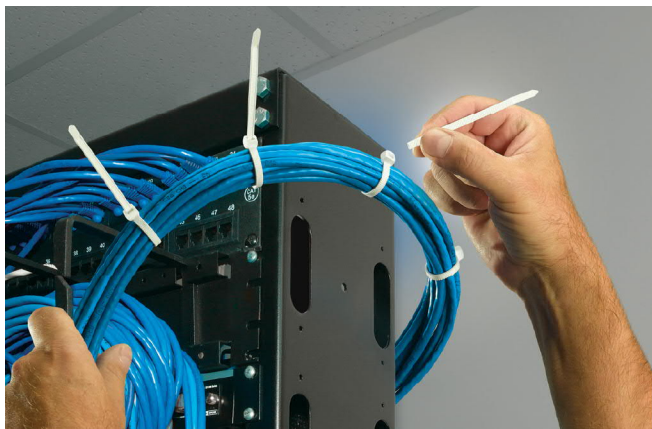

### Technical information:

- Material: Polyamide 6.6
- Temperature max.: +85°C
- Color: White or UV-resistant black
- Flammability rating: UL 94 V-2
- Other properties: Halogen free, Silicone free, UV resistant (black)

Product Ref.	GID	Color	Length [mm]	Width [mm]	Thickness [mm]	Max. bundle diameter [mm]	Quantity [pieces]
TT-7-30-9-L-EU	7TAG054780R0023	white	181	4.7	1.4	45	50
TT-7-30-0-L-EU	7TAG054780R0020	black	181	4.7	1.4	45	50
TT-11-30-9-L-EU	7TAG054780R0012	white	282	4.7	1.4	76	50
TT-11-30-0-L-EU	7TAG054780R0009	black	282	4.7	1.4	76	50