


Temp.

0 25 40 50 60C

Shift index for long-time delay only.

MULTIPLES OF CIRCUIT BREAKER CURRENT RATING

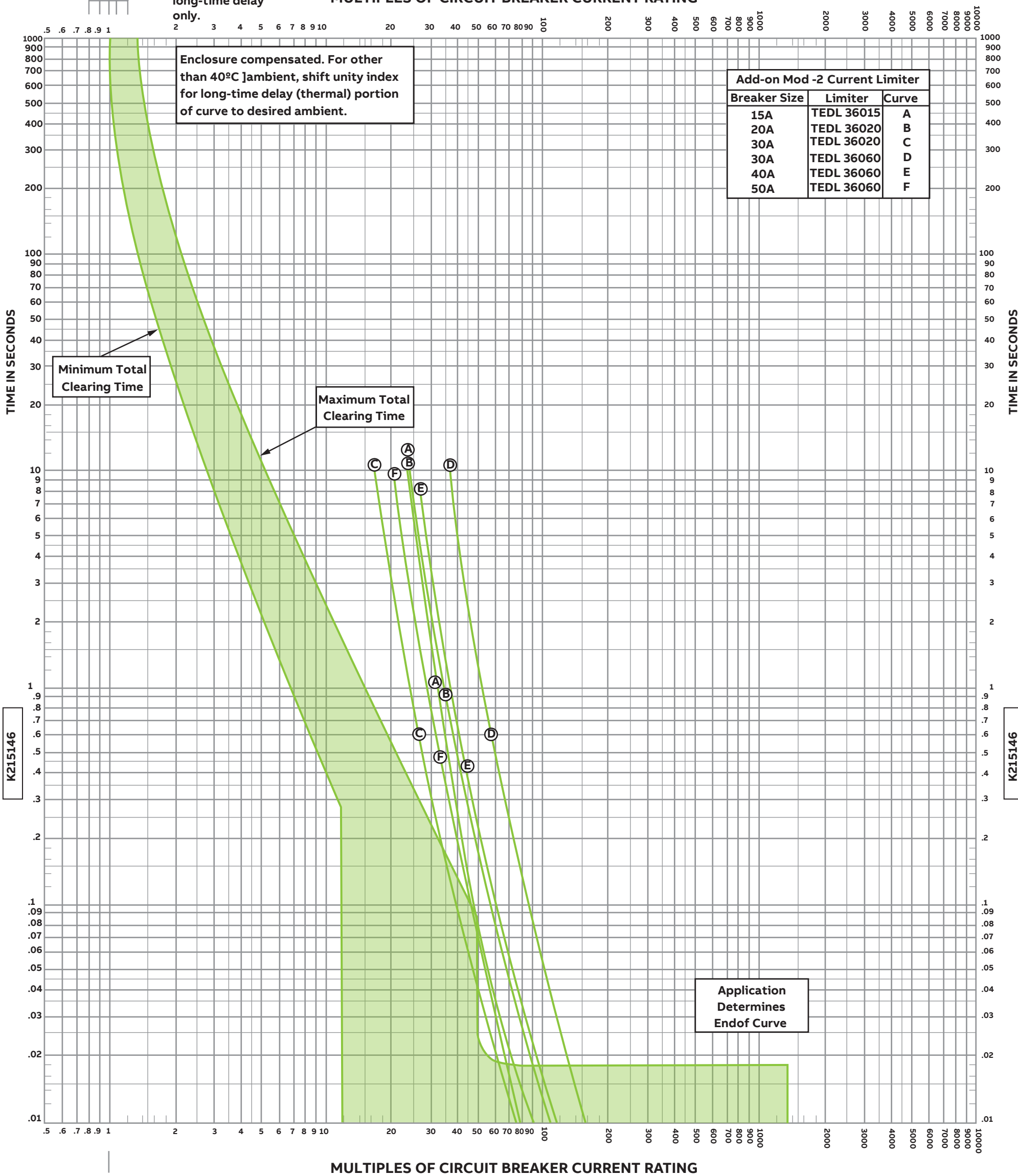

**Molded Case Circuit Breaker E 100 LINE**

**Current Ratings**

15, 20, 30, 40, and 50 Amperes

**Voltage Ratings**

2 and 3 pole – 480 Vac (250Vdc)

**Frequency Rating**

60 Hertz

Type TED, 15-50 Amperes

Enclosure Compensated

Long-time Delay and Instantaneous

Time-current Curves

Curves show enclosure-compensated circuit breaker in open air, 40°C ambient, wired with conductors of corresponding rating, no prior load. For all other ambients, use shift index at top of sheet.

**K215146**

**Adjustments**

Long-time delay thermal trip: not adjustable.

Instantaneous magnetic trip: not adjustable.

**NOTE: Limiters can only be applied to AC breakers.**

K215146

K215146