


# Aqualux

Durable & high performance




### High power open area luminaire

- Attractive aluminium modular enclosure
- Clear polycarbonate broad delivery diffuser
- Intelligent Self-test as standard
- Complies to IEC 60598.2.22

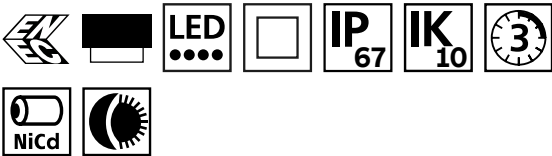

### Luminaire

Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
CTOW3L261	CT 2LED M3	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
IR2OW3L261	2LED M3 IR2	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
OW1L261HF	2XLED SIGN 230VHF	220-240 AC/DC 0-60Hz	2 x LED 1W	89	8 / 3.5	230V	0-40	1.5
OW1L261LTC	2XLED 230V LTC IP65	220-240 AC 50/60Hz	2 x LED 1W	89	8 / 3.5	230V	0-40	1.5
OW3L261	2LED M3	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
OW3L261LS	2LEDM3 LSENS IP65	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
OW3L261V2	2LED M3 220V60HZ	220-240 AC 50/60Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
DLOW3LS60	3W LED DALI M3	220-240 AC 50Hz	1 x LED 3W	79	9.9 / 5.1	3	0-25	1.7

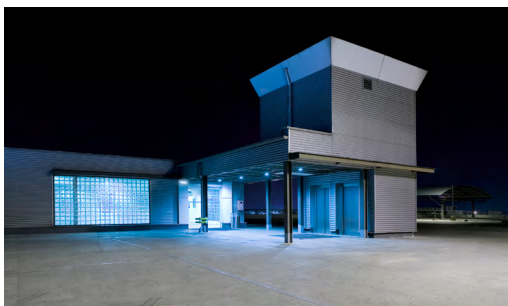

### Accessories

Order code	Description
OW/BCM	Ceiling bracket, vertical mount
OW/BWA	Wall bracket, angled mount
OW/BWM	Wall mount end cantilever bracket
OW/BCR	Recessing kit

