


On-load tap-changer type UBBR, 25 tap positions, reverser.
 Max effective No. of turns in pos 1.
 The tap-changer is delivered set in pos 13,
 the preceding pos. was 13A.

Lindningskopplare typ UBBR, 25 lägen,
 plus/minus-koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 13,
 föregående läge var 13A.

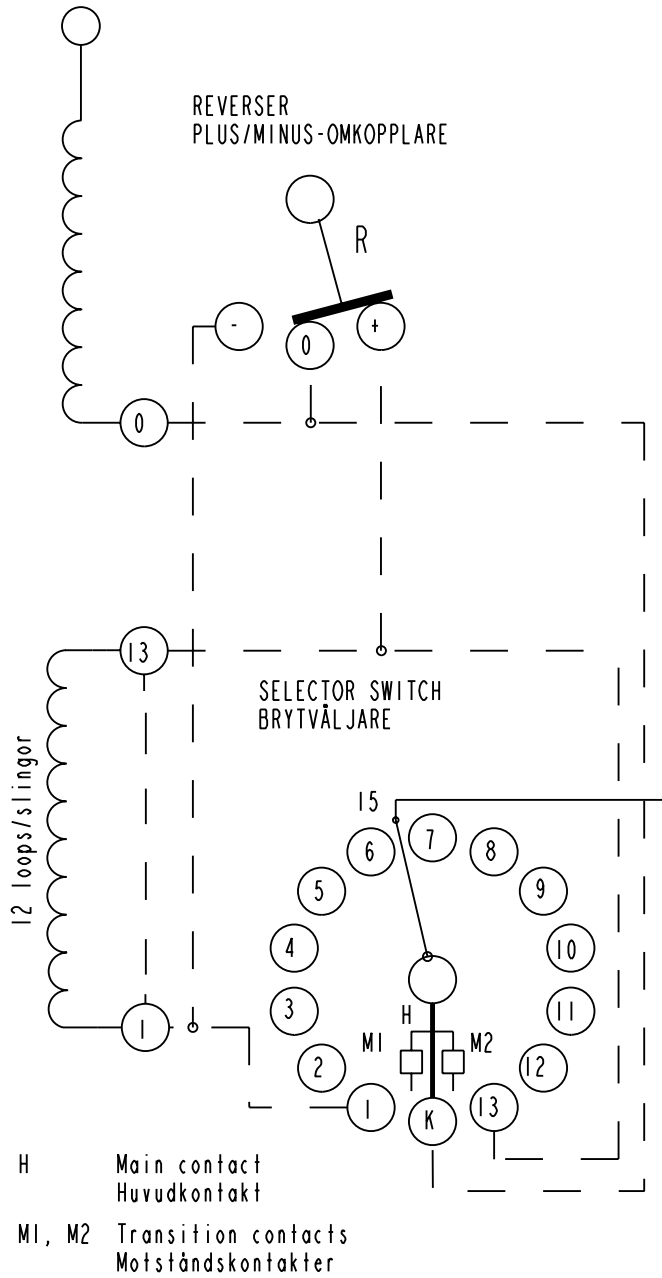

Pos Läge	R connects förbinder	H connects förbinder
1		1 - 15
2		2 - 15
3		3 - 15
4		4 - 15
5		5 - 15
6		6 - 15
7	0+	7 - 15
8		8 - 15
9		9 - 15
10		10 - 15
11		11 - 15
12		12 - 15
13A		13 - 15
13		K - 15
13B		1 - 15
14		2 - 15
15		3 - 15
16	0-	4 - 15
17		5 - 15
18		6 - 15
19		7 - 15
20		8 - 15
21		9 - 15
22		10 - 15
23		11 - 15
24		12 - 15
25		13 - 15

1) OUTPUT TERMINAL
STRÖMAVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Dashed lines show in delivery not included leads belonging to cleats and leads.

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktsutförande. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19

Sheet	Cont
Year	Week
Dept	
Rev Ind	Revision
Appd	Year
Week	
Rev Ind	Accepted for prod by
Design checked by	Design (English)
Drawn by	DESCRIPTION (own language)
Issued by	Dept
Year	Week
Lang	Sheet
Rev Ind	Cont



Asea Brown Boveri

5492 0388-10

Accepted for prod by	Description (English)	DATA ORIGINAL
Design checked by	DESCRIPTION (own language)	File name
Drawn by		0388-10
Issued by		Lang
		Sheet
		Rev Ind
		Cont