

## Literay™ Series

Wall mount remote head for damp and wet locations



### Description

- Indoor or outdoor use
- Die-cast aluminum construction
- Fully gasketed cover
- Impact- and tamper-resistant polycarbonate lens

### Mounting

- Surface wall mount
- Universal J-box mounting

### Lamp type

- Choice of MR16 LED lamp wattages

### Approval


- UL 924 listed
- NEMA-3R
- Damp and wet location listed (50°F to 104°F, 10°C to 40°C)

### Warranty

- Unit has a three-year limited warranty  
Detailed warranty terms located on page 178 or online at:  
[www.emergi-lite.com/usa/files/EL\\_Warranty.pdf](http://www.emergi-lite.com/usa/files/EL_Warranty.pdf)


### Dimensions

Dimensions are approximate and subject to change.

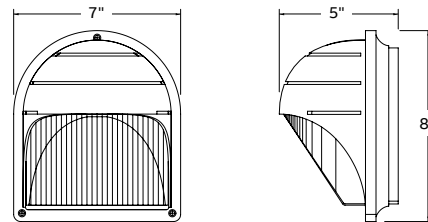

### Photometric performance

Lamp	Spacing center-to-center (feet)	7 ft. mounting height
LG frosted lens		16'
LG clear lens		28'

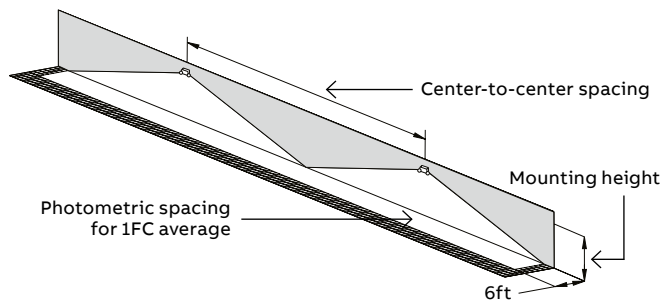

### Housing color



### How to order

Series	No. of lamps	Lamp type/ Wattage	Color	Options
LITE=	-2= 2 lamps	(LA)= 6V-4W, MR16 LED	-WT= White	Blank= No
Exterior	(standard)	(LB)= 6V-5W, MR16 LED	-BK= Black	options
remote		(LG)= 12V-4W, MR16 LED	-DG= Dark gray	-VR= Vandal- resistant screws
		(LI)= 12V-5W, MR16 LED		-N= Clear lens
		(LJ)= 12V-6W, MR16 LED		
		(LL)= 24V-4W, MR16 LED		
		(LV)=120V-4W, MR16 LED		

Example: LITE-2(LA)-WT-VR