

TECHNICAL DATA SHEET - INTERACTIVE PDF

# Plugs, knockout hole plugs

## Accessories for enclosures

### ***T&B Liquidtight Systems®***



Knockout hole plugs provide a water, dust and oil tight seal for unused knockouts.

#### Certifications / Standards:



#### 3-Part Specification:

#### End User Tools

#### Features:

- No tools are required to install. Push the plug into the knockout hole, and it will snap in.
- Not necessary to replace NEMA 1, 4, 4X, 12 or 13 boxes when a knockout is no longer used.
- Available in ½" to 4" trade sizes.

#### Applications:

- Provides a water, dust and oil tight seal for unused NPT knockout hole sizes.
- Not suitable for use with Metric or PG hole sizes.
- Efficient and effective installation process.

#### Material / Finishes:

- Neoprene, flame retardant

#### Working Temperature:

- Range: -30 to +105°C (-22 to +221°F)

#### Conforms to:

- UL514B, Conduit, Tubing and Cable Fittings:
  - File: E13938
- UL 50E & CSA22.2 No. 94.2-15, Enclosures for Electrical Equipment, Environmental Considerations:
  - File: E506371
- UL 508A, Industrial Control Panels:
  - File: E506371

#### UL & NEMA System Ingress Ratings:


- UL Listed type ratings tested to UL 50E requirements
- UL File No: E13938
  - Type 1, 4, 4X, 12, 13
- NEMA
  - Type 1, 4, 4X, 12, 13

#### IEC System Ingress Ratings:

- IEC Ingress Ratings:
  - IP66, IP67

**NPT knockout hole plug sizes:**

Product selection		
Part nos.	Hole size (inch)	A (inch)
5710	½	1 <sup>9</sup> / <sub>32</sub>
5711-TB	¾	1½
5712	1	1 <sup>27</sup> / <sub>32</sub>
5713	1¼	2 <sup>7</sup> / <sub>32</sub>
5714-TB	1½	2½
5715	2	3 <sup>3</sup> / <sub>32</sub>
5716	2½	3 <sup>21</sup> / <sub>32</sub>
5717-TB	3	4 <sup>19</sup> / <sub>64</sub>
5718	4	5 <sup>19</sup> / <sub>64</sub>

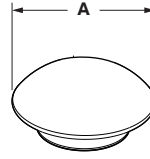

Note: Product must be installed in accordance with applicable national and local electrical codes.