

Product presentation
Switch mode power supply
CP-D 24/2.5

Updated 2008-11-01



EPR = Electronic Products and Relays



The ABB logo, consisting of the letters 'ABB' in a bold, red, sans-serif font.

CP-D 24/2.5


CP-D range power supply CP-D 24/2.5



- Output voltage 24 V DC, output current 2.5 A
- Output power 60 W
- Adjustable output voltage 24-28 V
- 2 LEDs ,LOW' – red, ,ON' – green
- Single phase input
Rated: 110-240VAC,
Range: 90-265VAC, 120-370VDC
- Ambient temperature range -10 ... +70°C
- Full output load up to +60°C
- De-rating from 60...70°C of 2.5% / °C
- Width of 71 mm

Power supplies CP-D range

Output curve (output power over ambient temperature)

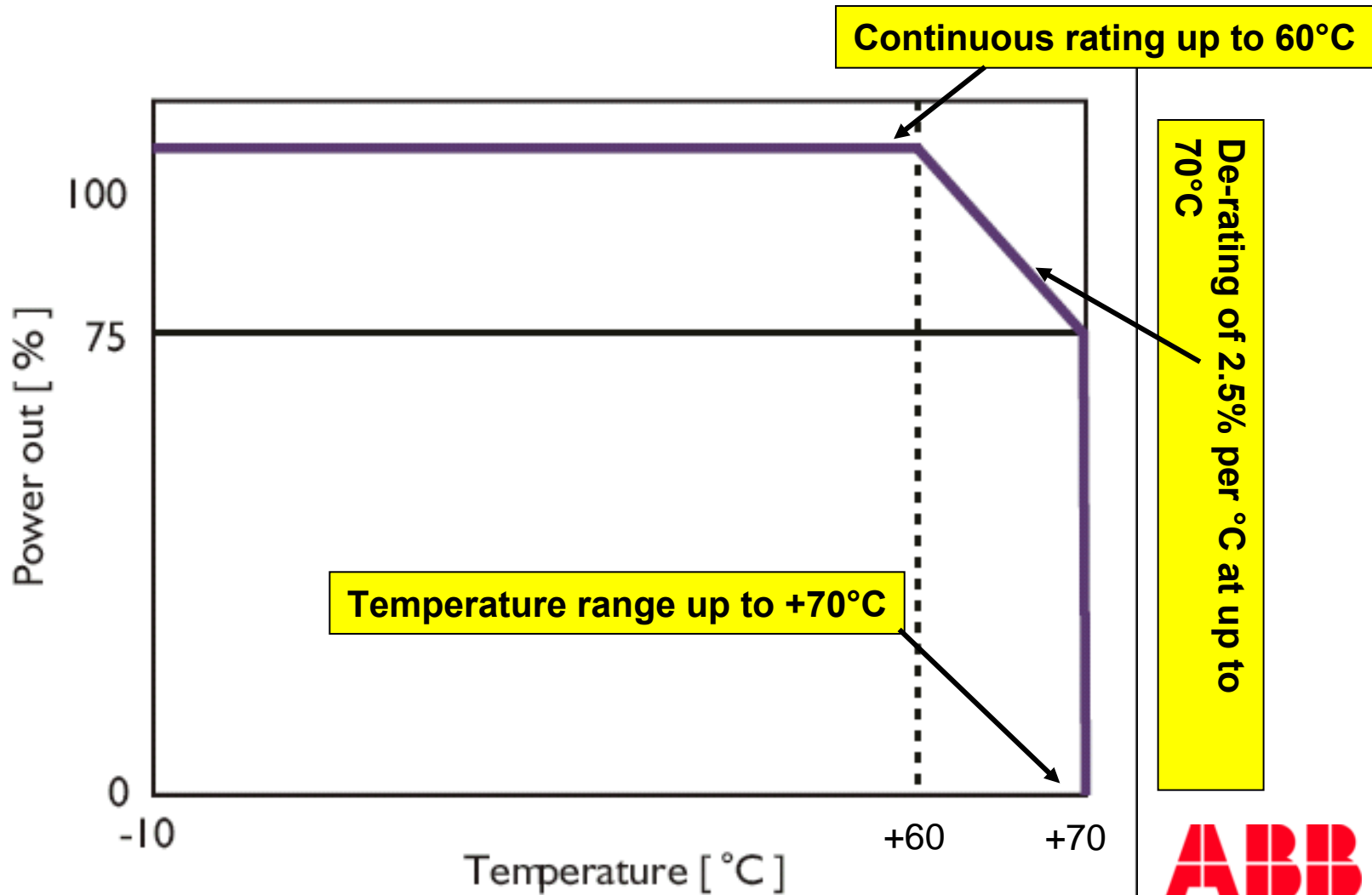

The background of the slide is an aerial photograph of a coastline, showing a mix of green land and blue water. A bright sun flare is visible in the upper left quadrant, creating a lens flare effect across the sky. The ABB logo is prominently displayed in the upper center.

ABB

Power and productivity
for a better world™