


TECHNICAL DATA SHEET - INTERACTIVE PDF

Locknuts, non-metallic

Series 140P NPSL

T&B Liquidtight Systems®

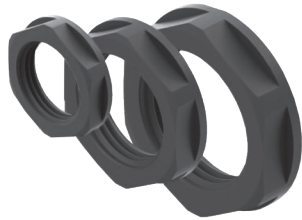

Non-Metallic Locknuts to be used with non-metallic fittings and cord connectors.

3-Part Specification:
Tools and Calculators

Features:

- Available in trade sizes $\frac{3}{8}$ to 2"
- NPSL threads for use on NPT threaded fittings
- Ideal for corrosive environments

Applications:

- Industrial applications
- Effectively secure fitting to box or enclosure

Materials / Finishes:

- Polyamide 6, 30% Glass Fiber Fill
- Color: Black

Environment ratings:

Working Temperature:

- Continuous: -20°C to +100°C (-4°F to + 212°F)
- Intermittent: -30°C to + 150°C (-22°F to +302°F)

Chemical Resistance Guide:

- See Publication [TDS000081](#)
(Fittings: Steel, Iron & PA66 Polymide)

Table 1

Product selection and approximate dimensions - Inches			
Part no.	Trade size	A	B
140P	$\frac{3}{8}$	0.98	0.28
141P	$\frac{1}{2}$	1.20	0.28
142P	$\frac{3}{4}$	1.48	0.28
143P	1	1.82	0.28
Available soon	1 $\frac{1}{4}$	—	—
Available soon	1 $\frac{1}{2}$	—	—
Available soon	2	—	—

Note: Product must be installed in accordance with applicable national and local electrical codes.

