


On-load tap-changer type UBBD, 23 tap positions, coarse/fine-switching.
 Max effective No. of turns in pos 1.
 The tap-changer is delivered set in pos 12, the preceding pos. was 11.

Lindningskopplare typ UBBD, 23 lägen, grov/fin-koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 12, föregående läge var 11.

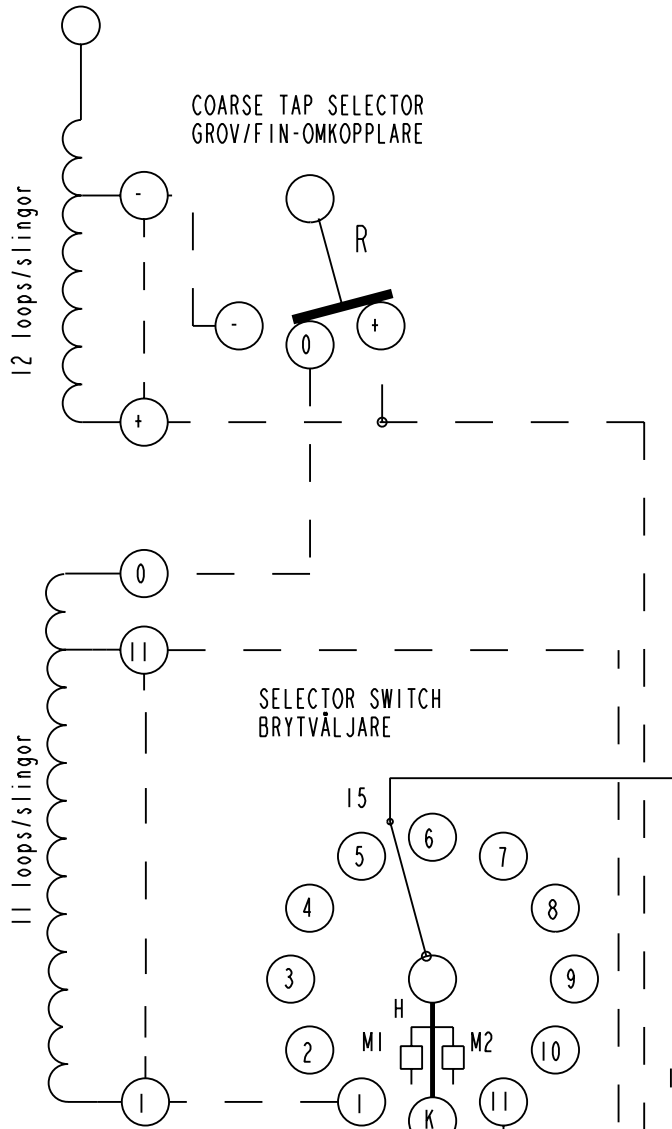

H Main contact
Huvudkontakt
 M1, M2 Transition contacts
Motståndskontakter

Pos Läge	R connects förbinder	H connects förbinder
1		1 - 15
2		2 - 15
3		3 - 15
4		4 - 15
5		5 - 15
6		6 - 15
7	0+	7 - 15
8		8 - 15
9		9 - 15
10		10 - 15
11		11 - 15
12		K - 15
13		1 - 15
14		2 - 15
15		3 - 15
16		4 - 15
17		5 - 15
18	0-	6 - 15
19		7 - 15
20		8 - 15
21		9 - 15
22		10 - 15
23		11 - 15

1) OUTPUT TERMINAL
STRÖMÄVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Dashed lines show in delivery not included leads belonging to cleats and leads.

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktutförande. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19

Sheet Cont
 Year Week
 Dept
 Rev Ind
 Design checked by
 Form No.

Rev Ind	Revision	Appd	Year	Week
-	-	-	-	-

Accepted by qual control R. Yngvesson	Accepted for prod by	Description (English) CONNECTION DIAGRAM UBBD	DATA ORIGINAL
Design checked by B-O. Stenestam	Drawn by L. Bergman	Description (own language) KOPPLINGSSCHEMA UBBD	File name 0389-9
Design checked by M. Hedlund	Issued by Dept COM/TKO 97 32	Lang	Sheet 1
Asea Brown Boveri		Rev Ind	Cont -

5492 0389-9