
PRODUCT SHEET

Superstrut[®] half-slot channel for 5/8" rod




Superstrut® half-slot channel for 5/8" rod

Perfect for heavy-duty applications.



For installers who've been drilling holes in solid strut to accommodate 5/8" threaded rod, new Superstrut half-slot channel for 5/8" rod offers a time-saving alternative. Available in 10- and 20-foot lengths with GoldGalv®, SilverGalv® or pre-galvanized finishes, the channel features half-slot holes that are 5/8" wide to accept all sizes of threaded rod up to 5/8" diameter.

- Available in two lengths and three finishes
- Channels are 1 5/8" x 1 5/8" (41.28 x 41.28 mm)
- Half-slot holes are 1 1/8" wide x 1 1/8" long (15.88 x 28.58 mm) with 2" (50.8 mm) center-to-center spacing

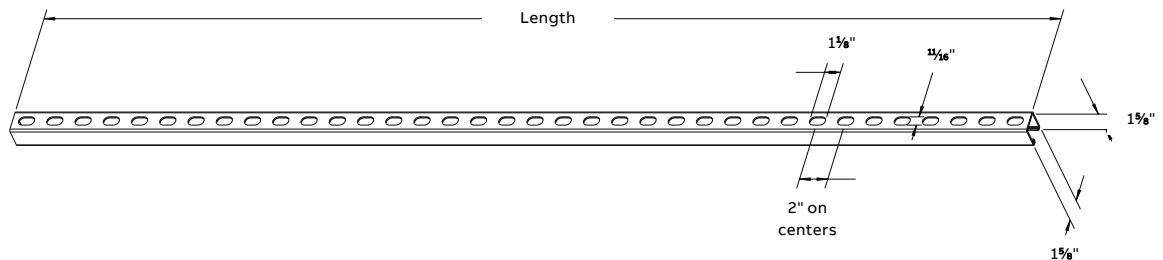

Superstrut half-slot channel for 5/8" rod — 12-gauge steel

Catalog no.	Finish	Length		Std. ctn. qty.	UPC no.
		ft.	m		
A1200WHS 10	GoldGalv	10	3.05	500	616013-13661
A1200WHS 10EG	SilverGalv	10	3.05	500	616013-13663
A1200WHS 10PG	Pre-galvanized	10	3.05	500	616013-13665
A1200WHS 20	GoldGalv	20	6.1	500	616013-13662
A1200WHS 20EG	SilverGalv	20	6.1	500	616013-13664
A1200WHS20PG	Pre-galvanized	20	6.1	500	616013-13666