


Serenga

In harmony with the interior



LED escape route illumination, plastic frame, aluminium trim Normal legend face

- 2 surface mount orientations
- 4 LED (2-downlighters) exit sign or 2 LED exit sign
- First-Fix with optional mounting accessories
- High output down-lighters for points of emphasis
- Complies to BS EN 60598.2.22

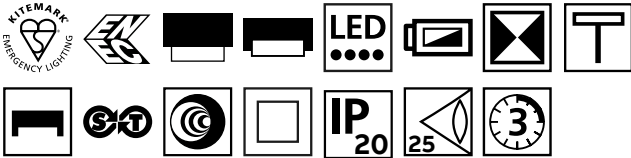

Control assembly

Order code	Description	Input voltage	Operation / Environment duration (hrs) temp. (°C)	Weight (kg)
SER-M3-003	Control module & battery pack	220 - 240 AC 50Hz	3 5-25	0.8
CTSER-M3-003	Control module & battery pack, CT version	220 - 240 AC 50Hz	3 5-25	0.9
CTSER-M3V2-003	Control module & battery pack, CT version	220 - 240 AC 60Hz	3 5-25	0.9
IR2SER-M3-003	Control module & battery pack, IR2 version	220-240 AC 50 Hz	3 5-25	0.9
SER-M3V2-003	Control module & battery pack	220 - 240 AC 60Hz	3 5-25	0.8
SER-230-003	Control module mains	85 - 240 AC/DC 50/60Hz	230V 0-40	0.8
SER-230LTC-003	Control module, LTC version	85 - 240 AC 50/60Hz	230V 0-40	0.8

Smart-Frame

Order code	Description	Lamp type	Power consumption self contained (VA/W)	Power consumption slave (VA/W)	Weight (kg)
SER-FE2D	Smart frame 2 LED - normal face	2 x LED 1W	17.5 / 8.6	8.0 / 3.5	0.9
SER-FE4D	Smart frame 4 LED - normal face	4 x LED 1W			
SER-FE2DS	Smart frame 2 LED - normal face/ flag format	2 x LED 1W (side wired)			
SER-FE4DS	Smart frame 4 LED - normal face/ flag format	4 x LED 1W (side wired)			

ISO 7010 pictogram legends are shown. Euro format & Special legends are available to order see pages 138-141.

Legends

Part No.	Pictogram
ISO 7010 legend format	
SER-SNN10	
SER-SNN11	
SER-SNN12	
SER-SNN13	
Arabic legend format	
SER-SNB01	
Safety signs	
SER-SN802	
SER-SN803	

Accessories

Order code	Pictogram
SER-BZKIT	
SER-RKIT150	
SER-RKIT300	
SER-RKIT500	
SER-RKIT1000	

