



产品认证证书

证书编号: CQC2003010305054693

申请人名称及地址

ABB 新会低压开关有限公司
广东省江门市新会区今古洲工业开发区

制造商名称及地址

ABB 新会低压开关有限公司
广东省江门市新会区今古洲工业开发区

生产企业名称及地址

ABB 新会低压开关有限公司 (V005372)
广东省江门市新会区今古洲工业开发区

产品名称和系列、规格、型号

指示装置

TYPE C(CP、C2SS、C3SS、CL、CE、CB、CEP): 详见参数附件

产品标准和技术要求

GB/T14048.5-2017

认证模式

型式试验+获证后监督

上述产品符合 CQC11-462142-2019 认证规则的要求, 特发此证。

发证日期: 2020 年 08 月 14 日 有效期至: 2024 年 11 月 14 日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

经中国合格评定国家认可委员会认可 CNAS C001-P

主任: _____

陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>

C 0346438



PRODUCT CERTIFICATE

CERTIFICATE NO.: CQC2003010305054693

NAME AND ADDRESS OF THE APPLICANT

ABB Xinhui Low Voltage Switchgear Co.,Ltd.
Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China

NAME AND ADDRESS OF THE MANUFACTURER

ABB Xinhui Low Voltage Switchgear Co.,Ltd.
Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China

NAME AND ADDRESS OF THE FACTORY

ABB Xinhui Low Voltage Switchgear Co.,Ltd. (V005372)
Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China

PRODUCT NAME, MODEL AND SPECIFICATION

Pilot devices

TYPE C(CP、C2SS、C3SS、CL、CE、CB、CEP); See the Appendix

THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T14048.5-2017

TYPE OF CERTIFICATION SCHEMES

Type testing+Follow up factory inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC11-462142-2019 .

Valid from: Aug.14,2020

Valid until: Nov.14,2024

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

Accredited by China National Accreditation Service for Conformity Assessment CNAS C001-P

President: _____

Lu Mei



CHINA QUALITY CERTIFICATION CENTRE

Section 9, No.188, Nansihuan Xilu, Beijing 100070 P.R.China

<http://www.cqc.com.cn>

C 0346438



产品认证证书

第 1 页 共 9 页

附 录

证书编号: CQC2003010305054693

纸 号: 346438

TYPE C(CP, C2SS, C3SS, CL, CE, CB, CEP);

Ui:300V (按钮、选择开关和急停开关, 蜂鸣器和带灯按钮), 415V (指示灯);

Uimp:6kV (按钮、选择开关和急停开关和带灯按钮), 4kV (蜂鸣器);

Ith:5A(按钮、选择开关、急停按钮和带灯按钮);

按钮、选择开关、急停按钮、带灯按钮、塑料按钮盒(套装);

AC-15: 120V/3A, 240V/2A (触头 Ag), 120V/1.5A, 240V/1A (触头 Cu/Ep, Ag);

DC-13: 24V/0.3A, 125V/0.2A;

LED 指示灯: Ue=110-130VAC, 230VAC, Ie=15mA;

Ue=48VAC/DC, Ie=12mA; Ue=110-130VDC, Ie=7mA;

Ue=220VDC, Ie=5mA; Ue=380VAC, Ie=16mA;

Ue=60VAC/DC, 415VAC, Ie=17mA;

LED II 指示灯: Ue=48-60VAC/DC, Ie=13-17mA;

Ue=110-130VAC, Ie=15-17mA;

Ue=110-130VDC, Ie=8-9mA; Ue=230VAC, Ie=17mA;

Ue=220VDC, Ie=6mA; Ie=2mA (CL2-720),

Ue=380-415VAC, Ie= 15-17mA;

白织灯指示灯: Uemax=240VAC;

蜂鸣器(红,黄色带灯):

Ue=110-130VAC, 230VAC, Ie=70mA; Ue=110-130VDC, Ie=15mA;

(绿色带灯): Ue=110-130VAC, 230VAC, Ie=55mA; Ue=110-130VDC, Ie=15mA;

外壳防护等级: 安装在特定面板后头部外壳防护等级可达到 IP66, LED II 指示灯尾部端面可达到 IP20, 基于标准产品的特殊印刷 LED 指示灯 CL9 安装在特定面板后头部外壳防护等级可达到 IP66 和尾部端面可达到 IP20, 没有安装平整圈的 LED 指示灯 CL9 安装在特定面板后头部外壳防护等级可达到 IP40 和尾部端面可达到 IP20. 塑料按钮盒(套装) CEP 没有安装保护罩或标牌时外壳防护等级可达到 IP66, 安装保护罩或标牌时外壳防护等级为 IP40;

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>



产品认证证书

附 录

第 2 页 共 9 页

证书编号：CQC2003010305054693

纸 号：346438

型号的解釋：

注：此附录与证书同时使用时有效。

主任： 陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>



产品认证证书


附录

第 3 页 共 9 页

证书编号: CQC2003010305054693

纸号: 346438

1 按钮

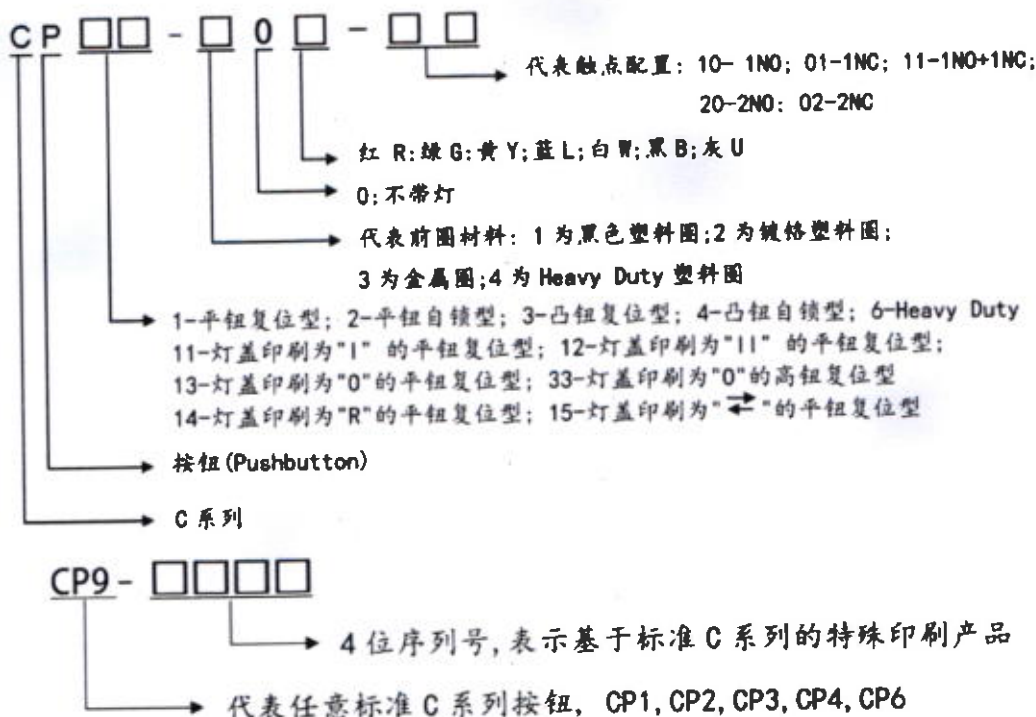

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>



产品认证证书


附录

第 4 页 共 9 页


证书编号: CQC2003010305054693

纸号: 346438

带灯按钮

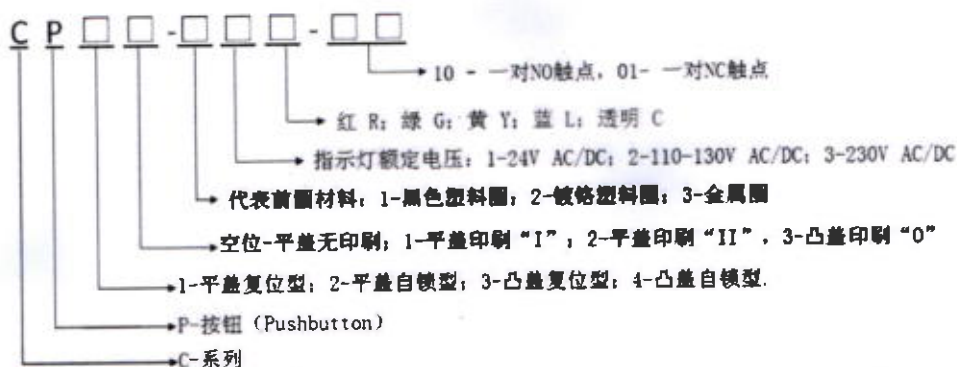

2 位选择开关

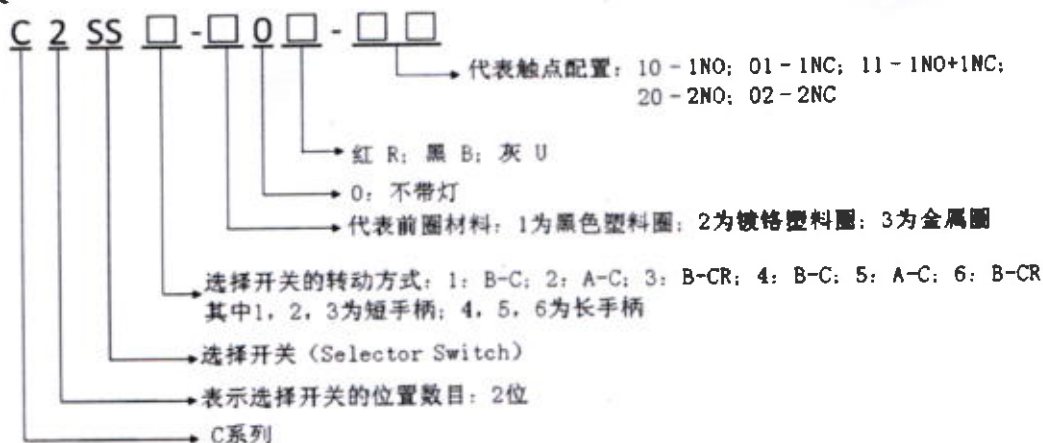

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路188号9区100070

<http://www.cqc.com.cn>



产品认证证书

附录

第 5 页 共 9 页

证书编号: CQC2003010305054693

纸号: 346438

C2SS9-□□□□

- 4 位序列号, 表示基于标准 C 系列的特殊印刷产品
- 代表任意标准 C 系列 2 位选择开关: C2SS1, C2SS2, C2SS3, C2SS7, C2SS4, C2SS5, C2SS6, C2SS8

3 位选择开关

C 3 SS □ - □ 0 □ - □ □

- 代表触点配置: 10 - 1NO; 01 - 1NC; 11 - 1NO+1NC; 20 - 2NO; 02 - 2NC
- 红 R; 黑 B; 灰 U
- 0: 不带灯
- 代表前面材料: 1为黑色塑料圈; 2为镀铬塑料圈; 3为金属圈
- 选择开关的转动方式: 1: A-B-C; 2: AR-B-CR; 3: A-B-CR; 4: A-B-C; 5: AR-B-CR; 6: A-B-CR; 7: AR-B-C; 8: AR-B-C
- 其中 1, 2, 3, 7 为短手柄; 4, 5, 6, 8 为长手柄
- 选择开关 (Selector Switch)
- 表示选择开关的位置数目: 3 位
- C 系列

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>



产品认证证书

附录

第 6 页 共 9 页

证书编号: CQC2003010305054693

纸号: 346438

4 指示灯

C L □ - □ □ □ □

红:R; 绿:G; 黄:Y; 白:W; 透明:C

00: 白炽灯指示灯, 最大电压等级 240VAC;

04: LED 指示灯, 48VAC/DC;

05: LED 指示灯, 60VAC/DC

07: LED II 指示灯, 48-60VAC/DC

13: LED/LED II 指示灯, 110-130VAC;

15: LED/LED II 指示灯, 110-130VDC

20: LED/LED II 指示灯, 220VDC;

23: LED/LED II 指示灯, 230VAC

30: LED 指示灯, 380VAC;

41: LED 指示灯, 415VAC

42: LED/LED II 指示灯, 380-415VAC;

-1: 白炽灯指示灯; -5: LED 指示灯; 2-5: LED II 指示灯;

2-6: LED II 指示灯 (具有较高抗感应电压的客户化产品)

2-7: LED II 指示灯 (220VDC/2mA 的客户化产品)

指示灯 (Light)

C 系列

CL9- □ □ □ □

4 位序列号, 表示基于标准 C 系列的特殊产品

代表任意标准 C 系列指示灯

注: 此附录与证书同时使用时有效。

主任: _____

陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>



产品认证证书



附录

第 7 页 共 9 页

证书编号: CQC2003010305054693

纸号: 346438

5 急停开关

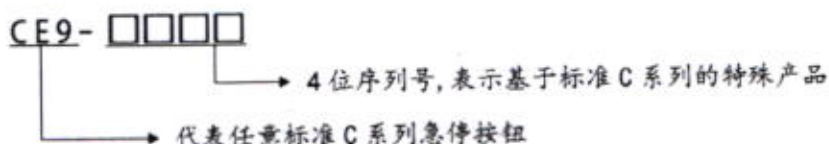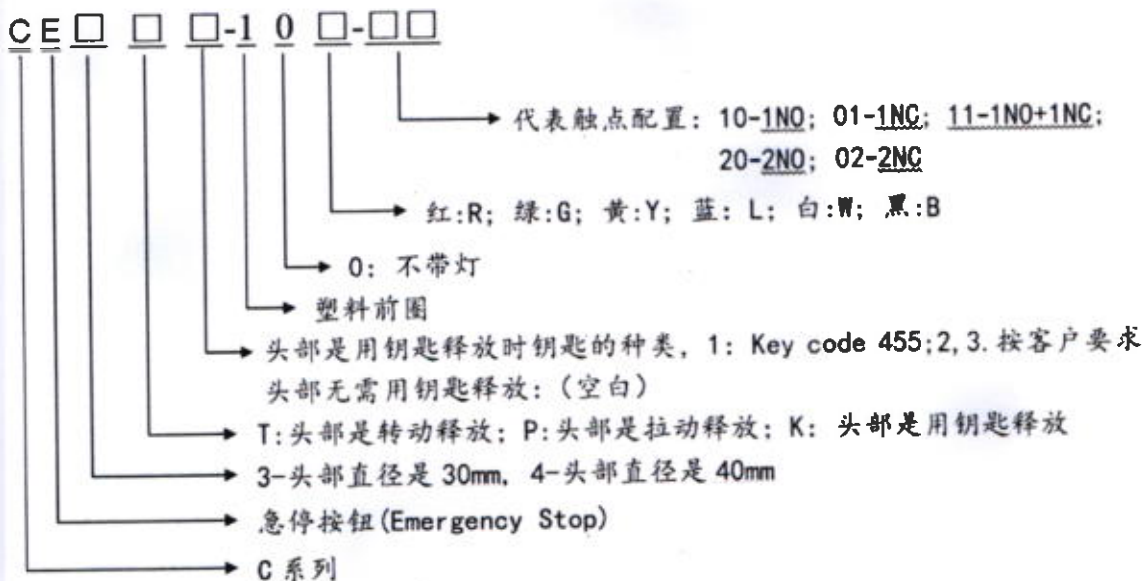

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>



产品认证证书


附录

第 8 页 共 9 页

证书编号: CQC2003010305054693

纸号: 346438

6 蜂鸣器

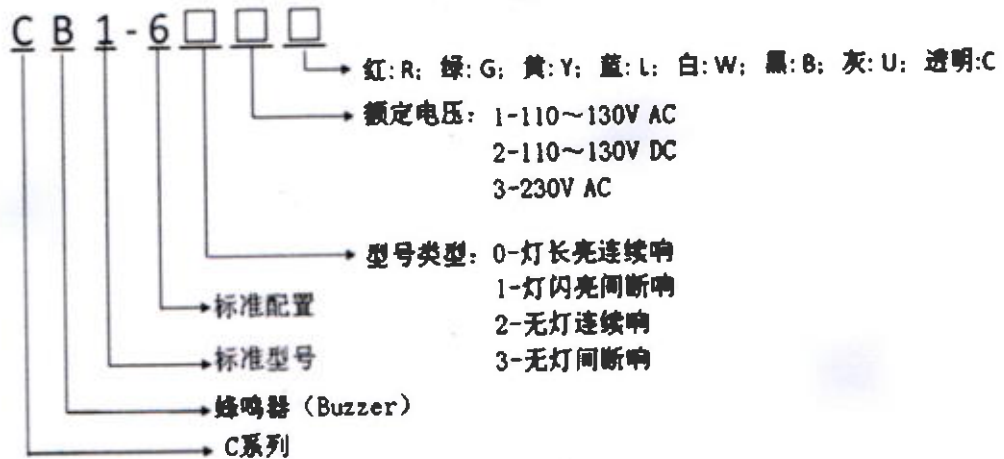

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>



产品认证证书

附录


第 9 页 共 9 页

证书编号: CQC2003010305054693

纸号: 346438

7 塑料按钮盒(套装)

CEP □ 1 - □□□□

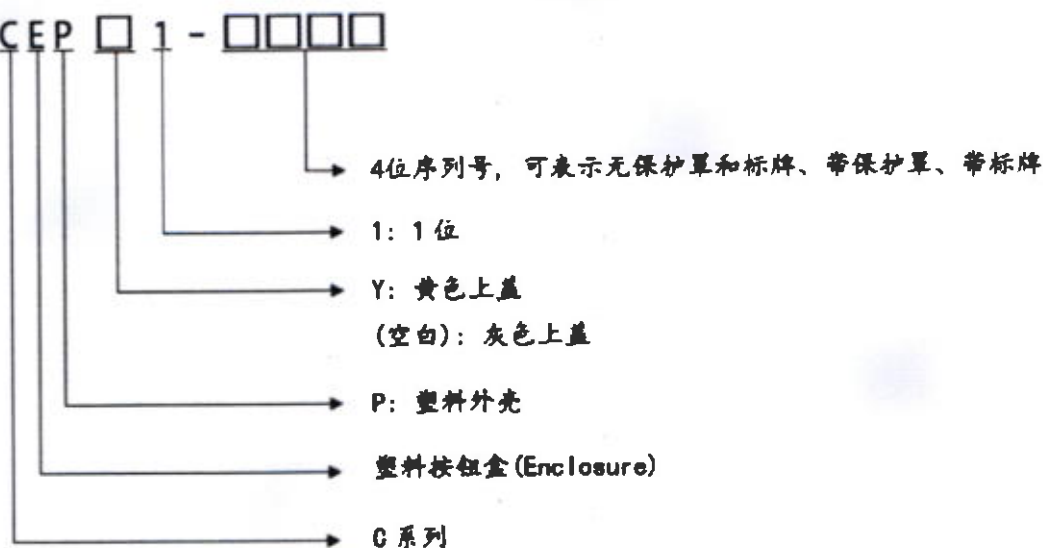

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路188号9区100070

<http://www.cqc.com.cn>