


# Camarque

Elegant LED lighting



### Aesthetically pleasing, decorative emergency LED luminaire

- Fire-resistant polycarbonate luminaire body with opal diffuser
- ELR/SLR exemption for luminaires with Emergency as the primary function
- Semi-recessing accessory available
- Complies to IEC 60598.2.22 and IEC 60598-1

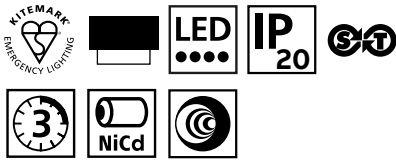

### Luminaire


Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
CLQ1LA1	CLQ LED 2D WH/OPAL HF	110-230 AC/DC 0-60Hz	1 x LED 20W	1830	20.8 / 19.5	230V	0-40	1.7
CTCLQ4LA1	CLQ LED 2D WH/OPAL CT	220-240 AC 50/60Hz	1+1 LED 20+2W	1830/207	25.8 / 23	3	0-30	2.2
LTCCLQ1LA1	CLQ LED 2D WH/OPAL LTC	220-240 AC 50/60Hz	1 x LED 20W	1830	20.8 / 19.5	230V	0-40	1.8
STCLQ4LA1	CLQ LED 2D WH/OPAL SLFTST	220-240 AC 50/60Hz	1+1 x LED 20+2W	1830/207	25.8 / 23	3	0-30	2.1



### Accessories

Order code	Description
CLQ/SR	Semi-recessing kit

See spacing tables on pages 130

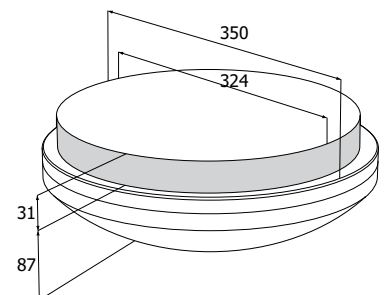

Cable entry via 20 mm hole on rear of unit.  
Ceiling cutout 330 mm when semi-recessing.