

PRODUCT BROCHURE

Sta-Kon[®] power crimp tools for 22–6 AWG insulated/non-insulated terminals

3 tools + 1 interchangeable die set = savings



Sta-Kon® power tools for 22–6 AWG insulated/non-insulated terminals

Interchangeable dies provide consistent crimps from all your tools.


01 BAIR22-6 – heavy-duty bench-top air crimp tool

These Sta-Kon power crimp tools meet a wide range of crimping needs — from 22 to 6 AWG, from stationary to mobile, and from medium to high volume. Best of all, all three tools use the same affordable hand-tool crimping dies, offering tremendous cost savings, as well as consistency of crimps from tool to tool. Each of these tools provides well over a ton of crimping force — enough to crimp insulated and non-insulated terminals up to 6 AWG. All three are easy on the operator's hands, minimizing the risk of repetitive-motion injuries that can occur with traditional hand crimping tools. Short cycle times keep productivity levels high. Choose among the BAIR22-6 bench-top air crimp tool, the PAIR22-6 portable air crimp tool, and the BAT22-6NV2 battery-powered hand crimp tool to meet all your crimping needs.



BAIR22-6 – Heavy-duty bench-top air crimp tool

- Ideal for wire-harness or panel assembly applications
- Bench-mounted power tool driven by air (pneumatic) cylinder and operated by foot pedal
- Delivers 1.8 tons of crimping force at 100 psi
- Completes a full crimp cycle in less than 1 second for high productivity
- Shure-Stake® mechanism ensures enough power to complete the cycle, delivering a UL® listed crimp every time
- Jaws switchable from normally open to normally closed, providing a spring-loaded terminal-holding feature
- Crimps Sta-Kon terminals, splices and disconnects on 22–6 AWG wire using economical hand-tool dies
- Can also be used to crimp Spec-Kon® terminals, Dragon Tooth® connectors and Sta-Kon ferrules
- Tool comes with pneumatic port for connection to air supply, foot pedal, air hose and air lubricator (dies sold separately)
- Requires 85 psi minimum to 100 psi maximum, non-lubricated air
- Dimensions: 12"L x 8"W x 8"D, 17 lbs.

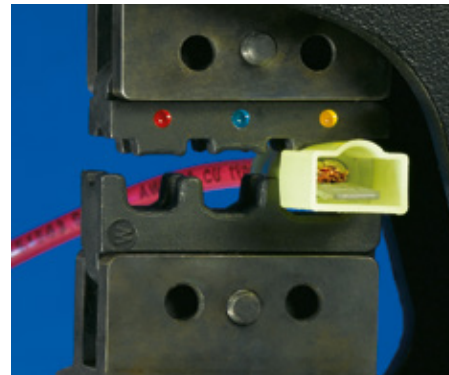

—
02 PAIR22-6 heavy-duty portable air crimp tool

—
03 BAT22-6NV2 heavy-duty battery-powered crimp tool

PAIR22-6 heavy-duty portable air crimp tool

- Ideal for OEM and MRO crimping applications requiring mobility
- Delivers 1.25 tons of crimping force at 100 psi
- Completes a full crimp cycle in less than 1 second for high productivity
- Open yoke enables easy insertion/removal of all terminals including 8 and 6 AWG sizes
- Die holder is spring-loaded to the normally closed position to facilitate holding connectors
- Aluminum crimping head rotates 360° for easy access to hard-to-reach connections
- Crimps Sta-Kon terminals, splices and disconnects on 22–6 AWG wire using economical hand-tool dies
- Can also be used to crimp Spec-Kon terminals, Dragon Tooth connectors and Sta-Kon ferrules
- Tool comes with pneumatic port for connection to air supply (dies sold separately)
- Requires 85 psi minimum to 100 psi maximum, non-lubricated air
- Dimensions: 14"L x 2.375" dia., 2.5 lbs.

BAT22-6NV2 heavy-duty battery-powered crimp tool

- Exclusive UL listing*
- Extra battery, charger and carrying case included
- Powerful lithium-ion batteries with charge level indicator
- Single-lever motorized operation for easy manual preclamping, automatic crimping and auto-retract functions
- Extremely light and super fast
- Motor stall protection in case of faulty operation
- LED task illumination
- Includes extra battery, charger and carrying case (dies sold separately)

*When used with UL listed die sets.



—
02



—
03



Sta-Kon® power tools for 22–6 AWG insulated/non-insulated terminals

Interchangeable dies provide consistent crimps from all your tools!

Sta-Kon heavy-duty bench-top air crimp tool



Cat. no.	Description	Std. pkg. qty.	UPC no.
BAIR22-6	Bench-top air tool for 22–6 AWG terminals	1	786210-96227

Sta-Kon heavy-duty portable air crimp tool



Cat. no.	Description	Std. pkg. qty.	UPC no.
PAIR22-6	Portable air tool for 22–6 AWG terminals	1	786210-96900

Sta-Kon heavy-duty battery-powered crimp tool



Cat. no.	Description	Std. pkg. qty.	UPC no.
BAT22-6NV2	Battery-powered hand tool for 22–6 AWG terminals	1	786210-07953

Die sets for Sta-Kon power crimp tools



Cat. no.	Description	Std. pkg. qty.	UPC no.
DIE2001	For insulated 22–10 AWG Sta-Kon terminals	1	786210-92215
DIE2002	For non-insulated 22–10 AWG Sta-Kon and Spec-Kon terminals	1	786210-92216
DIE2005	For non-insulated 16–6 AWG Sta-Kon terminals	1	786210-93172
DIE2007	For insulated 8–6 AWG Sta-Kon terminals	1	786210-92546
DIE2009	For RB, RC, RP wire joints	1	786209-87248
DIE2500	For insulated 22–10 AWG Spec-Kon terminals	1	786210-92217
DIE1801	For Dragon Tooth 01 series	1	786210-96272
DIE1802	For Dragon Tooth 02 series	1	786210-96272
DIE1804	For Dragon Tooth 04 series	1	786210-96410
DIE1806	For Dragon Tooth 06 series	1	786210-96271
ERG4	For insulated and non-insulated ferrules (includes hand tool frame in kit)	1	786209-92876

ABB Inc.
 Electrification Products
 860 Ridge Lake Blvd.
 Memphis, TN 38120
 Customer Service: 800-816-7809
 Technical Support: 888-862-3289

abb.com/lowvoltage

We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB Inc. does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction or utilization of its contents – in whole or in parts – is forbidden without prior written consent of ABB Inc.
 Copyright © 2018 ABB
 All rights reserved