

Hazlux® AH1 LED Series

Explosion-proof, shock and vibration resistant lighting fixture, designed for use in marine and wet locations, and a variety of hazardous areas.

CERTIFICATION

CLASS I

Division 1 Group B, C, D

Division 2 Group A, B, C, D

CLASS II


Division 1 Group E, F, G

Division 2 Group E, F, G

CLASS III

Classification may vary depending on the product configuration. Please follow catalogue information and exceptions.

 APPROVALS



APPLICATIONS

Power plants

Paper mills

Paint spray booth

Wastewater treatment plants

Chemical processing

Petrochemical

Life expectancy: 130,000 Hours

Certified for use in
marine locations

Corrosion resistant copper
free aluminum housing

IP66/67 rated fixture

Available with clear or frosted
tempered glass lens



Hazlux® AH1 LED Series

Key features and information

FEATURES

Temperature range 40W and 50W models:
-40°F to 149°F (-40°C to 65°C)

Temperature range 60W model:
-40°F to 147°F (-40°C to 64°C)

Exposed hardware made of stainless steel

HOUSING

Housing made of copper-free aluminum

Anti-corrosion housing (tested for 1000hrs)

Tempered glass lens is impact and thermal shock resistant

Lens tested to IK08

High temperature silicone gasketing

Available with multiple distribution patterns

LED

Efficacy: up to 150 Lm/W

Lumen output: From 6,499 Lumens to 8,514 Lumens

Nichia LED's

CRI Ra>75

Correlated Color Temperature (CCT): 5000K (standard), 3000K and 4000K (optional)

ELECTRICAL

Operating voltage: 120Vac-277Vac : 40W and 60W

Operating voltage: 347Vac-480Vac: 50W

Frequency: 50/60Hz

Power factor .95

Driver efficiency 90%

THD <20%

Surge protection standard at 4KV. Contact your sales representative if higher protection is required.

MOUNTING

Pendant mount

Optional yoke/pipe bracket for wall/ceiling or pole mount

APPROVALS

UL 844

UL 8750 LED safety

UL 1598 Wet Locations

UL 1598A Marine

CUL approved to CSA 22.2 No. 137, CSA 22.2 No. 250.0-08, CSA 22.2 No. 250.13

IP66/67

IK08

5G (shock and vibration resistant)

1000hrs salt spray

WARRANTY

5 year limited warranty

T-code chart

Fixture	40 watt	50 watt	60 watt
C1D1	T6	T6	T6
C1D2	T4	T4A	T4
CIID2	T6	T6	T5

Electrical specifications

Specification	AH1-40	AH1-50	AH1-60
Rated power	40W	50W	60W
Input voltage	AC120-277V	AC347-480V	AC120-277V
Input frequency	50/60Hz	50/60Hz	50/60Hz
Input current	AC120/277V AC347/480V	0.34/0.16A N.A	N.A 0.48/0.215A
Power factor	≥0.95		

Lighting output


Fixture	40 watt	50 watt	60 watt
Lumen output	6499	7179	8514
Lumen per watt	160	140	140





Hazlux® AH1 LED Series

PHOTOMETRY

Type III

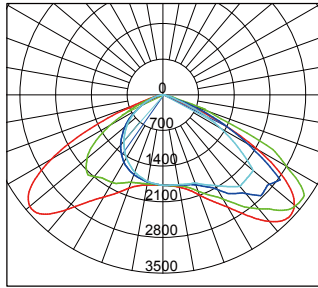


- C0/180,134.6
- C30/210,133.3
- C60/240,98.3
- C90/270,102.0

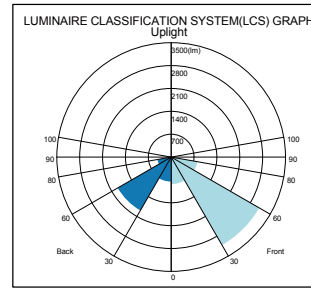
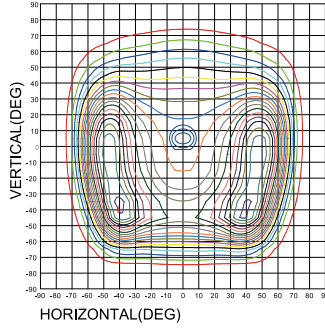


BUG (Back, Up, Glare) Rating: B2-U0-G1

Type V

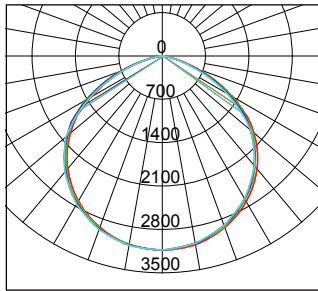

- C0/180,112.5
- C30/210,113.7
- C60/240,112.9
- C90/270,111.4

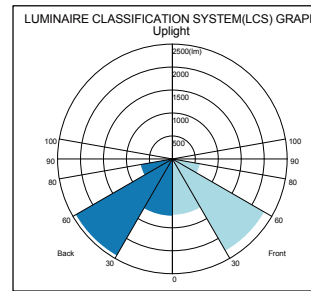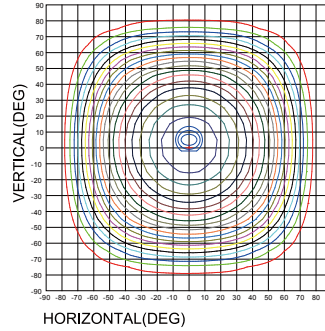

BUG (Back, Up, Glare) Rating: B3-U0-G1

MOUNTING AND OPTIONAL ACCESSORIES (sold separately)

Pendant Mount

(Included standard)




Yoke/Pipe Bracket


(Optional accessory)



Pole Mount

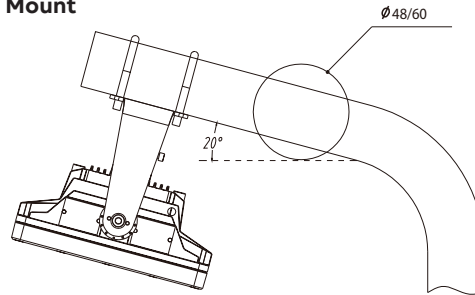

PB02 - Yoke/Pipe Bracket (SUS 304) Stainless steel
(Optional accessory)

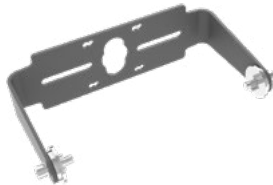

PC01 - Pipe clamp (1 pair)
(Optional accessory)




PC01 = Pipe clamp (M8*48mm) for pole Ø 1-7/8" (48 mm)

PC02 - Pipe clamp (1 pair)
(Optional accessory)



PC02 = Pipe clamp (M8*60mm) for pole Ø 2-3/8" (60 mm)

WG04 - Stainless steel wire guard
(Optional accessory)

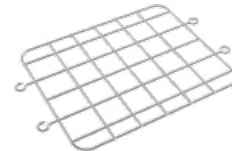


Note: Wall mount bracket required for Pipe installation.

Hazlux® AH1 LED Series

DIMENSIONS


Dimensions are approximate and subject to change.

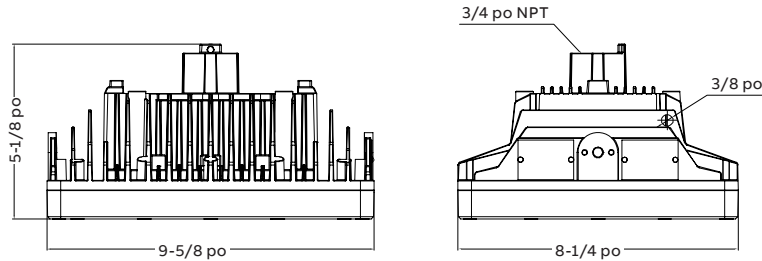

Model	Net weight C1D1 (Glass)	Product dimensions
AH1-40	4.9kg/10.8lbs	245x210x129mm 9.7x8.3x5.1in
AH1-50	5.3kg/11.7lbs	
AH1-60	5.3kg/11.7lbs	

NUMBERING SYSTEM

Lighting fixture

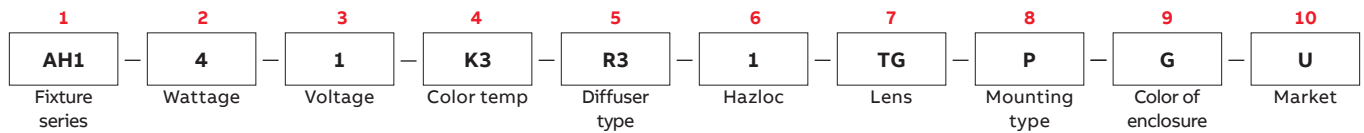

Ordering information

Part	Part number	Description
1 Fixture series	AH1	Hazlux LED Class I Div 1
2 Wattage	4	40 watts
	5	50 watts
	6	60 watts
3 Voltage	1	120-277V (40W and 60W only)
	4	347-480V (50W only)
4 Color temp	K3	3000K ¹
	K4	4000K ¹
	K5	5000K
5 Diffuser type	R3	Type 3 Diffuser ¹
	R5	110° (no diffuser)
6 Hazloc	1	C1D1
7 Lens	TG	Clear glass
	FG	Frosted glass ¹
8 Mounting type	P	NPT 3/4 pendant mount
	U	NPT 3/4 pendant mount + Yoke bracket
9 Color of enclosure	G	Gray
10 Market	U	U.S. market
	Blank	Canadian market

¹Longer lead time, contact your sales representative for more details.

Accessories (sold separately)

PC01	Pipe clamp (1 pair) Pipe clamp (M8*48mm) for pole Ø 1-7/8" (48mm)
PC02	Pipe clamp (1 pair) Pipe clamp (M8*60mm) for pole Ø 2-3/8" (60mm)
PB02	Yoke/Pipe Bracket (SUS 304) Stainless steel
WG04	Stainless steel wire guard

Note: For Canadian market, please add "-CA" to the part no. (ex: PC01-CA).