


FurseWELD

Bar to bar BB7

Bar to bar BB7 - FurseWELD

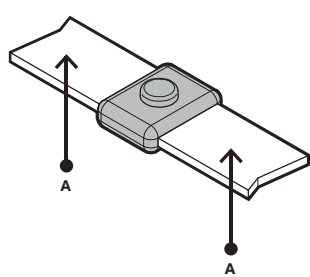

Flat tape conductor size A (mm)	Mould part no.	Order code	Powder cartridge part no.	Handle clamp part no.
20 x 3	BB7-4-203	7TCA083910R0309	45P10	HCPK4
25 x 3	BB7-4-253	7TCA083910R0311	65P10	HCPK4
25 x 3	BB7-4-253-IU	–	65P10	HCPK4
25 x 4	BB7-4-254	7TCA083910R0312	90P10	HCPK4
25 x 4	BB7-4-254-IU	–	90P10	HCPK4
25 x 6	BB7-4-256	7TCA083910R0313	115P10	HCPK4
25 x 6	BB7-4-256-IU	–	115P10	HCPK4
30 x 3	BB7-4-303	7TCA083910R0317	65P10	HCPK4
30 x 4	BB7-4-304	7TCA083910R0319	90P10	HCPK4
30 x 5	BB7-4-305	7TCA083910R0320	115P10	HCPK4
31 x 6	BB7-4-316	7TCA083910R0325	150P10	HCPK4
38 x 5	BB7-4-385	7TCA083910R0327	150P10	HCPK4
38 x 6	BB7-4-386	7TCA083910R0328	200P10	HCPK4
40 x 3	BB7-4-403	7TCA083910R0330	90P10	HCPK4
40 x 4	BB7-4-404	7TCA083910R0331	115P10	HCPK4
40 x 4	BB7-4-404-IU	–	115P10	HCPK4
40 x 5	BB7-4-405	7TCA083910R0335	150P10	HCPK4
40 x 6	BB7-4-406	7TCA083910R0336	200P10	HCPK4
50 x 3	BB7-5-503	7TCA083910R0342	150P10	HCPK5
50 x 4	BB7-5-504	7TCA083910R0343	200P10	HCPK5
50 x 4	BB7-5-504-IU	–	200P10	HCPK5
50 x 5	BB7-5-505	7TCA083910R0344	200P10	HCPK5
50 x 6	BB7-5-506	7TCA083910R0345	250P10	HCPK5
50 x 6	BB7-5-506-IU	–	250P10	HCPK5

Special moulds for all FurseWELD products can be manufactured to meet specific customer applications on request

For order codes of powder cartridges and handle clamps, see pages 49-50

FurseWELD moulds should only be used with FurseWELD powders, handle clamps and accessories. If moulds, powders, handle clamps and accessories from other manufacturers are utilized, we cannot guarantee the safe use or the integrity of the completed joint

Conductors must be installed in the orientation shown to achieve the correct connection