




**TOP VIEW**

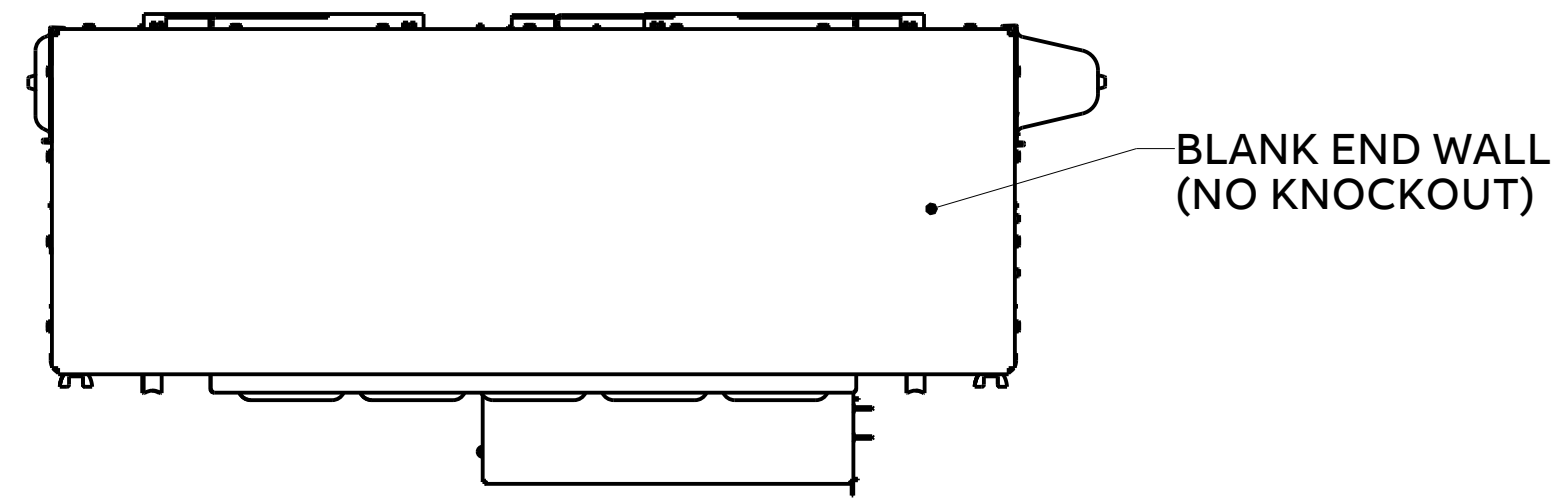


**SECTIONAL SIDE VIEW**

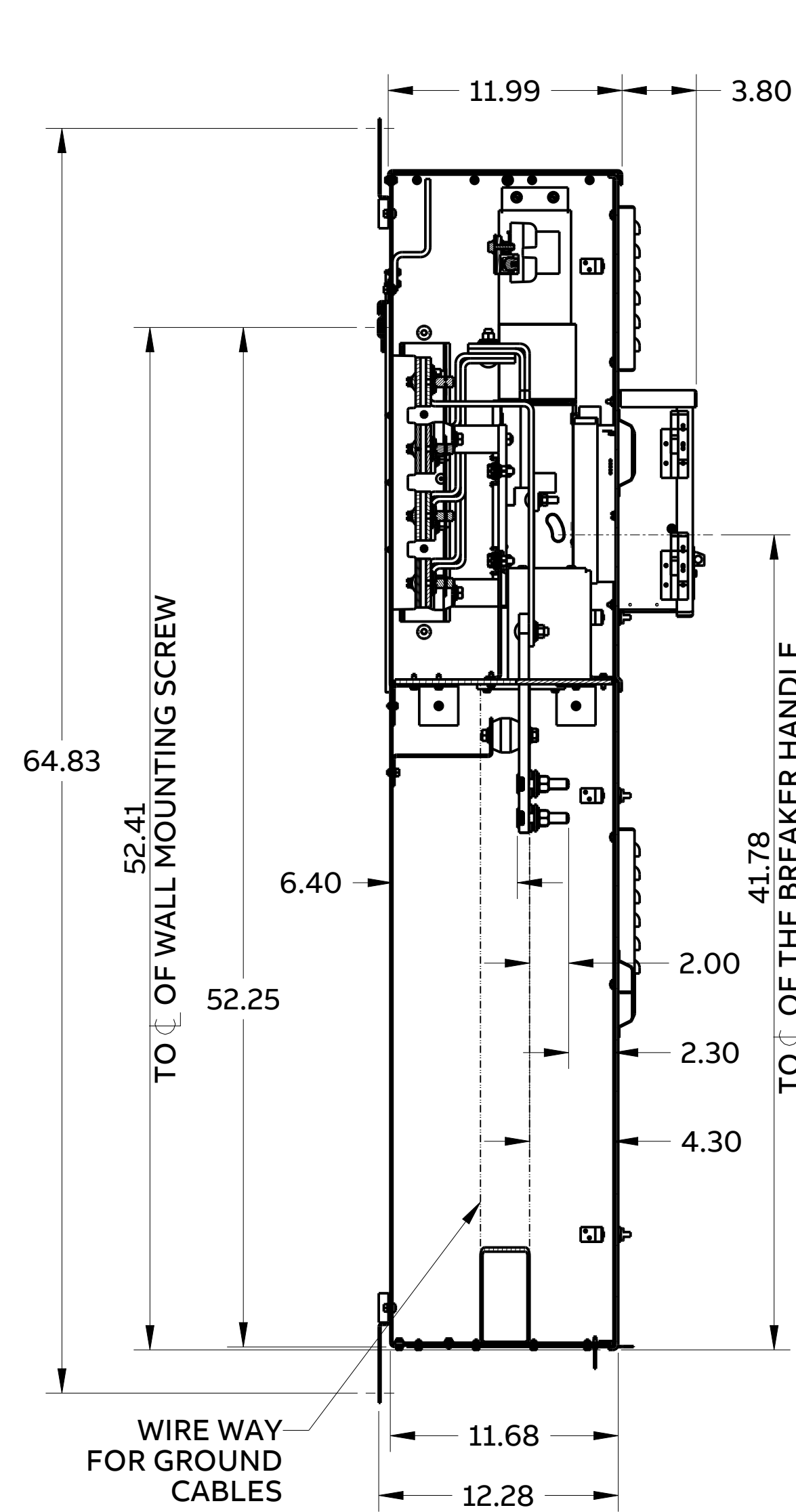


**FRONT VIEW**

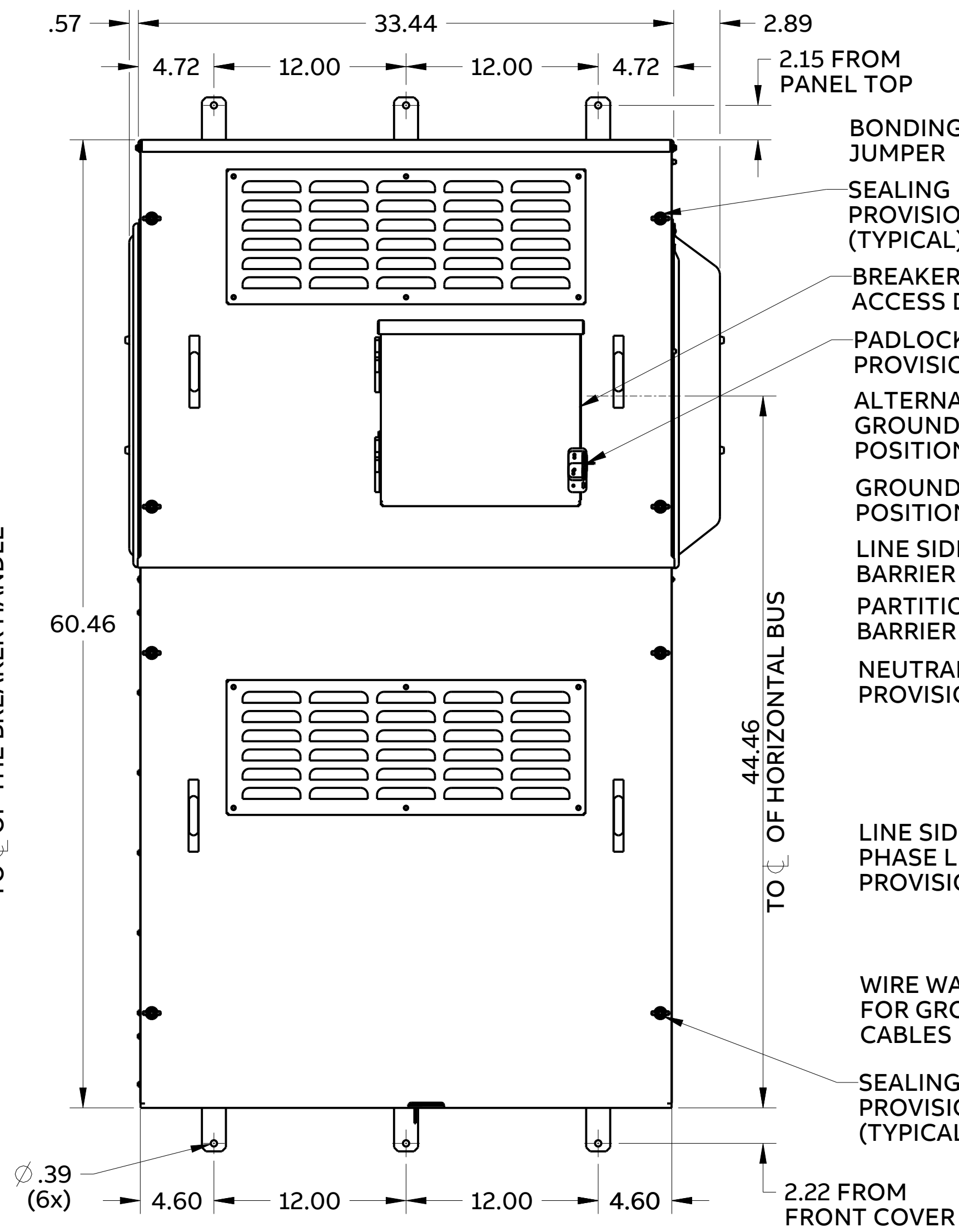

**FRONT VIEW (WITH OUT FRONT COVERS)**

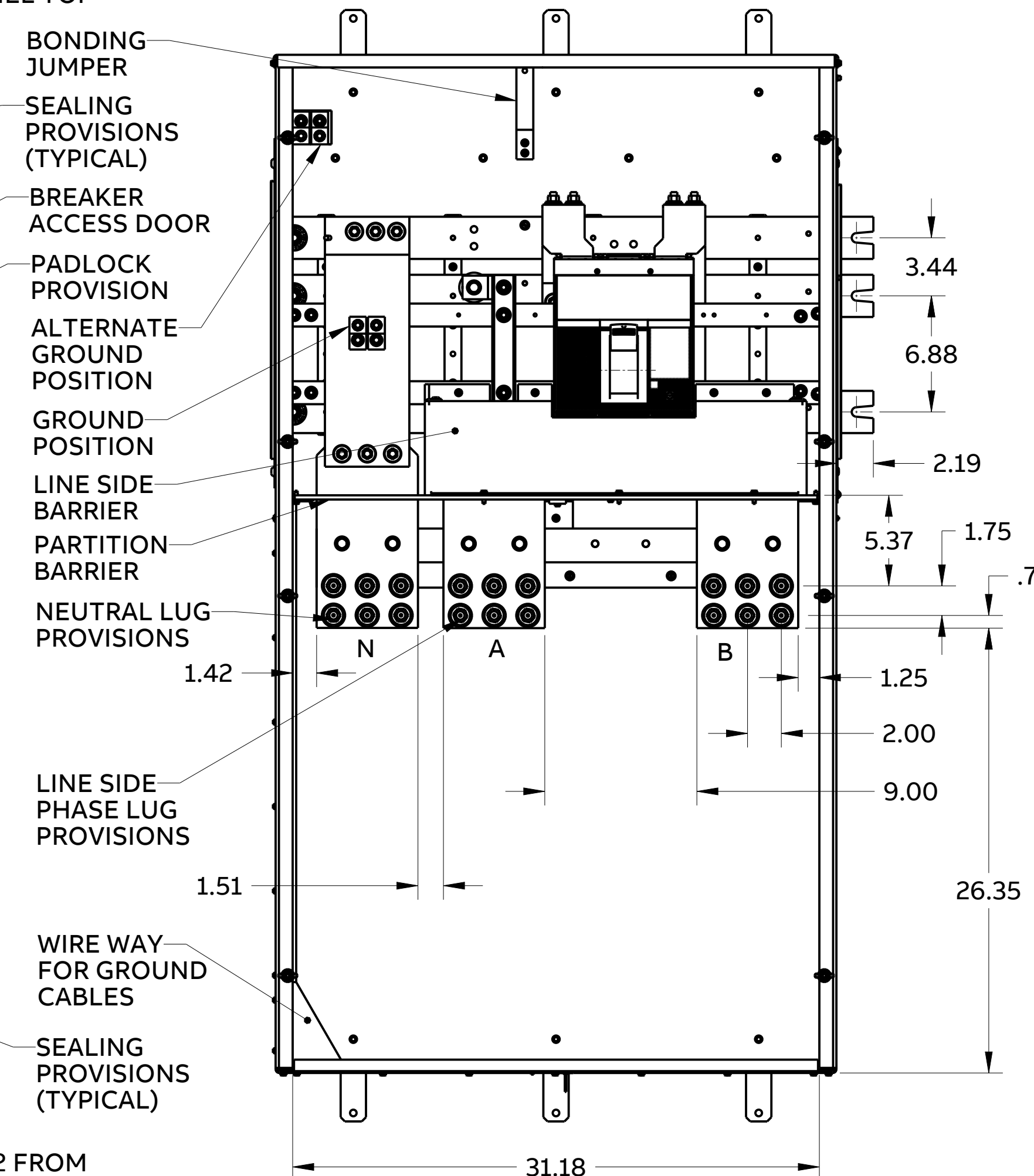

**BOTTOM VIEW**

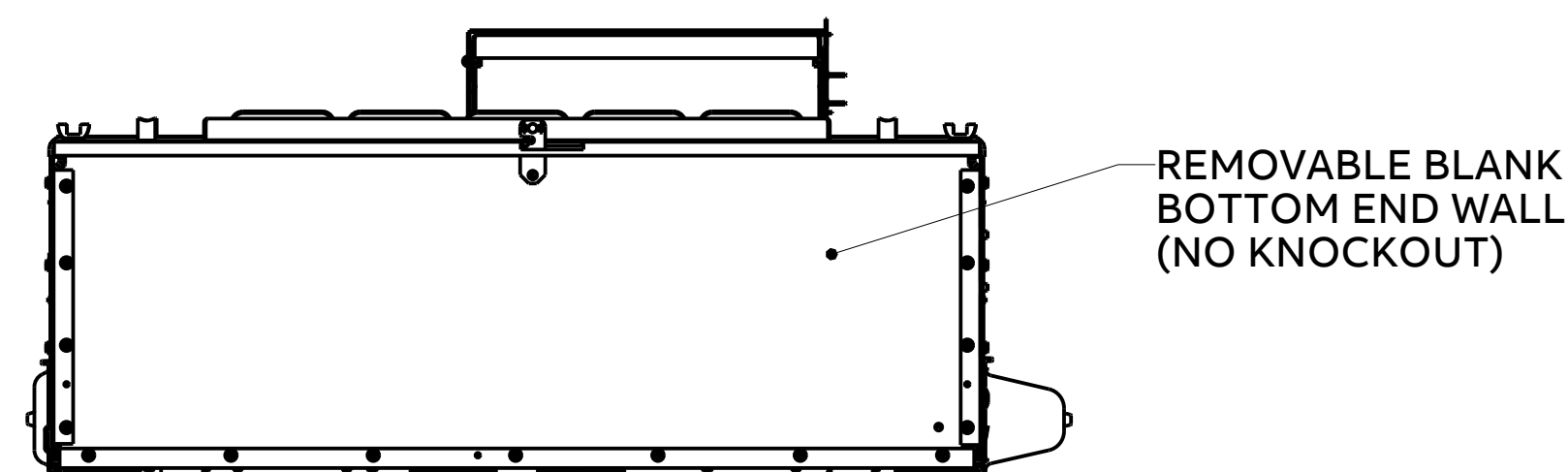

- Specification:**
- Phase: 1-Phase 3-Wire
  - Voltage: 120/240V
  - Amperage: 1000A
  - Circuit Breaker Frame: XT7S
  - Circuit Breaker Trip Unit: Ekip Dip LS/I
  - Circuit Breaker kAIC: 65kA @ 240V
  - Incoming Feed: Bottom Only
  - Enclosure: N3R Outdoor
  - Estimated Weight: 330 lbs
  - Meets EUSERC Requirements, EUSERC Drawing Reference 315, 343, 347

- Conductor Range:**
- Phase lugs and neutral lugs not included, Landing Pad only.
  - Landing Pad has provision for double hole lugs up to (3) 750kcmil Cu/Al.
  - Ground Lugs: (2) #6-350 kcmil Cu/Al.

DIMENSIONS: INCH



SHEET#  
1 of 1

CATALOG NO.  
RMM1BEL10R

**ABB ReliaMod™**  
1000A MAIN BREAKER MODULE  
65kA 1PH 3W 120/240V N3R EUSERC

DATE  
04-Aug-23

REV  
A