

Type KESUL

UL1 Compliant Flexible Steel Conduit



KESUL Galvanized Steel Flexible Conduit is UL listed. Flexibility, pull and impact resistance comply with UL1 standards.

Certifications / Standards:



Features & benefits:

- UL 1 compliant
- UV resistant
- High flexibility
- Inherent low fire hazard

Temperature range:

- -50°C to +350°C

Material / Materials / Finishes:

- Galvanized Steel

Conforms to:

- UL1

Degree of mechanical protection:


- Medium flexibility & high fatigue life

Ingress protection:

- Upto IP40 (Fitting dependant)

Applications

- Elevators
- HVAC
- Lighting
- Cable Tracks
- Underfloor

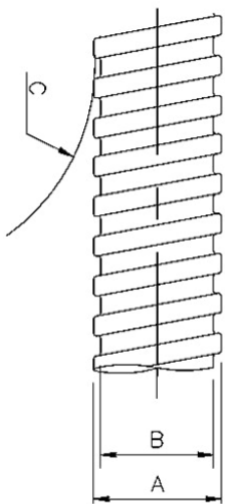

Conduit Profile

Type KESUL Conduit – Part numbers and dimensions

Part No.	Conduit		Dimensions (mm)			Reel Length (ft)
	US Trade Size	Metric	Outside Dia. (A)	Inside Dia. (B)	Bend radi (C)	
KESUL0430	1/2"	20	18.4	16.1	75	100
KESUL0530	3/4"	25	27.3	20.9	100	100
KESUL0615	1"	32	34.0	25.9	125	50
KESUL0915	2"	63	61.0	51.8	255	50

ABB Cable Management Products Ltd
 CMG House, Station Road,
 Coleshill, Birmingham
 B46 1 HT
 Tel: +44 (0) 1675 468 200

For Sales Support contact:
 gb-cmg.salessupport@abb.com
For Technical Support contact:
 cmg.conduitsystems@abb.com
For Samples Support contact:
 gb-sample-requests@abb.com

We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB Cable Management Products Ltd. does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction, disclosure to third parties or utilisation of its contents – in whole or in parts – is forbidden without prior written consent of ABB Cable Management Products Ltd. Copyright© 2023 ABB. All rights reserved