


Movion®

Modular & versatile



Escape route lighting - Surface mount

- Square shaped design fitting any ceiling
- Specially designed lens for optimal light distribution - long and wide beam
- Quick installation and parallel wiring option with the smart loop-in, loop-out system
- Light track mountable with 3C adapter included

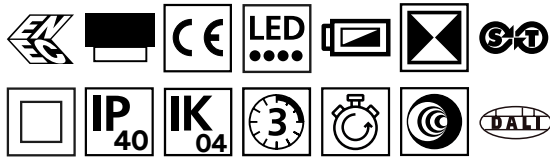

Luminaire

Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Light optics	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
511013111/50	EL800S-M3/ST ER	230-240 AC 50/60Hz	1 x LED 1W	101	Escape route	3.33 / 3.19	3	5-35	0.39
511013211/50	EL800S-M3/DALI ER	230-240 AC 50/60Hz		101		3.33 / 3.19	3	5-35	0.39
511013311/50	EL800S-M3/COM ER	230-240 AC 50/60Hz		101		3.33 / 3.19	3	5-35	0.39
511012811/50	EL800S-230 ER	220-240 AC/DC 0-60Hz		124	Open area	3.21 / 3.05	230V	0-40	0.29
511012611/50	EL800S-230/LTC ER	220-240 AC 50/60Hz		124		3.21 / 3.05	230V	0-40	0.29
511013112/50	EL800S-M3/ST OA	230-240 AC 50/60Hz		109	Open area	3.33 / 3.19	3	5-35	0.39
511013212/50	EL800S-M3/DALI OA	230-240 AC 50/60Hz		109		3.33 / 3.19	3	5-35	0.39
511013312/50	EL800S-M3/COM OA	230-240 AC 50/60Hz		109		3.33 / 3.19	3	5-35	0.39
511012812/50	EL800S-230 OA	220-240 AC/DC 0-60Hz		134	Open area	3.21 / 3.05	230V	0-40	0.29
511012612/50	EL800S-230/LTC OA	220-240 AC 50/60Hz		134		3.21 / 3.05	230V	0-40	0.29

Accessories

Order code	Description	Product type
5110007/50	PK EL800	Pendant kit surface mounted escape route lighting

Modular pendant tubes and accessories to be used in combination with the pendant kit
See spacing tables on pages 134-138

