

Contact us

ABB Oy

P.O. Box 622
FI-65101 Vaasa
Finland



abb.com/lowvoltage

© Copyright 2024 ABB. All rights reserved.
Specifications subject to change without notice.


34OT_G2-34 rev. B / 1SCC301134M0201 # 23.09.2024




OT Plus OT63...100G2-

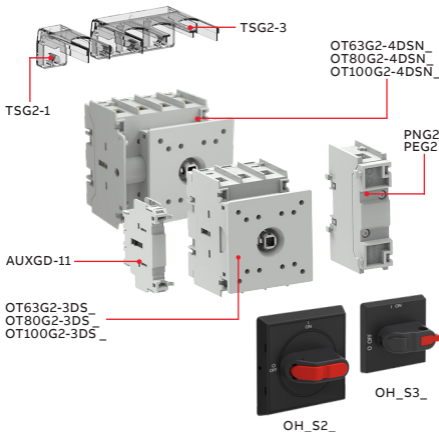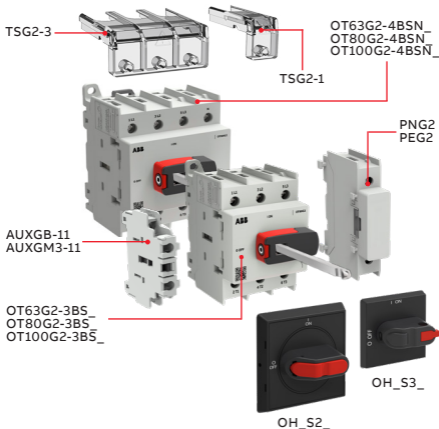


Mounting

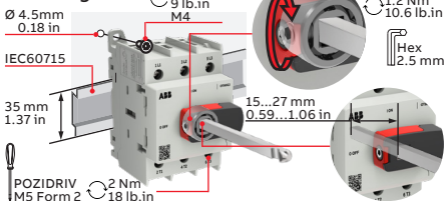

Padlock

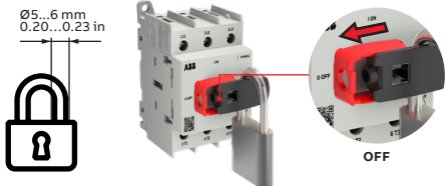

Adjustable neutral pole timing

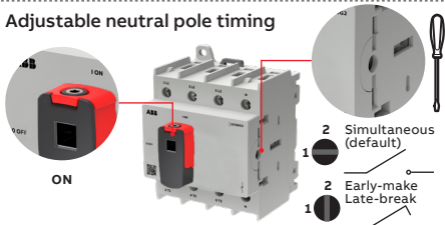

Clearances per UL60947-4-1



Wire type (Cu only)	1 Wire (mm ²)	2 Wire (mm ²)	Stripping length	Tightening torque
Class 5-Flexible	1.5-35	1.5-16		
Class 2-Stranded	1.5-35	1.5-16		
Class 6-Very flexible with ferrule	1.5-4	1.5-4	13-16 mm 0.51-0.63 in	2 Nm 18 lb.in
Class 1-Solid	1.5-6	1.5-6		
UL - CU wire size (AWG)	16-2	16-8		



 Warning! Hazardous voltage! Installation by person with electrotechnical expertise only.

