




TOP VIEW

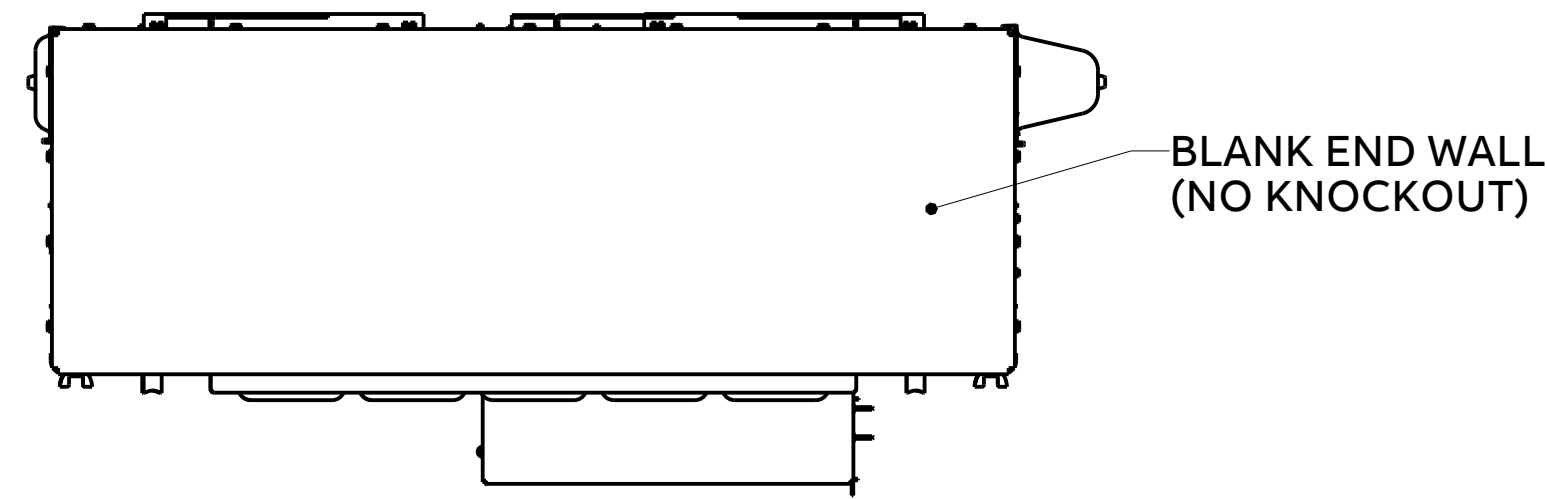


SECTIONAL SIDE VIEW

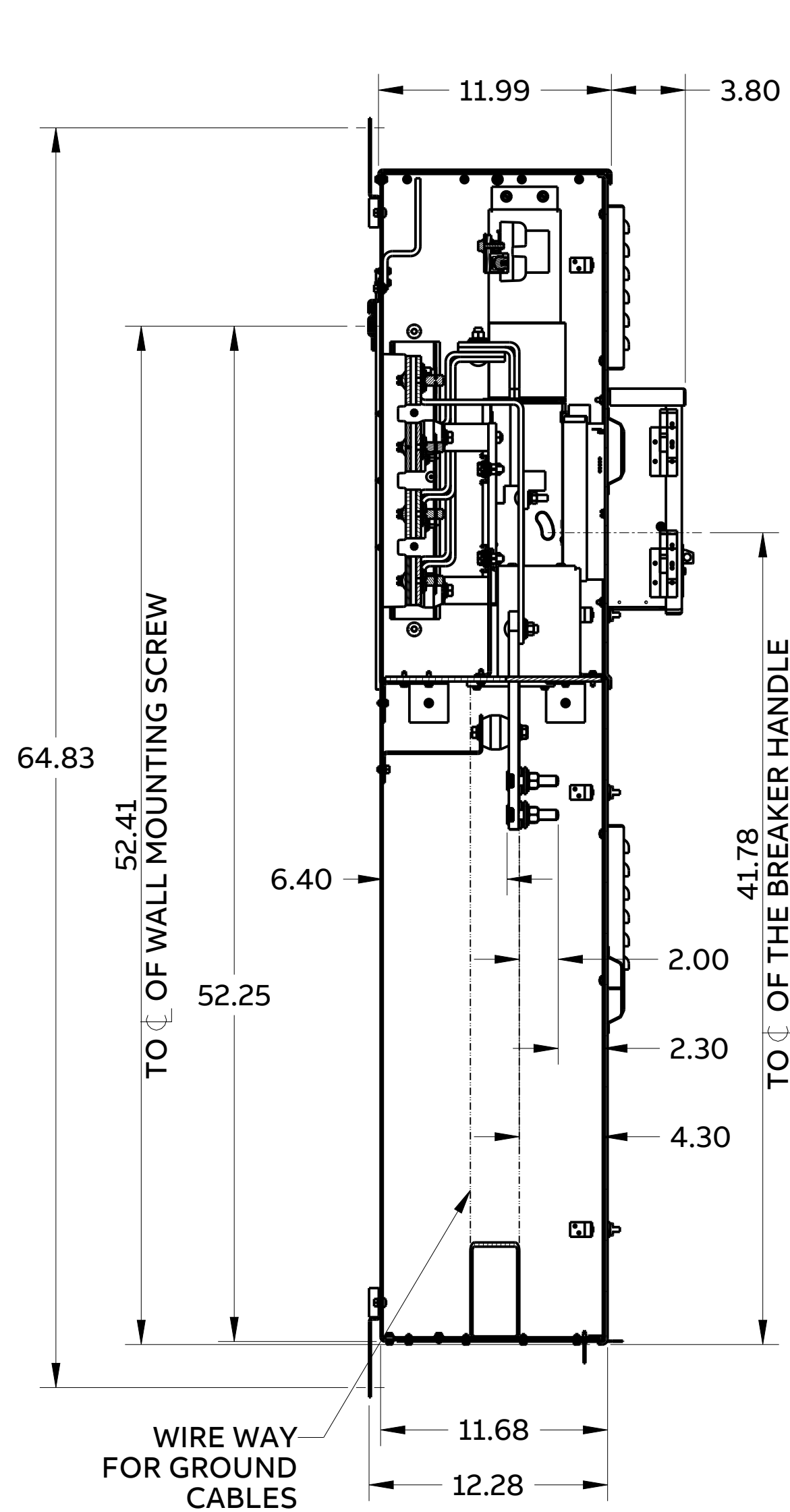


FRONT VIEW

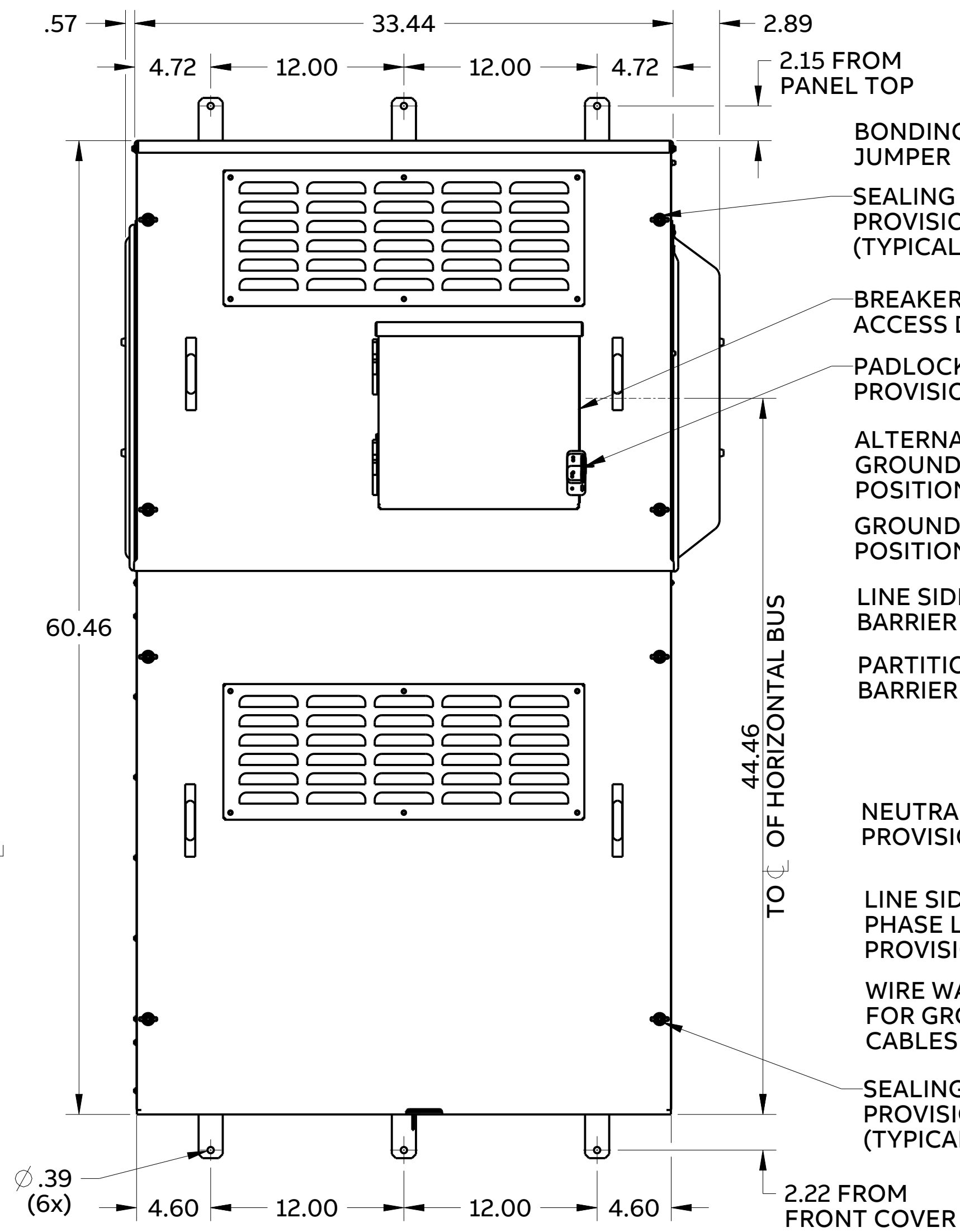

FRONT VIEW (WITH OUT FRONT COVERS)

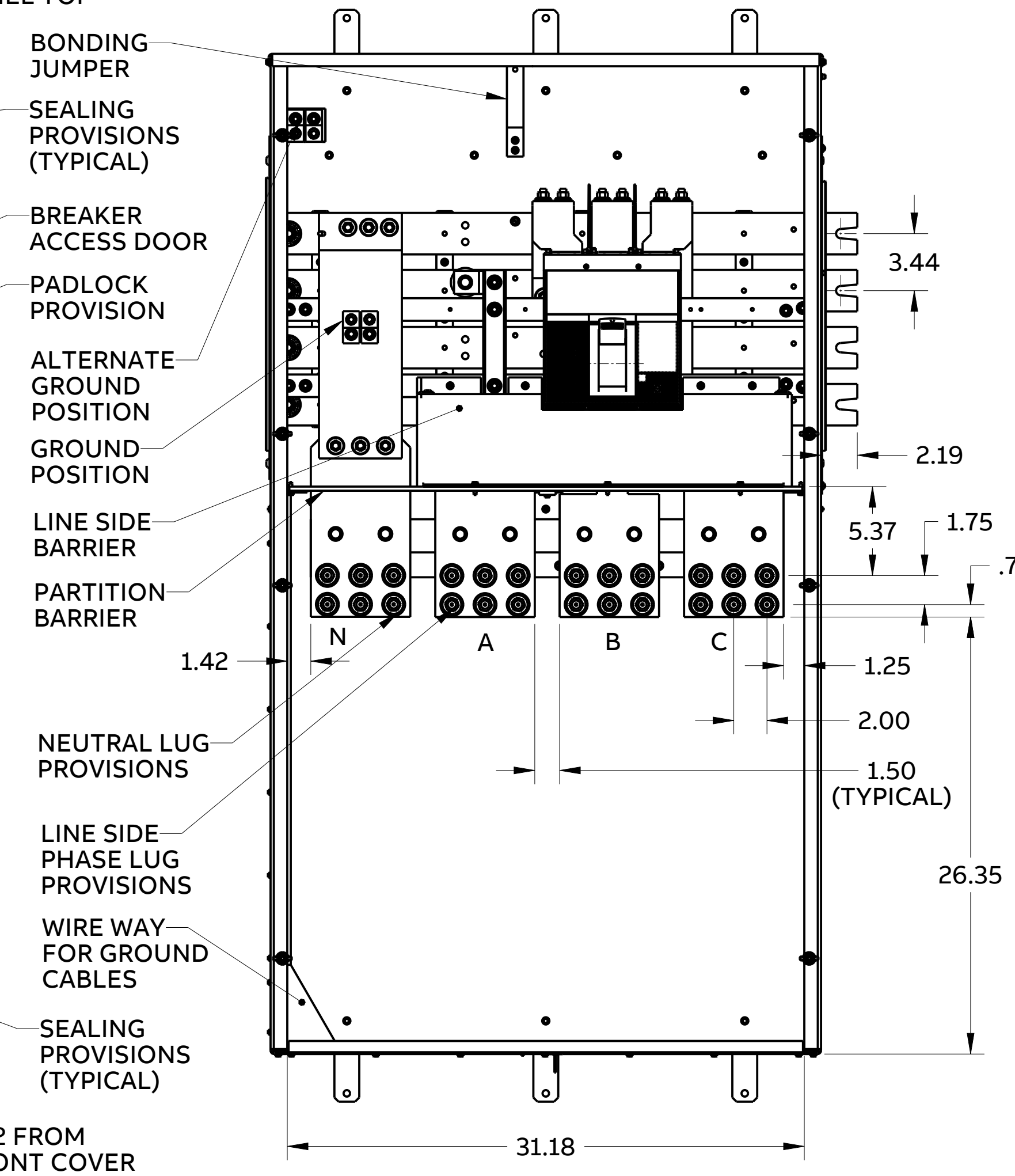

BOTTOM VIEW

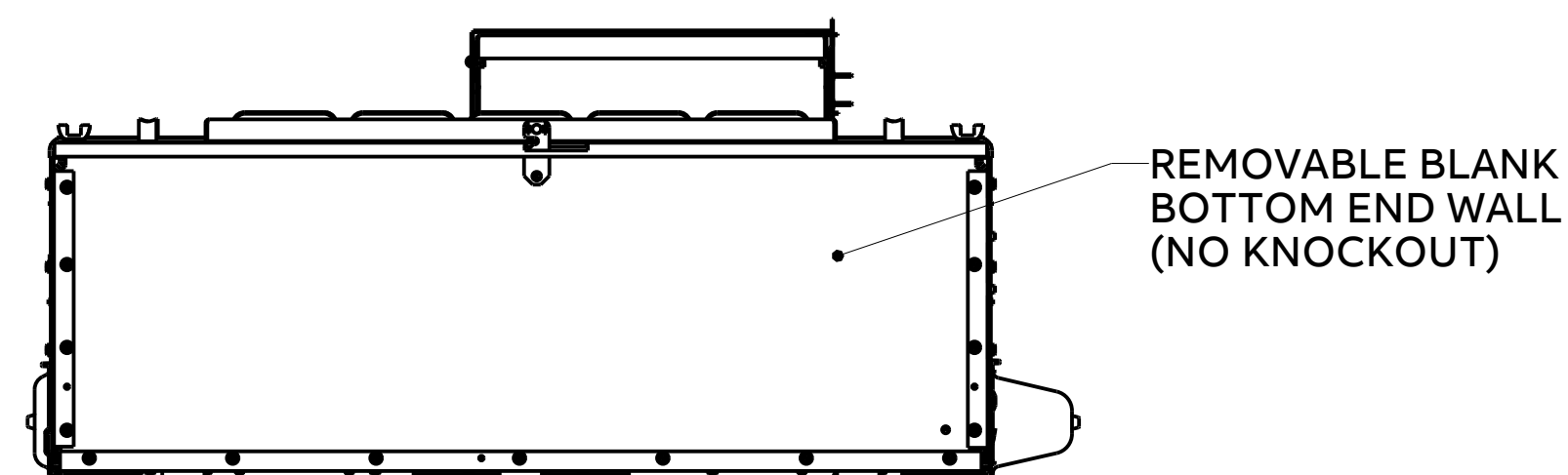

- Specification:**
- Phase: 3-Phase 4-Wire
 - Voltage: 208Y/120V
 - Amperage: 1000A
 - Circuit Breaker Frame: XT7S
 - Circuit Breaker Trip Unit: Ekip Dip LS/I
 - Circuit Breaker kAIC: 65kA @ 240V
 - Incoming Feed: Bottom Only
 - Enclosure: N3R Outdoor
 - Estimated Weight: 330 lbs
 - Meets EUSERC Requirements, EUSERC Drawing Reference 315, 343, 347

- Conductor Range:**
- Phase lugs and neutral lugs not included, Landing Pad only.
 - Landing Pad has provision for double hole lugs up to (3) 750kcmil Cu/Al.
 - Ground Lugs: (2) #6-350 kcmil Cu/Al.

DIMENSIONS: INCH

THIRD ANGLE	SHEET#
	1 of 1

CATALOG NO.	DATE	REV
RMM3BEL10R	01-Aug-23	A

ABB | **ReliaMod™**

1000A MAIN BREAKER MODULE
65kA 3PH 4W 208Y/120V N3R EUSERC