

Distinction™ EF150 Series

Surface mounted designer light fixtures



Description

- Indoor use
- Available as a single, double or triple MR16 LED size lighting head
- Die-cast aluminum construction

Finish

- Powder-coated off-white or black

Mounting

- Surface mount
- Universal J-box mounting

Approval


- UL 924 listed

Warranty


- Unit has a three-year limited warranty
Detailed warranty terms located on page 178 or online at:
www.emergi-lite.com/usa/files/EL_Warranty.pdf

Photometric performance

Lamp	Spacing center-to-center (feet)	
	7' mounting height	15' mounting height
LA	43'	36'
LB	81'	64'
LG	55'	43'
LI	71'	56'
LJ	100'	85'
LL	56'	44'
LV	53'	42'

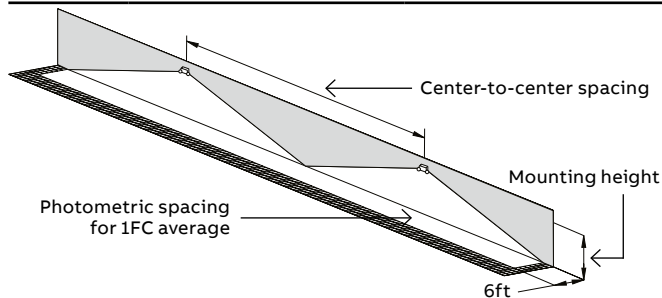

Housing color

 


White


Black

Dimensions

Dimensions are approximate and subject to change.

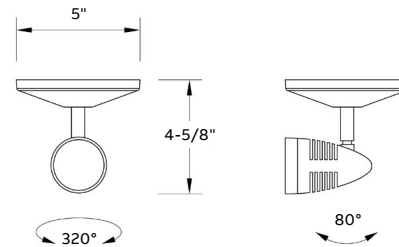

EF150

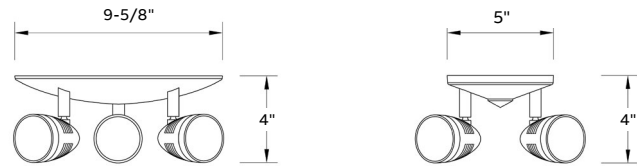

EF150T

EF150D

Accessories (order as a separate item)

Description	Suffix
Wire guard for EF150, EF150D	WG8-E
Wire guard for EF150T	WG2-E

How to order

Series	# of heads	Color	Lamp type/ wattage
EF150=	Blank= Single head	Blank= White B= Black	(LA)= 6V-4W, MR16 LED (LB)= 6V-5W, MR16 LED
Decorative MR16 remote head	D= Double head T= Triple head		(LG)= 12V-4W, MR16 LED (LL)= 24V-4W, MR16 LED (LI)= 12V-5W, MR16 LED (LJ)= 12V-6W, MR16 LED (LV)= 120V-4W, MR16 LED

Example: EF150D-B(MK)