


Product family overview

4-pole push-in contactors

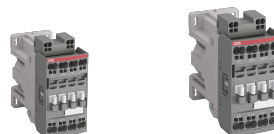

IEC	AC-1 Rated operational current	$\theta \leq 40^\circ\text{C}$, 690 V	A	25	30	45	55
UL/CSA	General use rating	600 V	A	25	30	45	55
AC / DC Control supply			Type	AF09	AF16	AF26	AF38
AC Control supply			Type	AF09	AF16	AF26	AF38
DC Control supply			Type	AF09	AF16	AF26	AF38
IEC	AC-1 Rated operational current 690 V	$\theta \leq 40^\circ\text{C}$	A	25	30	45	55
		$\theta \leq 60^\circ\text{C}^1$	A	25	30	40	45
		$\theta \leq 70^\circ\text{C}$	A	22	26	32	37
	With conductor cross sectional area		mm ²	4	6	10	16
	Rated operational voltage Ue max.		V	690	690	690	690

¹ $\theta \leq 55^\circ\text{C}$ for EK550, EK1000 contactors

Main accessories

Auxiliary contact blocks	Front mounting	CA4-10 (1 x N.O.), CA4-01 (1 x N.C.)
	Side mounting	CAL4-11 (1 x N.O. + 1 x N.C.)
Timers	Electronic	TEF4-ON TEF4-OFF
	Mechanical	VM4
Interlocking units	Mechanical / Electrical	VEM4
	Varistor + RC (AC / DC)	Built-in surge protection