


HyLED

Powerful & reliable



Energy efficient, high output LED luminaire

- 360 degrees turnable lamp unit, steady in position
- High ceilings industrial environments
- Sealed IP65 loop in, loop out cabling system
- Mounting and assembly flexibility onto pillars, ceilings, etc.

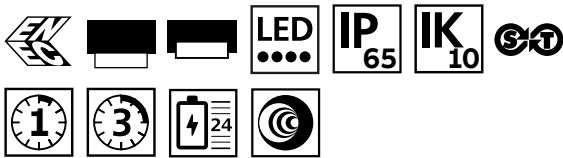

Luminaire

Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
3 hour								
C3HY3LA2	HY-LED CT-M/NM3 OA GY PC IP65	220-240 AC 50Hz	1 x LED 7W	400	15 / 7	3	0-25	1.7
C3HY3LE2	HY-LED CT-M/NM3 ESC GY PC IP65	220-240 AC 50Hz	1 x LED 7W	400	15 / 7	3	0-25	1.7
HY3LA2	HY-LED M/NM3 OA GY PC IP65	220-240 AC 50Hz	1 x LED 7W	400	15 / 7	3	0-25	1.7
HY3LE2	HY-LED M/NM3 ESC GY PC IP65	220-240 AC 50Hz	1 x LED 7W	400	15 / 7	3	0-25	1.7
1 hour								
11170052	HY-LED CT-Naveo OA 1HR IP65	220-240 AC 50Hz	1 x LED 7W	1000	15 / 7	1	0-25	1.7
11170042	HY-LED CT-Naveo ESC 1HR IP65	220-240 AC 50Hz	1 x LED 7W	1000	15 / 7	1	0-25	1.7
11170050	HY-LED Self-Test OA 1HR IP65	220-240 AC 50Hz	1 x LED 7W	1000	15 / 7	1	0-25	1.7
11170040	HY-LED Self-Test ESC 1HR IP65	220-240 AC 50Hz	1 x LED 7W	1000	15 / 7	1	0-25	1.7
Central battery (230V)								
HY1LA2HF	HY-LED 230V50HZ HF OA PC IP65	220-240 AC/DC 0-60Hz	1 x LED 7W	1000	15.5 / 14	230V	0-40	1.7
HY1LA2LTC	HY-LED 230V50HZ LTC OA PC IP65	220-240 AC 50/60Hz	1 x LED 7W	1000	15.5 / 14	230V	0-40	1.7
HY1LE2HF	HY-LED 230V50HZ HF ESC PC IP65	220-240 AC/DC 0-60Hz	1 x LED 7W	1000	15.5 / 14	230V	0-40	1.7
HY1LE2LTC	HY-LED 230V50HZ LTC ESC PC IP65	220-240 AC 50/60Hz	1 x LED 7W	1000	15.5 / 14	230V	0-40	1.7

60 hrs charge at first commissioning, 24 hrs re-charge thereafter.

Accessories

Order code	Description
HY-MBK	Wall mounting/coupling bracket kit
HY-RKIT	Recessing kit

