

## Zenit - ABB i-bus® KNX

### Push switch sensors

| Product                                                                           | Article-No.                                                                                                                                                                                                                                                                                                     | Order-No.       | Pack/Qty |
|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------|----------|
|  | <b>KNX sensor - 1/2-gang - 1M</b> <span style="color: red; font-weight: bold;">NEW</span><br>Push switch function: switching, dimming, blind or scene.<br>Display elements: LED to indicate the function.<br>To be installed with N2121, N2121.1, N2121.3, N2121.5, N2121.8, N2121.9 or N21 customized rockers. |                 |          |
|                                                                                   | RS/U 1.1                                                                                                                                                                                                                                                                                                        | 2CSY244490R1012 | 1        |

|                                                                                   |                                                                                                                                                                                                                                                                                                                 |                 |   |
|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------|---|
|  | <b>KNX sensor - 2/4-gang - 2M</b> <span style="color: red; font-weight: bold;">NEW</span><br>Push switch function: switching, dimming, blind or scene.<br>Display elements: LED to indicate the function.<br>To be installed with N2121, N2121.1, N2121.3, N2121.5, N2121.8, N2121.9 or N21 customized rockers. |                 |   |
|                                                                                   | RS/U 2.1                                                                                                                                                                                                                                                                                                        | 2CSY247450R1003 | 1 |

### Push switch sensor & switch actuators

|                                                                                     |                                                                                                                                                                                                                                                                                                                                                                                                |                 |   |
|-------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------|---|
|  | <b>KNX sensor/switch actuator - 2/1-gang - 2M</b> <span style="color: red; font-weight: bold;">NEW</span><br>Push switch function: switching, dimming, blind or scene.<br>Display elements: LED to indicate the function.<br>Outputs: 1x potential free contact.<br>Rated current: 16 A.<br>To be installed with N2121, N2121.1, N2121.3, N2121.5, N2121.8, N2121.9 or N21 customized rockers. |                 |   |
|                                                                                     | RA/U 1.16.1                                                                                                                                                                                                                                                                                                                                                                                    | 2CSY249580R1103 | 1 |

|                                                                                     |                                                                                                                                                                                                                                                                                                                                                                                                |                 |   |
|-------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------|---|
|  | <b>KNX sensor/switch actuator - 2/2-gang - 2M</b> <span style="color: red; font-weight: bold;">NEW</span><br>Push switch function: switching, dimming, blind or scene.<br>Display elements: LED to indicate the function.<br>Outputs: 2x potential free contacts.<br>Rated current: 8 A.<br>To be installed with N2121, N2121.1, N2121.3, N2121.5, N2121.8, N2121.9 or N21 customized rockers. |                 |   |
|                                                                                     | RA/U 2.8.1                                                                                                                                                                                                                                                                                                                                                                                     | 2CSY242150R1106 | 1 |

### Push switch sensor & blind actuators

|                                                                                     |                                                                                                                                                                                                                                                                                                                                                                                                           |                 |   |
|-------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------|---|
|  | <b>KNX sensor/blind actuator - 1/1-gang - 2M</b> <span style="color: red; font-weight: bold;">NEW</span><br>Push switch function: switching, dimming, blind or scene.<br>Display elements: LED to indicate the function.<br>Outputs: 1x change-over contacts/potential-bound<br>Rated current: 8 A.<br>To be installed with N2221, N2221.1, N2221.3, N2221.5, N2221.8, N2221.9 or N22 customized rockers. |                 |   |
|                                                                                     | RB/U 1.1                                                                                                                                                                                                                                                                                                                                                                                                  | 2CSY247240R1105 | 1 |

### Rockers for push switch sensors

| Product                                                                           | Article-No.                                                                                         | Order-No.       | Pack/Qty        |    |
|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------|-----------------|-----------------|----|
|  | <b>Rocker cover without symbol - 1M</b>                                                             |                 |                 |    |
|                                                                                   | Rocker cover without symbol for KNX sensor/actuator.                                                |                 |                 |    |
|                                                                                   | Suitable for codes: RS/U 1.1 and left and right positions of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1. |                 |                 |    |
|                                                                                   | White                                                                                               | <b>N2121 BL</b> | 2CLA212100N1101 | 10 |
|                                                                                   | Silver                                                                                              | <b>N2121 PL</b> | 2CLA212100N1301 | 10 |
|                                                                                   | Anthracite                                                                                          | <b>N2121 AN</b> | 2CLA212100N1801 | 10 |
|                                                                                   | Champagne                                                                                           | <b>N2121 CV</b> | 2CLA212100N1901 | 10 |
| Total White                                                                       | <b>N2121 BB</b>                                                                                     | 2CLA212100N1201 | 10              |    |
| Total Anthracite                                                                  | <b>N2121 AA</b>                                                                                     | 2CLA212100N1601 | 10              |    |



**Rocker cover without symbol - 2M**  
Rocker cover without symbol for KNX  
sensor/actuator.  
Suitable for codes: RB/U 1.1.

NEW

|                  |                 |                 |    |
|------------------|-----------------|-----------------|----|
| White            | <b>N2221 BL</b> | 2CLA222100N1101 | 10 |
| Silver           | <b>N2221 PL</b> | 2CLA222100N1301 | 10 |
| Anthracite       | <b>N2221 AN</b> | 2CLA222100N1801 | 10 |
| Champagne        | <b>N2221 CV</b> | 2CLA222100N1901 | 10 |
| Total White      | <b>N2221 BB</b> | 2CLA222100N1201 | 10 |
| Total Anthracite | <b>N2221 AA</b> | 2CLA222100N1601 | 10 |

## Zenit - ABB i-bus® KNX

### Rockers for push switch sensors

| Color | Article-No. | Order-No. | Pack/Qty |
|-------|-------------|-----------|----------|
|-------|-------------|-----------|----------|



#### Rocker cover with lamp symbol - 1M

Rocker cover with lamp symbol for KNX sensor/actuator.  
Suitable for codes: RS/U 1.1 and left position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2121.1 BL</b> | 2CLA212110N1101 | 10 |
| Silver           | <b>N2121.1 PL</b> | 2CLA212110N1301 | 10 |
| Anthracite       | <b>N2121.1 AN</b> | 2CLA212110N1801 | 10 |
| Champagne        | <b>N2121.1 CV</b> | 2CLA212110N1901 | 10 |
| Total White      | <b>N2121.1 BB</b> | 2CLA212110N1201 | 10 |
| Total Anthracite | <b>N2121.1 AA</b> | 2CLA212110N1601 | 10 |



#### Rocker cover with lamp symbol - Right - 1M

Rocker cover with lamp symbol for KNX sensor/actuator.  
Suitable for codes: right position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1.

NEW

|                  |                    |                 |    |
|------------------|--------------------|-----------------|----|
| White            | <b>N2121.1R BL</b> | 2CLA212112N1101 | 10 |
| Silver           | <b>N2121.1R PL</b> | 2CLA212112N1301 | 10 |
| Anthracite       | <b>N2121.1R AN</b> | 2CLA212112N1801 | 10 |
| Champagne        | <b>N2121.1R CV</b> | 2CLA212112N1901 | 10 |
| Total White      | <b>N2121.1R BB</b> | 2CLA212112N1201 | 10 |
| Total Anthracite | <b>N2121.1R AA</b> | 2CLA212112N1601 | 10 |



#### Rocker cover with lamp symbol - 2M

Rocker cover with lamp symbol for KNX sensor/actuator.  
Suitable for codes: RB/U 1.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2221.1 BL</b> | 2CLA222110N1101 | 10 |
| Silver           | <b>N2221.1 PL</b> | 2CLA222110N1301 | 10 |
| Anthracite       | <b>N2221.1 AN</b> | 2CLA222110N1801 | 10 |
| Champagne        | <b>N2221.1 CV</b> | 2CLA222110N1901 | 10 |
| Total White      | <b>N2221.1 BB</b> | 2CLA222110N1201 | 10 |
| Total Anthracite | <b>N2221.1 AA</b> | 2CLA222110N1601 | 10 |

| Color | Article-No. | Order-No. | Pack/Qty |
|-------|-------------|-----------|----------|
|-------|-------------|-----------|----------|



#### Rocker cover with blind symbol - 1M

Rocker cover with blind symbol for KNX sensor/actuator.  
Suitable for codes: RS/U 1.1 and left and right positions of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2121.3 BL</b> | 2CLA212130N1101 | 10 |
| Silver           | <b>N2121.3 PL</b> | 2CLA212130N1301 | 10 |
| Anthracite       | <b>N2121.3 AN</b> | 2CLA212130N1801 | 10 |
| Champagne        | <b>N2121.3 CV</b> | 2CLA212130N1901 | 10 |
| Total White      | <b>N2121.3 BB</b> | 2CLA212130N1201 | 10 |
| Total Anthracite | <b>N2121.3 AA</b> | 2CLA212130N1601 | 10 |



#### Rocker cover with blind symbol - 2M

Rocker cover with blind symbol for KNX sensor/actuator.  
Suitable for codes: RB/U 1.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2221.3 BL</b> | 2CLA222130N1101 | 10 |
| Silver           | <b>N2221.3 PL</b> | 2CLA222130N1301 | 10 |
| Anthracite       | <b>N2221.3 AN</b> | 2CLA222130N1801 | 10 |
| Champagne        | <b>N2221.3 CV</b> | 2CLA222130N1901 | 10 |
| Total White      | <b>N2221.3 BB</b> | 2CLA222130N1201 | 10 |
| Total Anthracite | <b>N2221.3 AA</b> | 2CLA222130N1601 | 10 |

## Zenit - ABB i-bus® KNX

### Rockers for push switch sensors

| Color | Article-No. | Order-No. | Pack/Qty |
|-------|-------------|-----------|----------|
|-------|-------------|-----------|----------|



**Rocker cover with ON/OFF symbol - 1M**  
Rocker cover with ON/OFF symbol for KNX sensor/actuator.  
Suitable for codes: RS/U 1.1 and left position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2121.5 BL</b> | 2CLA212150N1101 | 10 |
| Silver           | <b>N2121.5 PL</b> | 2CLA212150N1301 | 10 |
| Anthracite       | <b>N2121.5 AN</b> | 2CLA212150N1801 | 10 |
| Champagne        | <b>N2121.5 CV</b> | 2CLA212150N1901 | 10 |
| Total White      | <b>N2121.5 BB</b> | 2CLA212150N1201 | 10 |
| Total Anthracite | <b>N2121.5 AA</b> | 2CLA212150N1601 | 10 |



**Rocker cover with ON/OFF symbol - Right - 1M**  
Rocker cover with ON/OFF symbol for KNX sensor/actuator.  
Suitable for codes: right position of RS/U 2.1, RA/U1.16.1 and RA/U/ 2.8.1.

NEW

|                  |                    |                 |    |
|------------------|--------------------|-----------------|----|
| White            | <b>N2121.5R BL</b> | 2CLA212152N1101 | 10 |
| Silver           | <b>N2121.5R PL</b> | 2CLA212152N1301 | 10 |
| Anthracite       | <b>N2121.5R AN</b> | 2CLA212152N1801 | 10 |
| Champagne        | <b>N2121.5R CV</b> | 2CLA212152N1901 | 10 |
| Total White      | <b>N2121.5R BB</b> | 2CLA212152N1201 | 10 |
| Total Anthracite | <b>N2121.5R AA</b> | 2CLA212152N1601 | 10 |



**Rocker cover with ON/OFF symbol - 2M**  
Rocker cover with ON/OFF symbol for KNX sensor/actuator.  
Suitable for codes: RB/U 1.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2221.5 BL</b> | 2CLA222150N1101 | 10 |
| Silver           | <b>N2221.5 PL</b> | 2CLA222150N1301 | 10 |
| Anthracite       | <b>N2221.5 AN</b> | 2CLA222150N1801 | 10 |
| Champagne        | <b>N2221.5 CV</b> | 2CLA222150N1901 | 10 |
| Total White      | <b>N2221.5 BB</b> | 2CLA222150N1201 | 10 |
| Total Anthracite | <b>N2221.5 AA</b> | 2CLA222150N1601 | 10 |

| Color | Article-No. | Order-No. | Pack/Qty |
|-------|-------------|-----------|----------|
|-------|-------------|-----------|----------|



**Rocker cover with dimmer symbol - 1M**  
Rocker cover with dimmer symbol for KNX sensor/actuator.  
Suitable for codes: RS/U 1.1 and left position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2121.8 BL</b> | 2CLA212180N1101 | 10 |
| Silver           | <b>N2121.8 PL</b> | 2CLA212180N1301 | 10 |
| Anthracite       | <b>N2121.8 AN</b> | 2CLA212180N1801 | 10 |
| Champagne        | <b>N2121.8 CV</b> | 2CLA212180N1901 | 10 |
| Total White      | <b>N2121.8 BB</b> | 2CLA212180N1201 | 10 |
| Total Anthracite | <b>N2121.8 AA</b> | 2CLA212180N1601 | 10 |



**Rocker cover with dimmer symbol - Right - 1M**  
Rocker cover with dimmer symbol for KNX sensor/actuator.  
Suitable for codes: right position of RS/U 2.1, RA/U1.16.1 and RA/U/ 2.8.1.

NEW

|                  |                    |                 |    |
|------------------|--------------------|-----------------|----|
| White            | <b>N2121.8R BL</b> | 2CLA212182N1101 | 10 |
| Silver           | <b>N2121.8R PL</b> | 2CLA212182N1301 | 10 |
| Anthracite       | <b>N2121.8R AN</b> | 2CLA212182N1801 | 10 |
| Champagne        | <b>N2121.8R CV</b> | 2CLA212182N1901 | 10 |
| Total White      | <b>N2121.8R BB</b> | 2CLA212182N1201 | 10 |
| Total Anthracite | <b>N2121.8R AA</b> | 2CLA212182N1601 | 10 |



**Rocker cover with dimmer symbol - 2M**  
Rocker cover with dimmer symbol for KNX sensor/actuator.  
Suitable for codes: RB/U 1.1.

NEW

|                  |                   |                 |    |
|------------------|-------------------|-----------------|----|
| White            | <b>N2221.8 BL</b> | 2CLA222180N1101 | 10 |
| Silver           | <b>N2221.8 PL</b> | 2CLA222180N1301 | 10 |
| Anthracite       | <b>N2221.8 AN</b> | 2CLA222180N1801 | 10 |
| Champagne        | <b>N2221.8 CV</b> | 2CLA222180N1901 | 10 |
| Total White      | <b>N2221.8 BB</b> | 2CLA222180N1201 | 10 |
| Total Anthracite | <b>N2221.8 AA</b> | 2CLA222180N1601 | 10 |

## Zenit - ABB i-bus® KNX

### Rockers for push switch sensors

| Color                                                                                                                                                                                                                                                                                                                                       | Article-No.        | Order-No.       | Pack/Qty |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------|-----------------|----------|
|  <b>Rocker cover with scene symbol - 1M</b><br>Rocker cover with scene symbol for KNX sensor/actuator.<br>Suitable for codes: RS/U 1.1 and left position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1. <span style="color: red; font-weight: bold;">NEW</span> |                    |                 |          |
| White                                                                                                                                                                                                                                                                                                                                       | <b>N2121.9 BL</b>  | 2CLA212190N1101 | 10       |
| Silver                                                                                                                                                                                                                                                                                                                                      | <b>N2121.9 PL</b>  | 2CLA212190N1301 | 10       |
| Anthracite                                                                                                                                                                                                                                                                                                                                  | <b>N2121.9 AN</b>  | 2CLA212190N1801 | 10       |
| Champagne                                                                                                                                                                                                                                                                                                                                   | <b>N2121.9 CV</b>  | 2CLA212190N1901 | 10       |
| Total White                                                                                                                                                                                                                                                                                                                                 | <b>N2121.9 BB</b>  | 2CLA212190N1201 | 10       |
| Total Anthracite                                                                                                                                                                                                                                                                                                                            | <b>N2121.9 AA</b>  | 2CLA212190N1601 | 10       |
|  <b>Rocker cover with scene symbol - Right - 1M</b><br>Rocker cover with scene symbol for KNX sensor/actuator.<br>Suitable for codes: right position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1. <span style="color: red; font-weight: bold;">NEW</span>     |                    |                 |          |
| White                                                                                                                                                                                                                                                                                                                                       | <b>N2121.9R BL</b> | 2CLA212192N1101 | 10       |
| Silver                                                                                                                                                                                                                                                                                                                                      | <b>N2121.9R PL</b> | 2CLA212192N1301 | 10       |
| Anthracite                                                                                                                                                                                                                                                                                                                                  | <b>N2121.9R AN</b> | 2CLA212192N1801 | 10       |
| Champagne                                                                                                                                                                                                                                                                                                                                   | <b>N2121.9R CV</b> | 2CLA212192N1901 | 10       |
| Total White                                                                                                                                                                                                                                                                                                                                 | <b>N2121.9R BB</b> | 2CLA212192N1201 | 10       |
| Total Anthracite                                                                                                                                                                                                                                                                                                                            | <b>N2121.9R AA</b> | 2CLA212192N1601 | 10       |
|  <b>Rocker cover with scene symbol - 2M</b><br>Rocker cover with scene symbol for KNX sensor/actuator.<br>Suitable for codes: RB/U 1.1. <span style="color: red; font-weight: bold;">NEW</span>                                                          |                    |                 |          |
| White                                                                                                                                                                                                                                                                                                                                       | <b>N2221.9 BL</b>  | 2CLA222190N1101 | 10       |
| Silver                                                                                                                                                                                                                                                                                                                                      | <b>N2221.9 PL</b>  | 2CLA222190N1301 | 10       |
| Anthracite                                                                                                                                                                                                                                                                                                                                  | <b>N2221.9 AN</b>  | 2CLA222190N1801 | 10       |
| Champagne                                                                                                                                                                                                                                                                                                                                   | <b>N2221.9 CV</b>  | 2CLA222190N1901 | 10       |
| Total White                                                                                                                                                                                                                                                                                                                                 | <b>N2221.9 BB</b>  | 2CLA222190N1201 | 10       |
| Total Anthracite                                                                                                                                                                                                                                                                                                                            | <b>N2221.9 AA</b>  | 2CLA222190N1601 | 10       |

### Customized rockers

| Color                                                                                                                                                                                                                                                                                                                                                                       | Article-No.        | Order-No.       | Pack/Qty |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------|-----------------|----------|
|  <b>Rocker cover with custom symbol - 1M</b><br>Rocker cover with custom symbol for KNX sensor/actuator.<br>Symbol size: 5,6 x 5,6 mm.<br>Suitable for codes: RS/U 1.1 and left position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1. <span style="color: red; font-weight: bold;">NEW</span> |                    |                 |          |
| White                                                                                                                                                                                                                                                                                                                                                                       | <b>N2121.01 BL</b> | 2CLA212101N1101 | 10       |
| Silver                                                                                                                                                                                                                                                                                                                                                                      | <b>N2121.01 PL</b> | 2CLA212101N1301 | 10       |
| Anthracite                                                                                                                                                                                                                                                                                                                                                                  | <b>N2121.01 AN</b> | 2CLA212101N1801 | 10       |
| Champagne                                                                                                                                                                                                                                                                                                                                                                   | <b>N2121.01 CV</b> | 2CLA212101N1901 | 10       |
| Total White                                                                                                                                                                                                                                                                                                                                                                 | <b>N2121.01 BB</b> | 2CLA212101N1201 | 10       |
| Total Anthracite                                                                                                                                                                                                                                                                                                                                                            | <b>N2121.01 AA</b> | 2CLA212101N1601 | 10       |
|  <b>Rocker cover with custom symbol - Right - 1M</b><br>Rocker cover with custom symbol for KNX sensor/actuator.<br>Symbol size: 5,6 x 5,6 mm.<br>Suitable for codes: right position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1. <span style="color: red; font-weight: bold;">NEW</span>     |                    |                 |          |
| White                                                                                                                                                                                                                                                                                                                                                                       | <b>N2121.02 BL</b> | 2CLA212102N1101 | 10       |
| Silver                                                                                                                                                                                                                                                                                                                                                                      | <b>N2121.02 PL</b> | 2CLA212102N1301 | 10       |
| Anthracite                                                                                                                                                                                                                                                                                                                                                                  | <b>N2121.02 AN</b> | 2CLA212102N1801 | 10       |
| Champagne                                                                                                                                                                                                                                                                                                                                                                   | <b>N2121.02 CV</b> | 2CLA212102N1901 | 10       |
| Total White                                                                                                                                                                                                                                                                                                                                                                 | <b>N2121.02 BB</b> | 2CLA212102N1201 | 10       |
| Total Anthracite                                                                                                                                                                                                                                                                                                                                                            | <b>N2121.02 AA</b> | 2CLA212102N1601 | 10       |
|  <b>Rocker cover with custom symbol - 2M</b><br>Rocker cover with custom symbol for KNX sensor/actuator.<br>Symbol size: 5,6 x 5,6 mm<br>Suitable for codes: RB/U 1.1. <span style="color: red; font-weight: bold;">NEW</span>                                                           |                    |                 |          |
| White                                                                                                                                                                                                                                                                                                                                                                       | <b>N2221.01 BL</b> | 2CLA222101N1101 | 10       |
| Silver                                                                                                                                                                                                                                                                                                                                                                      | <b>N2221.01 PL</b> | 2CLA222101N1301 | 10       |
| Anthracite                                                                                                                                                                                                                                                                                                                                                                  | <b>N2221.01 AN</b> | 2CLA222101N1801 | 10       |
| Champagne                                                                                                                                                                                                                                                                                                                                                                   | <b>N2221.01 CV</b> | 2CLA222101N1901 | 10       |
| Total White                                                                                                                                                                                                                                                                                                                                                                 | <b>N2221.01 BB</b> | 2CLA222101N1201 | 10       |
| Total Anthracite                                                                                                                                                                                                                                                                                                                                                            | <b>N2221.01 AA</b> | 2CLA222101N1601 | 10       |


## Zenit - ABB i-bus® KNX

### ID number definition

Customized rockers for RS/U 1.1 and left position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1:



Customized rockers for right position of RS/U 2.1, RA/U 1.16.1 and RA/U/ 2.8.1:

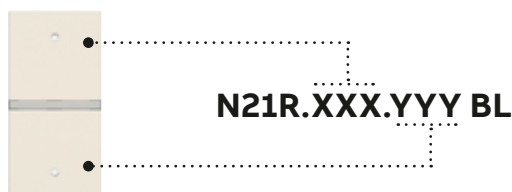

Customized rockers for right position of RS/U 1.1:



To define the ID Number of the customized rocker:

- 1) Substitute XXX by 3-digit Symbol Number of the icon to print at the upper side of the rocker
- 2) Substitute YYY by 3-digit Symbol Number of the icon to print at the lower side of the rocker

### Symbols

| Symbol | Symbol-No.                  | Symbol | Symbol-No.                  | Symbol | Symbol-No.                |
|--------|-----------------------------|--------|-----------------------------|--------|---------------------------|
|        | 000<br>No symbol            |        | 019<br>Jalousie mid         |        | 038<br>Eco plane          |
|        | 001<br>Light on             |        | 020<br>Jalousie closed      |        | 039<br>Fan                |
|        | 002<br>Light off            |        | 021<br>Hang open            |        | 040<br>Heat protection    |
|        | 003<br>Light on detail      |        | 022<br>Hang mid             |        | 041<br>Scene line         |
|        | 004<br>Lamp plane           |        | 023<br>Hang closed          |        | 042<br>Scene plane        |
|        | 005<br>Lamp line            |        | 024<br>Blind open           |        | 043<br>Sequence           |
|        | 006<br>Lamp ceiling plane   |        | 025<br>Blind mid            |        | 044<br>Scene day          |
|        | 007<br>Lamp wall plane      |        | 026<br>Blind closed         |        | 045<br>Night plane        |
|        | 008<br>Lamp floor plane     |        | 027<br>Curtain open         |        | 046<br>Scene night        |
|        | 009<br>Dim                  |        | 028<br>Curtain closed       |        | 047<br>Party              |
|        | 010<br>Light dimmed         |        | 029<br>Heating              |        | 048<br>Dinner plane       |
|        | 011<br>Light increase       |        | 030<br>Cooling              |        | 049<br>Eat                |
|        | 012<br>Light decrease       |        | 031<br>Antifreeze           |        | 050<br>Absence line       |
|        | 013<br>Light incr./decrease |        | 032<br>Temperature increase |        | 051<br>Presence home      |
|        | 014<br>Spotlight            |        | 033<br>Temperature decrease |        | 052<br>Reading            |
|        | 015<br>Spotlight plane      |        | 034<br>Temperature control  |        | 053<br>TV                 |
|        | 016<br>Door                 |        | 035<br>Temperature c        |        | 054<br>Make Up Room (MUR) |
|        | 017<br>Window               |        | 036<br>Temperature f        |        | 055<br>Conference         |
|        | 017<br>Jalousie open        |        | 037<br>Eco                  |        | 056<br>Presentation       |

## Zenit - ABB i-bus® KNX

### Symbols

| Symbol | Symbol-No.                         | Symbol | Symbol-No.                        | Symbol | Symbol-No.                     | Symbol | Symbol-No.                      | Symbol | Symbol-No.                 |
|--------|------------------------------------|--------|-----------------------------------|--------|--------------------------------|--------|---------------------------------|--------|----------------------------|
|        | <b>057</b><br>Emergency call       |        | <b>076</b><br>On                  |        | <b>095</b><br>First aid        |        | <b>114</b><br>Skip forward      |        | <b>133</b><br>Left         |
|        | <b>058</b><br>Exterior lighting    |        | <b>077</b><br>Off                 |        | <b>096</b><br>Defibrillator    |        | <b>115</b><br>Speaker           |        | <b>134</b><br>Up filled    |
|        | <b>059</b><br>Bowling              |        | <b>078</b><br>Cardreader          |        | <b>097</b><br>Doctor           |        | <b>116</b><br>Speaker off       |        | <b>135</b><br>Down filled  |
|        | <b>060</b><br>Swimming             |        | <b>079</b><br>Bathroom            |        | <b>098</b><br>Pharmacy RX      |        | <b>117</b><br>Channel           |        | <b>136</b><br>Right filled |
|        | <b>061</b><br>Reception            |        | <b>080</b><br>Laundry             |        | <b>099</b><br>Pharmacy Germany |        | <b>118</b><br>Stepwise increase |        | <b>137</b><br>Left filled  |
|        | <b>062</b><br>Showroom             |        | <b>081</b><br>Shave               |        | <b>100</b><br>Mail             |        | <b>119</b><br>Stepwise decrease |        | <b>138</b><br>Up line      |
|        | <b>063</b><br>Relax                |        | <b>082</b><br>Coffee              |        | <b>101</b><br>Message center   |        | <b>120</b><br>Info              |        | <b>139</b><br>Down line    |
|        | <b>064</b><br>Work                 |        | <b>083</b><br>Wellness            |        | <b>102</b><br>Call             |        | <b>121</b><br>Device on         |        | <b>140</b><br>Right line   |
|        | <b>065</b><br>Do Not Disturb (DND) |        | <b>084</b><br>Cloakroom           |        | <b>103</b><br>Micro            |        | <b>122</b><br>Device dimmed     |        | <b>141</b><br>Left line    |
|        | <b>066</b><br>Scene welcome        |        | <b>085</b><br>Wlan                |        | <b>104</b><br>Micro off        |        | <b>123</b><br>Device off        |        | <b>142</b><br>Up step      |
|        | <b>067</b><br>Dishwasher           |        | <b>086</b><br>Caretaker           |        | <b>105</b><br>Intercom inside  |        | <b>124</b><br>Settings          |        | <b>143</b><br>Down step    |
|        | <b>068</b><br>Hob                  |        | <b>087</b><br>Parking garage      |        | <b>106</b><br>Intercom outside |        | <b>125</b><br>Menu              |        | <b>144</b><br>Clock        |
|        | <b>069</b><br>Microwave            |        | <b>088</b><br>Lift                |        | <b>107</b><br>Audio            |        | <b>126</b><br>Active            |        | <b>145</b><br>Timer        |
|        | <b>070</b><br>Oven                 |        | <b>089</b><br>Stairs              |        | <b>108</b><br>Play             |        | <b>127</b><br>Plus              |        | <b>146</b><br>Alarm clock  |
|        | <b>071</b><br>Washing-machine      |        | <b>090</b><br>Lavatory            |        | <b>109</b><br>Pause            |        | <b>128</b><br>Minus             |        | <b>147</b><br>Bell off     |
|        | <b>072</b><br>Open plane           |        | <b>091</b><br>Lavatory men        |        | <b>110</b><br>Stop             |        | <b>129</b><br>Language          |        | <b>148</b><br>Bell         |
|        | <b>073</b><br>Outlet line          |        | <b>092</b><br>Lavatory ladies     |        | <b>111</b><br>Backwards        |        | <b>130</b><br>Up                |        | <b>149</b><br>Snapshot     |
|        | <b>074</b><br>Camera extern        |        | <b>093</b><br>Baby change         |        | <b>112</b><br>Forward          |        | <b>131</b><br>Down              |        | <b>150</b><br>Guard        |
|        | <b>075</b><br>On off               |        | <b>094</b><br>Disabled facilities |        | <b>113</b><br>Skip back        |        | <b>132</b><br>Right             |        | <b>151</b><br>Charge car   |
|        |                                    |        |                                   |        |                                |        |                                 |        |                            |

## Zenit - ABB i-bus® KNX

### Push-button sensors

| Product                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                     | Article-No.        | Order-No.       | Pack/Qty |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------|-----------------|----------|
|  <p><b>KNX sensor - 1/2-gang - 2M</b><br/>Push button function: switching / dimming / blind / sending values / scenes etc.<br/>Incl. 10 logic channels (light scene actuator, sequence actuator, logic gates, etc.).<br/>The accompanying symbol can be replaced by the symbols for lighting, blinds, room thermostat, scene and fan-coil.<br/>Control element: Switch contacts.<br/>Display elements: LED to indicate the function.<br/>To be installed with N2221.2 cover plates.</p>                    | <b>6125/98-509</b> | 2CKA006115A0444 | 1        |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |                    |                 |          |
|  <p><b>KNX sensor - 2/4-gang - 2M</b><br/>Push button function: switching / dimming / blind / sending values / scenes etc.<br/>Incl. 10 logic channels (light scene actuator, sequence actuator, logic gates, etc.).<br/>The accompanying symbol can be replaced by the symbols for lighting, blinds, room thermostat, scene and fan-coil.<br/>Control element: Switch contacts.<br/>Display elements: LED to indicate the function.<br/>To be installed with N2221.4 cover plates.</p>                    | <b>6126/98-509</b> | 2CKA006116A0219 | 1        |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |                    |                 |          |
|  <p><b>KNX sensor - 3/6-gang - 2M</b><br/>Push button function: switching / dimming / blind / sending values / scenes etc.<br/>Incl. 10 logic channels (light scene actuator, sequence actuator, logic gates, etc.).<br/>The accompanying symbol can be replaced by the symbols for lighting, blinds, room thermostat, scene and fan-coil.<br/>Control element: Switch contacts.<br/>Display elements: LED to indicate the function.<br/>To be installed with N2221.6 cover plates.</p>                  | <b>6129/96-509</b> | 2CKA006118A0105 | 1        |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |                    |                 |          |
|  <p><b>KNX sensor - 3/6-gang with IR receiver - 2M</b><br/>Push button function: switching / dimming / blind / sending values / scenes etc.<br/>Incl. 10 logic channels (light scene actuator, sequence actuator, logic gates, etc.).<br/>The accompanying symbol can be replaced by the symbols for lighting, blinds, room thermostat, scene and fan-coil.<br/>Control element: Switch contacts.<br/>Display elements: LED to indicate the function.<br/>To be installed with N2221.7 cover plates.</p> | <b>6129/96-509</b> | 2CKA006118A0108 | 1        |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |                    |                 |          |

### Covers for sensors

| Color                                                                                                                                                                                                                                                                              | Article-No.        | Order-No.       | Pack/Qty |
|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------|-----------------|----------|
| <div></div> <div><b>Cover plate - KNX 1/2-gang sensors - 2M</b><br/>Cover plate for KNX sensors 1/2-gang code: 6125/98-509.</div>                                                                 |                    |                 |          |
| White                                                                                                                                                                                                                                                                              | <b>N2221.2 BL</b>  | 2CLA222120N1101 | 1        |
| Silver                                                                                                                                                                                                                                                                             | <b>N2221.2 PL</b>  | 2CLA222120N1301 | 1        |
| Anthracite                                                                                                                                                                                                                                                                         | <b>N2221.2 AN</b>  | 2CLA222120N1801 | 1        |
| Champagne                                                                                                                                                                                                                                                                          | <b>N2221.2 CV</b>  | 2CLA222120N190  | 1        |
| <div></div> <div><b>Cover plate - KNX 2/4-gang sensors - 2M</b><br/>Cover plate for KNX sensors 2/4-gang code: 6126/98-509.</div>                                                                 |                    |                 |          |
| White                                                                                                                                                                                                                                                                              | <b>N2221.4 BL</b>  | 2CLA222140N1101 | 1        |
| Silver                                                                                                                                                                                                                                                                             | <b>N2221.4 PL</b>  | 2CLA222140N1301 | 1        |
| Anthracite                                                                                                                                                                                                                                                                         | <b>N2221.4 AN</b>  | 2CLA222140N1801 | 1        |
| Champagne                                                                                                                                                                                                                                                                          | <b>N2221.4 CV</b>  | 2CLA222140N1901 | 1        |
| <div></div> <div><b>Cover plate - KNX 3-gang sensors - 2M</b><br/>Cover plate for KNX sensors 3/6-gang code: 6129/96-509.</div>                                                                 |                    |                 |          |
| White                                                                                                                                                                                                                                                                              | <b>N2221.6 BL</b>  | 2CLA222160N1101 | 1        |
| Silver                                                                                                                                                                                                                                                                             | <b>N2221.6 PL</b>  | 2CLA222170N1301 | 1        |
| Anthracite                                                                                                                                                                                                                                                                         | <b>N2221.6 AN</b>  | 2CLA222170N1801 | 1        |
| Champagne                                                                                                                                                                                                                                                                          | <b>N2221.6 CV</b>  | 2CLA222170N1901 | 1        |
| <div></div> <div><b>Cover plate - KNX 3-gang sensors - 2M</b><br/>Cover plate for KNX sensors 3/6-gang code: 6129/96-509.</div>                                                                 |                    |                 |          |
| White                                                                                                                                                                                                                                                                              | <b>N2221.7 BL</b>  | 2CLA222170N1101 | 1        |
| Silver                                                                                                                                                                                                                                                                             | <b>N2221.7 PL</b>  | 2CKA006123A0001 | 1        |
| Anthracite                                                                                                                                                                                                                                                                         | <b>N2221.7 AN</b>  | 2CLA222160N1801 | 1        |
| Champagne                                                                                                                                                                                                                                                                          | <b>N2221.7 CV</b>  | 2CLA222160N1901 | 1        |
| <div></div> <div><b>KNX button with symbol</b><br/><b>Button with ABB i-bus® KNX symbol for sensor's cover plates code: N2221.2, N2221.4, N2221.6 and N2221.7.</b><br/><b>Color: gray</b></div> |                    |                 |          |
| Light                                                                                                                                                                                                                                                                              | <b>6123/20-500</b> | 2CKA006123A0001 | 1        |
| Blind                                                                                                                                                                                                                                                                              | <b>6123/21-500</b> | 2CKA006123A0002 | 1        |
| Scene                                                                                                                                                                                                                                                                              | <b>6123/22-500</b> | 2CKA006123A0003 | 1        |
| RTC                                                                                                                                                                                                                                                                                | <b>6123/23-500</b> | 2CKA006123A0004 | 1        |
| Lamp                                                                                                                                                                                                                                                                               | <b>6123/24-500</b> | 2CKA006123A0005 | 1        |
| Fan-coil                                                                                                                                                                                                                                                                           | <b>6123/26-500</b> | 2CKA006123A0006 | 1        |

## Zenit - ABB i-bus® KNX

### Room temperature controller

| Product | Article-No. | Order-No. | Pack/Qty |
|---------|-------------|-----------|----------|
|---------|-------------|-----------|----------|



#### KNX room temperature controller - 2M

For triggering the heating, ventilation and fan-coil actuators. Thermostat for fan-coil units in 2 and 4 pipe systems and conventional heating or cooling systems. Fan stage can be switched manually or in automatic mode. Switch contacts for operating mode selection and dial for setpoint or fan speed adjustment. Display elements: LCD showing operation modes. To be installed with N2240.4 cover plates.

|             |                 |   |
|-------------|-----------------|---|
| 6124/98-509 | 2CKA006134A0297 | 1 |
|-------------|-----------------|---|



#### Cover plate - KNX RTC - 2M

Cover plate for KNX RTC sensors code: 6124/98-509.

|            |                   |                 |   |
|------------|-------------------|-----------------|---|
| White      | <b>N2240.4 BL</b> | 2CLA224040N1101 | 1 |
| Silver     | <b>N2240.4 PL</b> | 2CLA224040N1301 | 1 |
| Anthracite | <b>N2240.4 AN</b> | 2CLA224040N1801 | 1 |
| Champagne  | <b>N2240.4 CV</b> | 2CLA224040N1901 | 1 |



#### KNX thermostat - 2M

Standard KNX thermostat equipped with backlight LCD display 4 push buttons on the front for the following functionalities (Operating mode switching, Fan-coil speed manual switching, set-point manual increment/decrement).

Possibility to choose different type of control: 2-point ON/OFF, PWM, Continue, Fan-coil  
Cover plate included.

**NEW**

|            |                    |                 |   |
|------------|--------------------|-----------------|---|
| White      | <b>RT/U 1.1.ZW</b> | 2CSY244280R1202 | 1 |
| Silver     | <b>RT/U 1.1.ZS</b> | 2CSY242280R1202 | 1 |
| Anthracite | <b>RT/U 1.1.ZA</b> | 2CSY249370R1202 | 1 |
| Champagne  | <b>RT/U 1.1.ZC</b> | 2CSY247370R1202 | 1 |

### Motion sensor

| Product | Article-No. | Order-No. | Pack/Qty |
|---------|-------------|-----------|----------|
|---------|-------------|-----------|----------|



#### KNX 180° motion sensor - 2M

Movement detector with up to 4 channels. Detection range: frontal: 6 m, lateral: 6 m. Brightness limit value: 5 - 150 lux. Detection angle: 180 °. Wall mounted. Mounting height: 1.1 m. To be installed with N2241.4 cover plates.

|             |                 |   |
|-------------|-----------------|---|
| 6122/98-509 | 2CKA006132A0307 | 1 |
|-------------|-----------------|---|



#### Cover plate - KNX RTC - 2M

Cover plate for KNX RTC sensors code: 6124/98-509.

|            |                   |                 |   |
|------------|-------------------|-----------------|---|
| White      | <b>N2241.4 BL</b> | 2CLA224140N1101 | 1 |
| Silver     | <b>N2241.4 PL</b> | 2CLA224140N1301 | 1 |
| Anthracite | <b>N2241.4 AN</b> | 2CLA224140N1801 | 1 |
| Champagne  | <b>N2241.4 CV</b> | 2CLA224140N1901 | 1 |