


On-load tap-changer type UBBL, 12 tap positions, linear switching.
 Max effective No. of turns in pos 1.
 The tap-changer is delivered set in pos 6.

Lindningskopplare typ UBBL, 12 lägen, linjär-koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 6.

Pos Läge	H connects förbinder
1	1 - 15
2	2 - 15
3	3 - 15
4	4 - 15
5	5 - 15
6	6 - 15
7	7 - 15
8	8 - 15
9	9 - 15
10	10 - 15
11	11 - 15
12	12 - 15

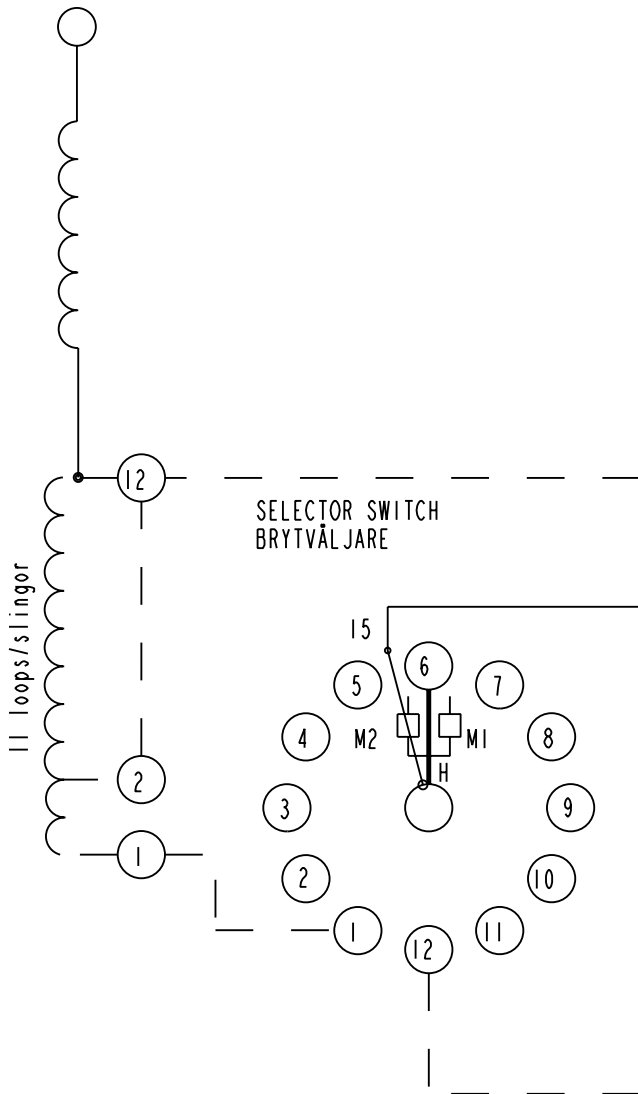

1) OUTPUT TERMINAL
STRÖMAVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Dashed lines show in delivery not included leads belonging to cleats and leads.

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktsutförande. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

H Main contact
Huvudkontakt
M1, M2 Transition contacts
Motståndskontakter

Rev	In	Revision	Appd	Year	Week
-	-				

Accepted by qual control	Accepted for prod by	Description (English)	DATAORIGINAL
R. Yngvesson		CONNECTION DIAGRAM UBBL	
Design checked by	Drawn by	Description (own language)	File name
B-O. Stenestam	L. Bergman	KOPPLINGSSCHEMA UBBL	0387-8
Drawing checked by	Issued by Dept	Year	Week
M. Hedlund	COM/TKO	97	32
ABB Asea Brown Boveri		5492 0387-8	Lang Sheet
			1
		RevIn	Cont
		-	-

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19

Sheet Cont
Year Week
Dept
RevIn
Design checked by
Form No.