


Horizon

Traditional & versatile



Edge-lit LED exit sign

- Choice of IP40 surface mount (OHD) or IP20 recessed (OZD)
- Shaped diffuser and contoured reflector
- First-Fix aluminium base with white polycarbonate luminaire body
- Legend panel with slotted aluminium frame
- Complies to IEC 60598.2.22

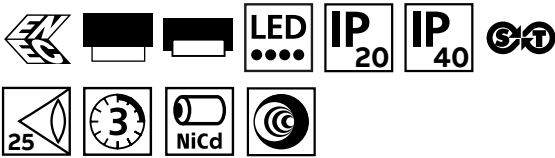


LED base unit

Order code	Description	Input voltage	Power Operation			Environment temp. (°C)	Weight (kg)
			Lamp type	consumption (VA/W)	/ duration (hrs)		
OZD3LS61V2	LEDS REC-EDGE SIGN M3 60HZ	220-240 AC 50/60Hz	2 x LED 2W	9.9 / 5.1	3	0-25	1.3
CTOHD3LS61	CT LEDS EDGE SIGH M3	220-240 AC 50Hz		9.9 / 5.1	3	0-25	1.3
CTOZD3LS61	CT LED REC-EDGE SIGN M3	220-240 AC 50Hz		9.9 / 5.1	3	0-25	1.3
OHD1LS61HF	LEDS EDGE SIGN 230VHF	220-240 AC/DC 0-60Hz		6.8 / 3.1	230V	0-40	1.1
OHD1LS61LTC	LEDS EDGE SIGN 230VLTC	220-240 AC 50/60Hz		6.8 / 3.1	230V	0-40	1.1
OHD3LS61	LEDS EDGE SIGN M3	220-240 AC 50Hz		9.9 / 5.1	3	0-25	1.3
OZD1LS61HF	LEDS REC-EDG SIGN 230HF	220-240 AC/DC 0-60Hz		6.8 / 3.1	230V	0-40	1.1
OZD1LS61LTC	LEDS REC-EDG SIGN 230LTC	220-240 AC 50/60Hz		6.8 / 3.1	230V	0-40	1.1
OZD3LS61	LEDS REC-EDGE SIGN M3	220-240 AC 50Hz		9.9 / 5.1	3	0-25	1.3

Legends

Single sided		Double sided	
Part No.	Pictogram	Part No.	Pictogram
XEN20HS		XEN22HD	
XEN30HS		XEN36HD	
XEN60HS		XEN55HD	
XEN50HS		ISO 7010 pictogram legends are shown. Euro format & Special legends are available to order see pages 139-141	
XLF802HS		For further information on Naveo®Pro and emergency luminaire testing formats, see pages 70-74	
XLF803HS			
Arabic legend format			
HB01HS			

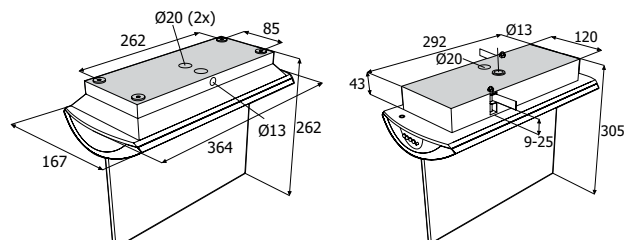

Accessories

Order code	Description
OH/BWM	Wall bracket for edge-lit sign/luminaire