


# FurseWELD

## Cable to steel surface & pipe CS3 & CS7

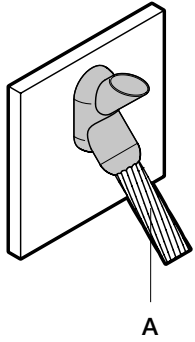


### Cable to steel surface & pipe CS3 - FurseWELD

| Stranded / solid circular conductor size A (mm <sup>2</sup> ) | Part no.         |                |              |            |                   |
|---|------------------|----------------|--------------|------------|-------------------|
|   | Powder cartridge | Standard mould | Handle clamp | Mini mould | Mini handle clamp |
| 16 *  | 45P10            | CS3-4-16       | HCPK4        | CS3-3-16   | HCPK3             |
| 25  | 45P10            | CS3-4-25       | HCPK4        | CS3-3-25   | HCPK3             |
| 35  | 45P10            | CS3-4-35       | HCPK4        | CS3-3-35   | HCPK3             |
| Ø 8   | 65P10            | CS3-4-8SC      | HCPK4        | CS3-3-8SC  | HCPK3             |
| 50  | 65P10            | CS3-4-50       | HCPK4        | CS3-3-50   | HCPK3             |
| Ø 10 m  | 90P10            | CS3-4-10SC     | HCPK4        | CS3-3-10SC | HCPK3             |
| 70  | 90P10            | CS3-4-70       | HCPK4        | CS3-3-70   | HCPK3             |
| 95  | 115P10           | CS3-4-95       | HCPK4        | CS3-3-95   | HCPK3             |
| 120   | 115P10           | CS3-4-120      | HCPK4        | CS3-3-120  | HCPK3             |
| 150   | 115P10           | CS3-4-150      | HCPK4        | CS3-3-150  | HCPK3             |
| 185   | 200P10           | CS3-4-185      | HCPK4        | -          | -                 |
| 240   | 200P10           | CS3-4-240      | HCPK4        | -          | -                 |
| 300   | 250P10           | CS3-4-300      | HCPK4        | -          | -                 |

Special moulds for all FurseWELD products can be manufactured to meet specific customer applications on request

\*1 x S103 Sleeve required when joining conductors 16 mm<sup>2</sup> or smaller

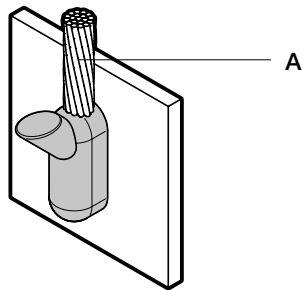

### Cable to steel surface & pipe CS7 - FurseWELD

| Stranded / solid circular conductor size A (mm <sup>2</sup> ) | Part no.         |                |              |            |                   |
|---|------------------|----------------|--------------|------------|-------------------|
|   | Powder cartridge | Standard mould | Handle clamp | Mini mould | Mini handle clamp |
| 16 *  | 65P10            | CS7-4-16       | HCPK4        | CS7-3-16   | HCPK3             |
| 25  | 65P10            | CS7-4-25       | HCPK4        | CS7-3-25   | HCPK3             |
| 35  | 65P10            | CS7-4-35       | HCPK4        | CS7-3-35   | HCPK3             |
| Ø 8   | 90P10            | CS7-4-8SC      | HCPK4        | CS7-3-8SC  | HCPK3             |
| 50  | 90P10            | CS7-4-50       | HCPK4        | CS7-3-50   | HCPK3             |
| Ø 10  | 150P10           | CS7-4-10SC     | HCPK4        | -          | -                 |
| 70  | 150P10           | CS7-4-70       | HCPK4        | -          | -                 |
| 95  | 200P10           | CS7-5-95       | HCPK4        | -          | -                 |
| 120   | 200P10           | CS7-5-120      | HCPK4        | -          | -                 |
| 150   | 250P10           | CS7-5-150      | HCPK4        | -          | -                 |
| 185   | 2 x 150P10       | CS7-9-185      | HCPK4        | -          | -                 |
| 240   | 2 x 150P10       | CS7-9-240      | HCPK4        | -          | -                 |
| 300   | 2 x 200P10       | CS7-10-300     | HCPK5        | -          | -                 |

Special moulds for all FurseWELD products can be manufactured to meet specific customer applications on request

\*1 x S103 Sleeve required when joining conductors 16 mm<sup>2</sup> or smaller