


- 1 PULSANTE DI APERTURA
- 2 PULSANTE DI CHIUSURA
- 3 ALBERO PER LA CARICA MANUALE DELLE MOLLE DI CHIUSURA
- 4 SEGNALE DI CHIUSURA CARICHE (GIALLO) E SCARICHE (BIANCO)
- 5 SEGNALE DI INTERRUPTORE APERTO '0' E CHIUSO '1'
- 6 CONTAMANOVRE (A RICHIESTA)
- 7 BLOCCO A CHIAVE
- 8 SUPPORTO CON RUOTE
- 9 VALVOLA PER CARICA E SCARICA DEL GAS 'SF6'
- 10 SPINA PRESA
- 11 SGANCIATORE DI MASSIMA CORRENTE PR521 (A RICHIESTA)
- 12 SENSORE DI CORRENTE PER SGANCIATORE PR521 (A RICHIESTA)
- 13 ESCLUSORE MECCANICO PER SGANC. DI MIN.TENSIONE (A RICHIESTA)
- 14 PRESSOSTATO CON DUE LIVELLI DI INTERVENTO :
PRESSIONE BASSA E INSUFFICIENTE (APPLIC. LIMITATA
AD ALCUNE TIPOLOGIE)
- 15 'LED' VERDE : PRESSIONE NORMALE
- 16 'LED' GIALLO : PRESSIONE BASSA
- 17 'LED' ROSSO : PRESSIONE INSUFFICIENTE
- 18 Q60 INTERR. TERMOMAGNETICO PROTEZIONE MOTORID. (A RICHIESTA)

- 1 OPENING PUSH-BUTTON
- 2 CLOSING PUSH-BUTTON
- 3 SHAFT FOR MANUAL CLOSING SPRING CHARGING
- 4 SIGNAL FOR CLOSING SPRINGS CHARGED (YELLOW) AND DISCHARGED (WHITE)
- 5 INDICATOR FOR CIRCUIT-BREAKER OPEN '0' AND CLOSED '1'
- 6 OPERATION COUNTER (ON REQUEST)
- 7 KEI LOCK
- 8 SUPPORT WITH WHEELS
- 9 SF6 GAS FILLING AND EXHAUST VALVE
- 10 PLUG AND SOCKET
- 11 PR521 OVERCURRENT RELEASE (ON REQUEST)
- 12 CURRENT SENSOR FOR PR521 (ON REQUEST)
- 13 MECHANICAL OVERRIDER FOR UNDERVOLTAGE RELEASE (ON REQUEST)
- 14 PRESSURE-SWITCH WITH TWO OPERATING LEVELS :
PRESSURE LOW AND INSUFFICIENT (LIMITED APPLIC.
FOR A FEW TYPE ONLY)
- 15 GREEN LED : NORMAL PRESSURE
- 16 YELLOW LED : LOW PRESSURE
- 17 RED LED : INSUFFICIENT PRESSURE
- 18 Q60 GEARED MOTOR THERMOMAGNETIC PROTECTION C.B.

A RICHIESTA:
15+16/15+16+17

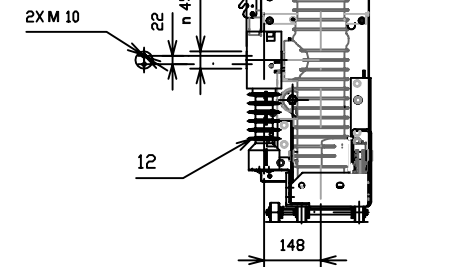

MEDIUM VOLTAGE SF6 CIRCUIT-BREAKER
TYPE 12-17.5-24kV 630-800-1250A



HD4/S

7236