

PRODUCT INFORMATION

# Steel City®

## BS Switch and socket boxes



Since 1904, Steel City products have symbolized the highest quality standards in manufacturing and innovative design, with one of the most complete offerings available.

Now we are manufacturing British Standard (BS) boxes in Saudi Arabia for the Middle East market, continuing our commitment to serve commercial and residential builders with regionally made products wherever possible.


### Features

- Designed and manufactured for mechanical strength using superior materials
- Made of corrosion-resistant pre-galvanized steel sheet
- Folded construction with no welds
- Certified for both surface and flush mounting\*
- Meet British Standards BS4662 2006 for electrical wiring installation of residential, commercial and industrial building construction
- Standard features include brass earth terminals and adjustable lugs to compensate for out-of-square, misaligned mountings
- Available in 0.9 and 1.1 mm steel thickness
- Voltage rating 220-440 VAC 50 to 60 Hz
- NEMA 1: Indoor use
- Positions of knockouts optimised allowing all possible configurations of inputs/outputs
- Patented adjustable lug allows for more space around knockout.\*

\* Features on single-gang boxes only



- 01 Adjustable lug
- 02 Brass earth terminal
- 03 Allows all configurations of inputs/outputs

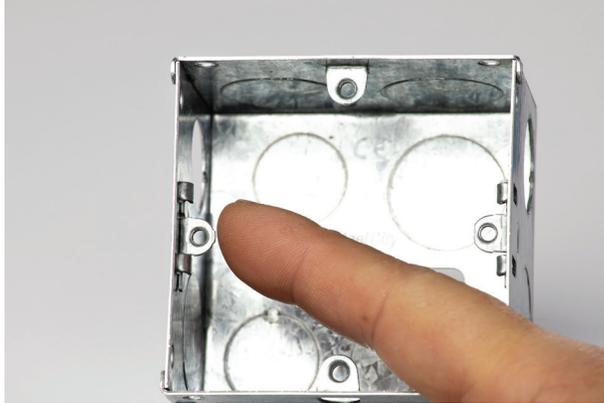

01



02



03

**Steel City BS Switch and socket boxes**

Cat. no.	Gang	Steel thickness (mm)	Dimensions (mm)			Knockouts (mm)		COO	Std. pkg. qty. Inner / outer
			H	W	D	diameter			
SFB135-2	1	0.9	72	72	35	(7) 20.5	(5) 25.5	KSA	0/64
SFB147-2	1	0.9	72	72	47	(7) 20.5	(5) 25.5	KSA	0/48
SFB235	2	0.9	72	132	35	(10) 20.5	(6) 25.5	India	5/50
SFB247	2	0.9	72	132	47	(10) 20.5	(6) 25.5	India	4/40
SFB135-2-11	1	1.1	72	72	35	(7) 20.5	(5) 25.5	KSA	0/64
SFB147-2-11	1	1.1	72	72	47	(7) 20.5	(5) 25.5	KSA	0/48
SFB235-11	2	1.1	72	132	35	(10) 20.5	(6) 25.5	India	5/50
SFB247-11	2	1.1	72	132	47	(10) 20.5	(6) 25.5	India	4/40