


Movion®

Modular & versatile



Hybrid - 22m

- All-in-one escape route lighting and signalisation luminaire for wall and ceiling mount
- Available lenses for escape route lighting and 5 lux illumination of safety equipment
- Light track mountable with 3C adapter included
- Recess kit for flush mounting available

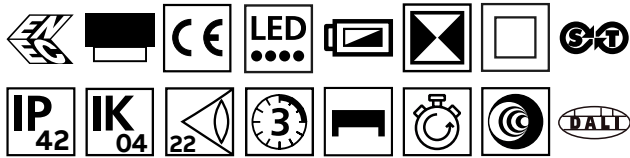

Luminaire

Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
411113111/50	XTH800S-M3/ST 22M	230-240 AC 50/60Hz	1 x LED 2W + 1 x LED 1W	67	5.02 / 4.89	3	5-35	0.6
411113211/50	XTH800S-M3/DALI 22M	230-240 AC 50/60Hz		67	5.02 / 4.89	3	5-35	0.6
411113311/50	XTH800S-M3/COM 22M	230-240 AC 50/60Hz		67	5.02 / 4.89	3	5-35	0.6
411112811/50	XTH800S-230 22M	220-240 AC/DC 0-60Hz		82	4.97 / 4.74	230V	0-40	0.5
411112611/50	XTH800S-230/LTC 22M	220-240 AC 50/60Hz		82	4.97 / 4.74	230V	0-40	0.5

Configurable pictograms included

Legends

Part No.	Pictogram
ISO 7010	
1522251/50	
1522252/50	
1522253/50	
1522258/50	
1522250/50	
1522210/50	
1522211/50	

Part no.	Pictogram
1522214/50	
1522205/50	
1522206/50	
1522204/50	

IP Rating	Product type
IP20*	flush mount from above
IP42*	flush mount from below

Accessories

Order code	Description	Product type
4110001/50	RK XT800	Recess kit for exit signs
4110003/50	PK XT800*	Pendant kit surface mounted exit signs
4110004/50	WB XTH 800	Wall bracket for Hybrid exit signs
4100007/50	RENO XT800**	Renovation kit for exit signs

*Modular pendant tubes and accessories to be used in combination with the pendant kit
 ** Use the RENO XT800 in combination with RK XT800
 See spacing tables on pages 134-138

