


SACE Tmax XT


EF-HR-VR per parte fissa - XT6
EF-HR-VR for fixed part - XT6
EF-HR-VR für festes teil - XT6
EF-HR-VR pour partie fixe - XT6
EF-HR-VR para parte fija - XT6
EF-HR-VR 后接线端子XT6 固定部分

XT6

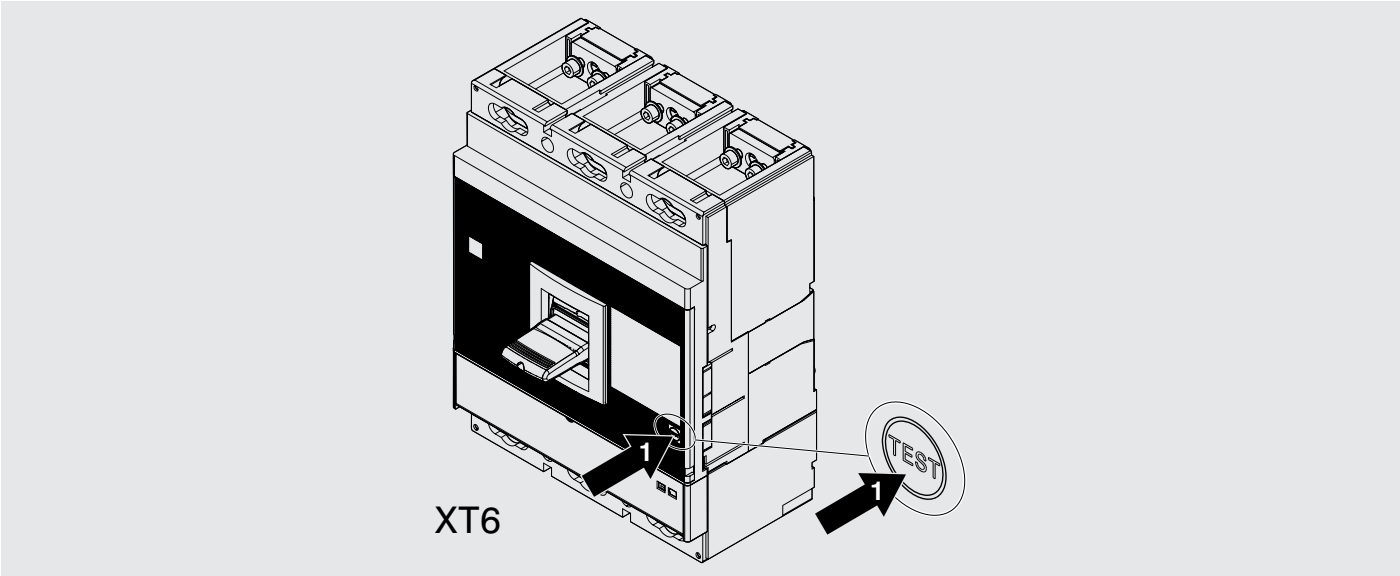


	A	B	C	D	E	F	G	H	I	
					T M5x20	Øint 5,3			2,9x13	
EF	3p	3	/	/	6	12	12	1	2	4
	4p	4	/	/	8	16	16	1	2	6
HR	3p	/	3	/	6	12	12	1	2	4
	4p	/	4	/	8	16	16	1	2	6
VR	3p	/	/	3	6	12	12	1	2	4
	4p	/	/	4	8	16	16	1	2	6

1

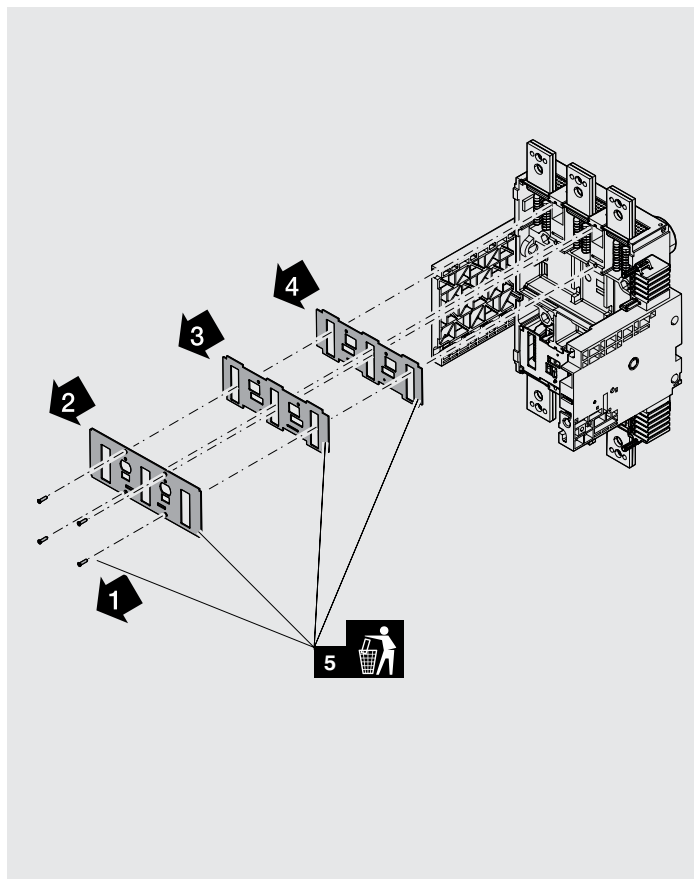


2

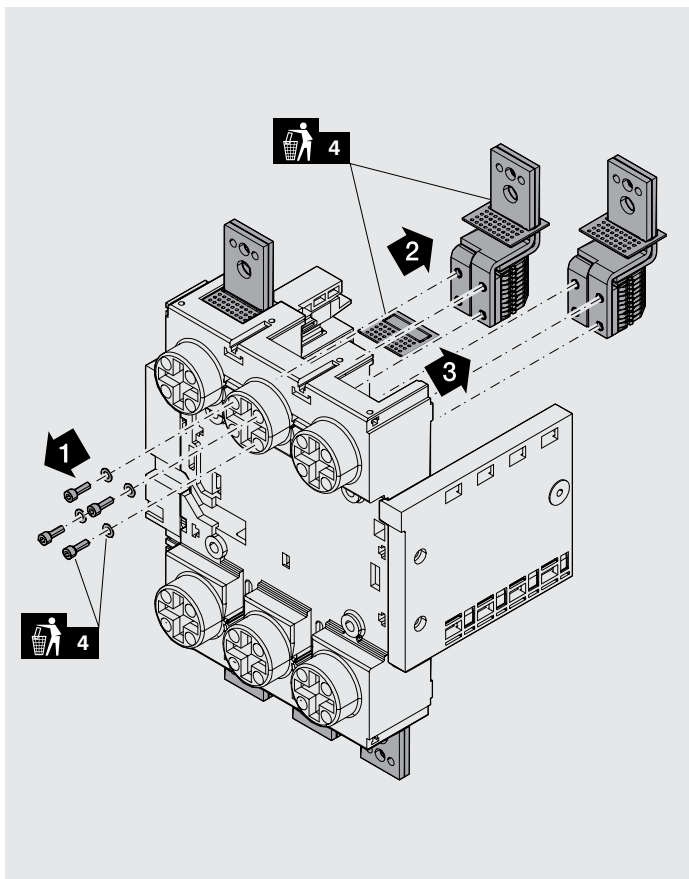


3

Only for EF 4

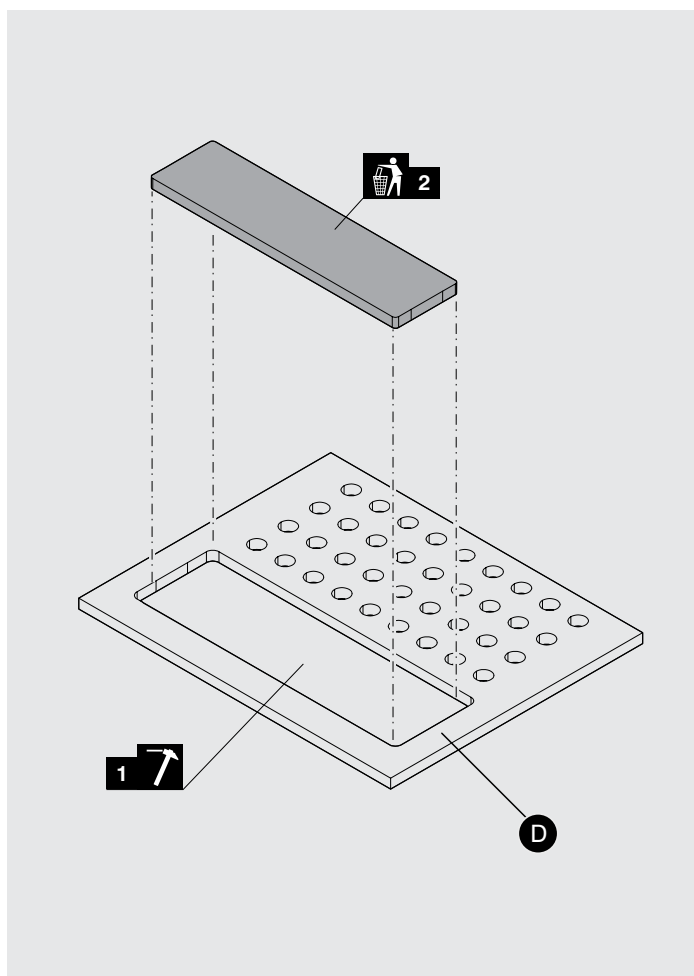


EF

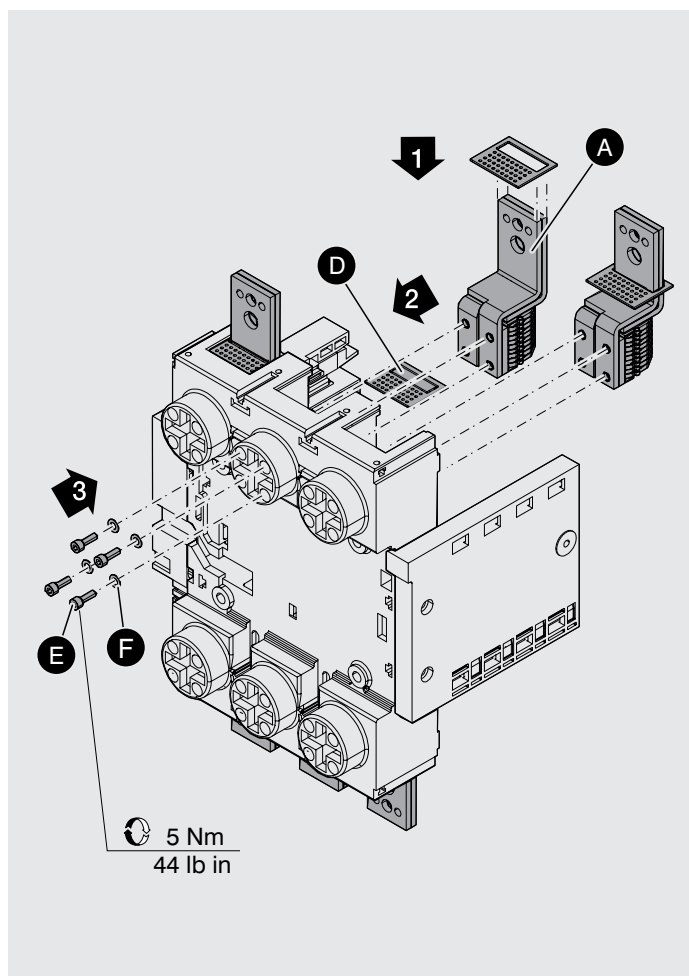


5

HR 6

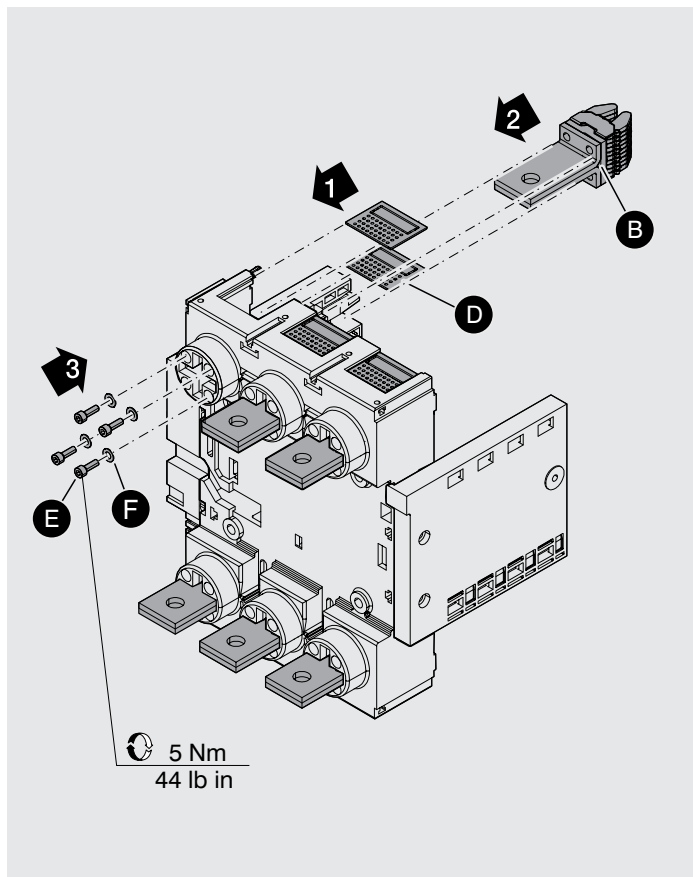






VR

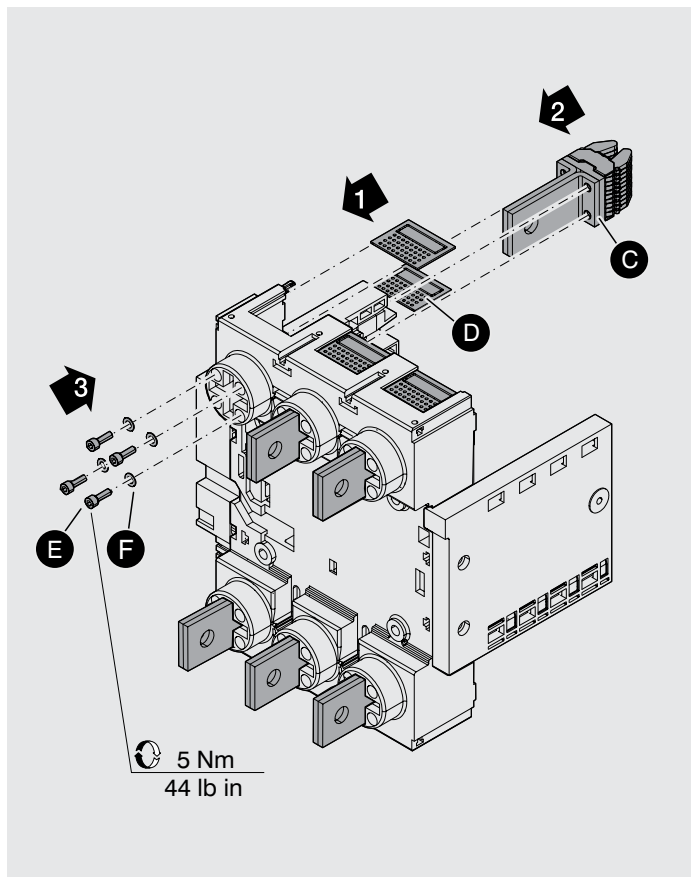

7

Example for EF

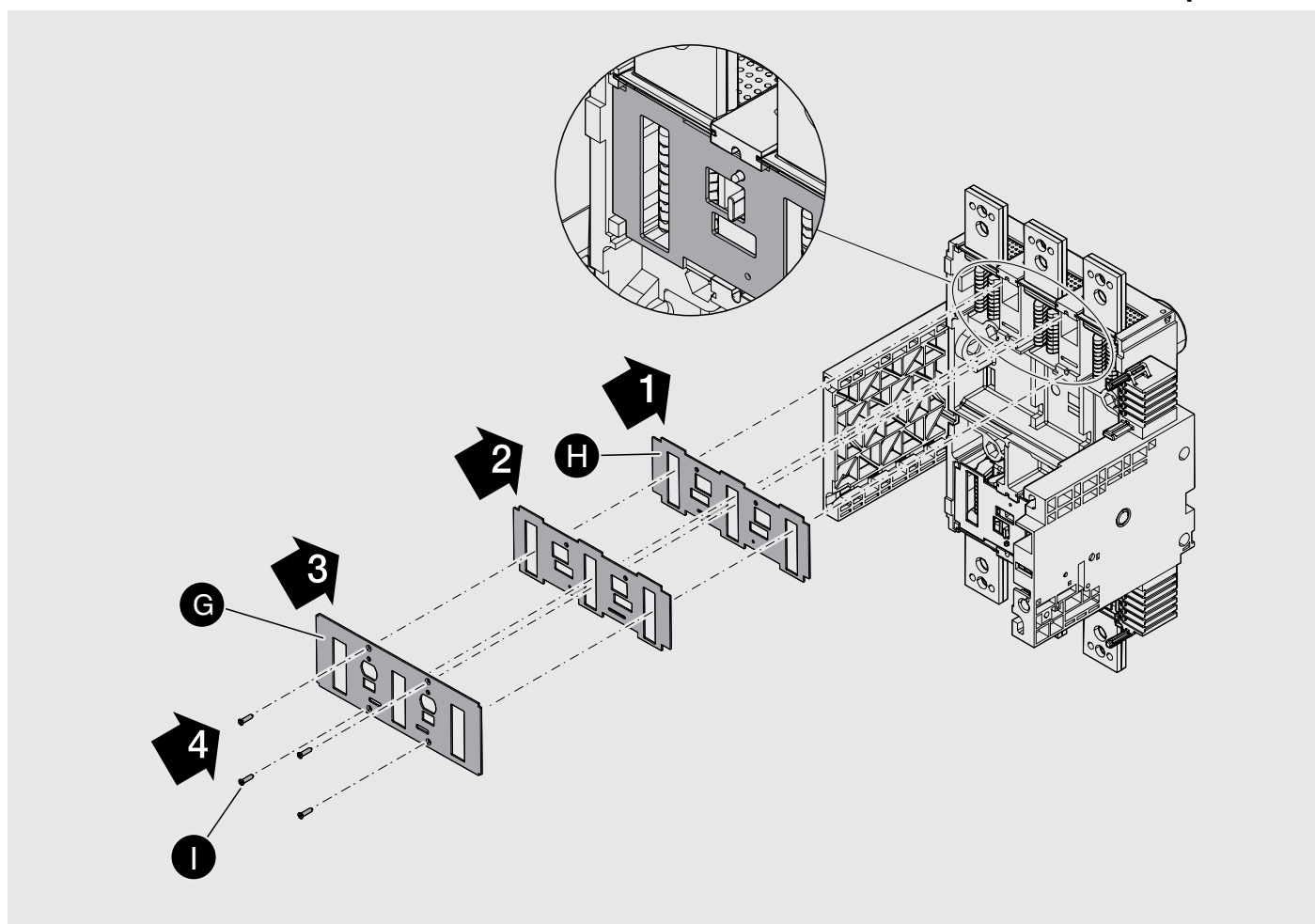

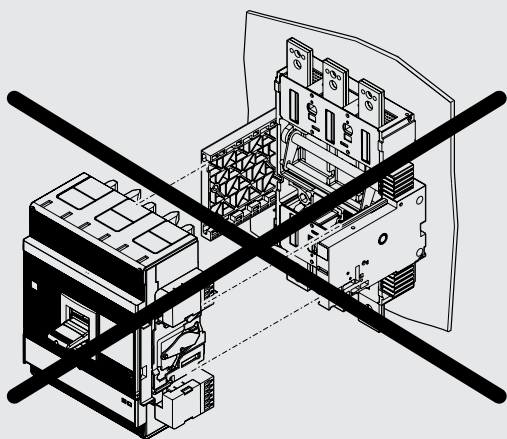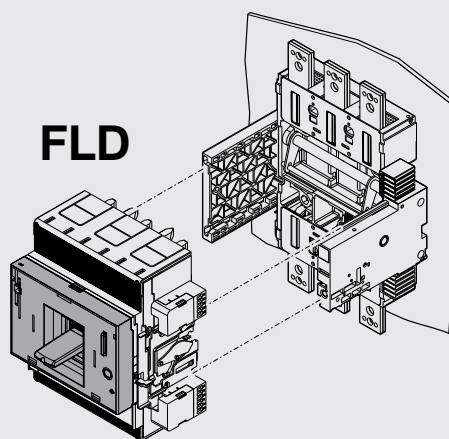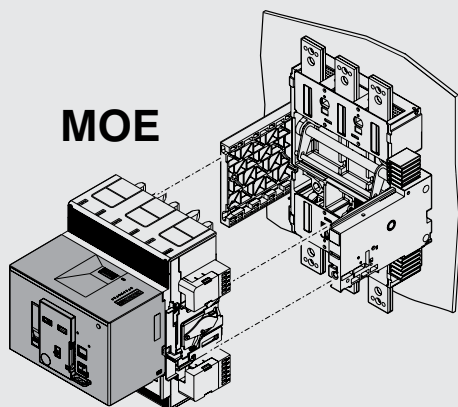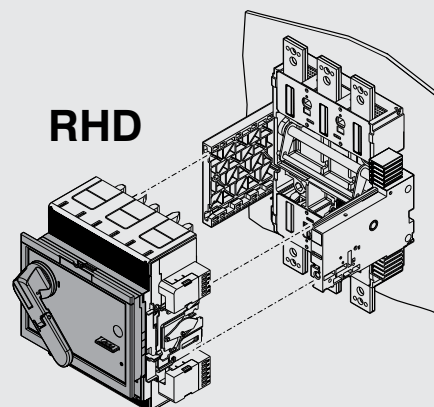**NO!****OK****OK****OK**