

# INFOGRAPHIC | Terra All-in-One UL DC Fast Charger


**CONNECTED** 24/7/365 network with remote monitoring, diagnostics and software updates supporting every new EV model.

**REDUNDANT** power modules for high reliability; delivers up to 920 VDC in all power configurations for the next generation of electric cars, trucks, vans and buses.

**LCD** touchscreen with high brightness and graphical visualization of the charging process.

**SAFETY:** Emergency stop push button can immediately stop charging operation

**HIGH UTILIZATION** with simultaneous charging for 2 electric vehicles – with flexible connector combinations.

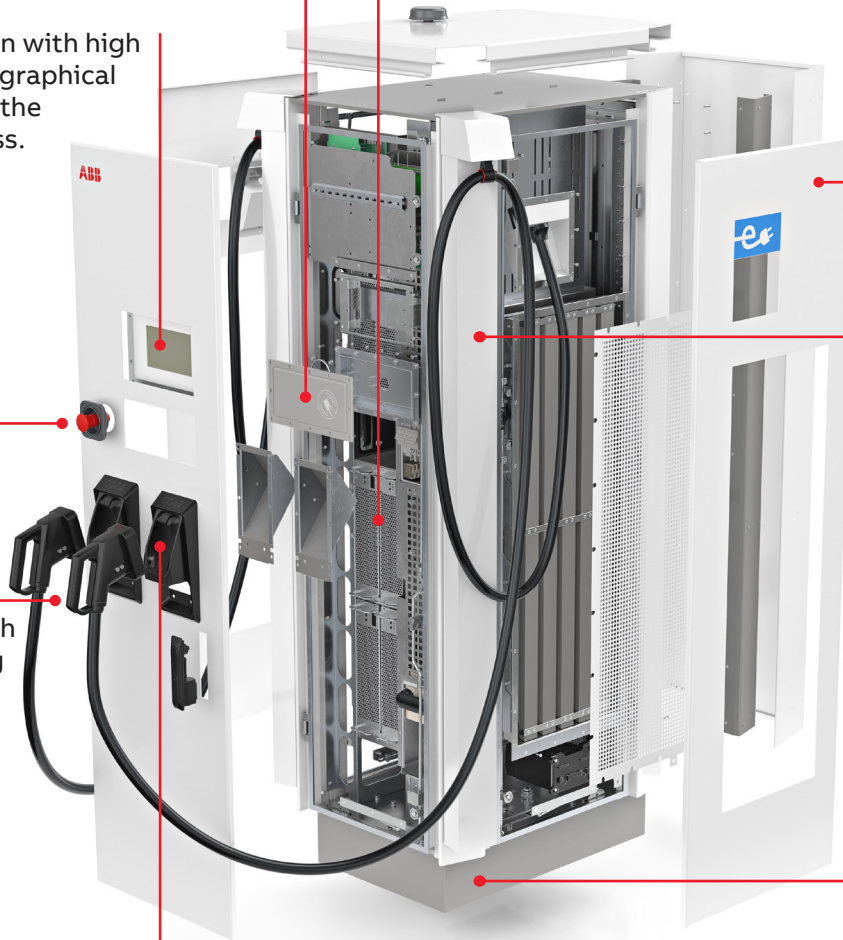

**ROBUST** all-weather, powder-coated stainless steel enclosure

**CONVENIENCE** and hassle-free reach for drivers with retractable cable management option

**EASY** installation and serviceability for fast commissioning, maintenance and field services

**AUTOMATIC** authentication via CCS connector via OCPP and Autocharge functionality; also enables ISO 15118 implementations.

## SPECIFICATIONS

### POWER CONFIGURATIONS

Terra 94: 90 kW on one outlet

Terra 124: 120 kW on one outlet  
or 2 x 60 kW on two outlets

Terra 184: 180 kW on one outlet  
or 2 x 90 kW on two outlets

### MAX CHARGING VOLTAGE

500 VDC CHAdeMO Connector  
920 VDC CCS Connector

### DIMENSIONS & WEIGHT

Height 190 cm / 74.8"

Width 56.5 cm / 22.2"

Depth 88 cm / 34.6"

395 kg / 871 lbs

