

## Contact us

### ABB Oy

Muottitie 2A, 65320  
Vaasa, Finland  
[abb.com/lowvoltage](http://abb.com/lowvoltage)




© Copyright 2025 ABB. All rights reserved.  
Specifications subject to change without notice.

34OT\_PNG\_PEG rev. C / 15CC390190M0201 # 28.02.2025

## OT Plus Additional poles PNG\_PEG\_

**PNG2 - Fixed neutral**  
**PEG2 - Protective earth**  
OT63...100G2-\_BS  
OT63...100G2-\_DS




**PNG3 - Fixed neutral**  
**PEG3 - Protective earth**  
OT30...160G3-\_BS  
OT30...160G3-\_DS

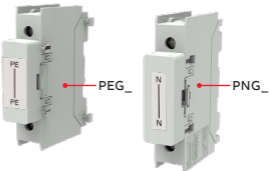


## Install





## Remove

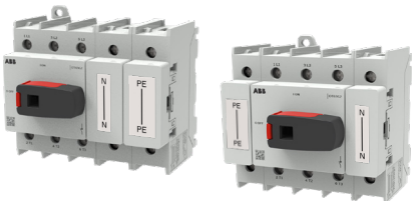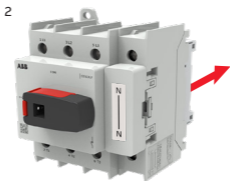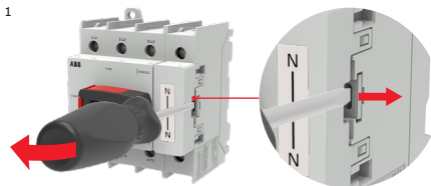

## Install

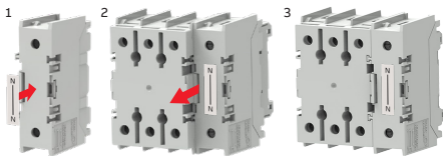

## Remove

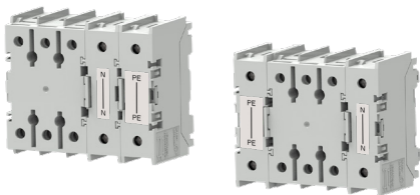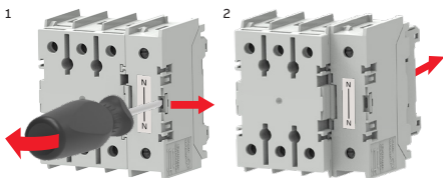

## PNG2, PEG2

Wire type (Cu only)	1 Wire (mm <sup>2</sup> )	2 Wire (mm <sup>2</sup> )	Stripping length	Tightening torque
Class 5-Flexible	1.5-35	1.5-16	13-16 mm 0.51- 0.63 in	POZIDRIV M5 Form 2  2 Nm 18 lb.in
Class 2-Stranded	1.5-35	1.5-16		
Class 6-Very flexible with ferrule	1.5-4	1.5-4		
Class 1-Solid	1.5-6	1.5-6		
UL - CU wire size (AWG)	16-2	16-8		

## PNG3, PEG3

Wire type (Cu only)	1 Wire (mm <sup>2</sup> )	2 Wire (mm <sup>2</sup> )	Stripping length	Tightening torque
Class 5-Flexible	4-70	4-25	16-18 mm 0.63- 0.71 in	Hex 4 mm  6 Nm 53 lb.in
Class 2-Stranded	4-70	4-25		
Class 6-Very flexible with ferrule	2.5-4	2.5-4		
Class 1-Solid	2.5-6	2.5-6		
UL - CU wire size (AWG)	12-2/0			



Warning! Hazardous voltage! Installation by person with electrotechnical expertise only.

