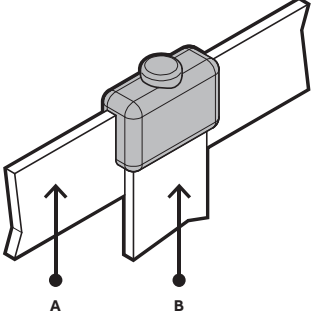


FurseWELD

Bar to bar BB3

Bar to bar BB3 - FurseWELD

	Flat tape conductor size A (mm)	Flat tape conductor size B (mm)	Mould part no.	Order code	Powder cartridge part no.	Handle clamp part no.
	20 x 3	20 x 3	BB3-4-203203	7TCA083910R0194	65P10	HCPK4
	25 x 3	25 x 3	BB3-4-253253	7TCA083910R0196	65P10	HCPK4
	25 x 3	25 x 3	BB3-4-253253-IU	-	65P10	HCPK4
	25 x 4	25 x 4	BB3-4-254254	7TCA083910R0200	90P10	HCPK4
	25 x 6	25 x 6	BB3-4-256256	7TCA083910R0205	150P10	HCPK4
	30 x 3	30 x 3	BB3-4-303303	7TCA083910R0207	90P10	HCPK4
	30 x 4	30 x 4	BB3-4-304304	7TCA083910R0209	115P10	HCPK4
	30 x 5	30 x 5	BB3-4-305305	7TCA083910R0210	115P10	HCPK4
	31 x 6	31 x 6	BB3-4-316316	7TCA083910R0213	200P10	HCPK4
	38 x 5	38 x 5	BB3-4-385385	7TCA083910R0217	150P10	HCPK4
	38 x 6	38 x 6	BB3-4-386386	7TCA083910R0219	200P10	HCPK4
	40 x 3	40 x 3	BB3-4-403403	7TCA083910R0221	115P10	HCPK4
	40 x 4	40 x 4	BB3-4-404404	7TCA083910R0223	150P10	HCPK4
	40 x 5	40 x 5	BB3-4-405405	7TCA083910R0224	150P10	HCPK4
	40 x 6	40 x 6	BB3-4-406406	7TCA083910R0226	200P10	HCPK4
	50 x 3	50 x 3	BB3-4-503503	7TCA083910R0228	200P10	HCPK4
	50 x 4	50 x 4	BB3-4-504504	7TCA083910R0229	200P10	HCPK4
	50 x 5	50 x 5	BB3-4-505505	7TCA083910R0233	200P10	HCPK4
	50 x 6	50 x 6	BB3-4-506506	7TCA083910R0238	250P10	HCPK4

Special moulds for all FurseWELD products can be manufactured to meet specific customer applications on request

For order codes of powder cartridges and handle clamps, see pages 49-50

FurseWELD moulds should only be used with FurseWELD powders, handle clamps and accessories. If moulds, powders, handle clamps and accessories from other manufacturers are utilized, we cannot guarantee the safe use or the integrity of the completed joint

Conductors must be installed in the orientation shown to achieve the correct connection