


# Guideway

Innovative & stylish



### Guideway 32m - Recessed

- Bright and uniformed light distribution with 500 cd/sq.m
- Versatile mounting options with First-Fix control gear
- Unique frameless legend design with click-lock assembly
- Quick release legend panels

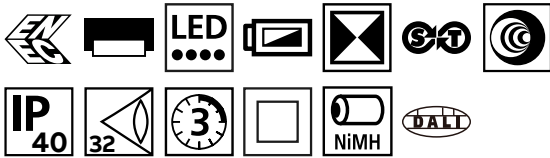

### Luminaire

Order code	Description	Input voltage	Lamp type	Power Operation		Environment temp. (°C)	Weight (kg)	Including	
				consumption (VA/W)	duration (hrs)				
CTEGR3LS1-S32	REC LED SIGN M3 CT-TST 32M	220-240 AC 50Hz	1 x LED 4W	7.1 / 6.5	3	5-35	1.5		
EGR1LS1D-S32	REC LED SIGN SLAVE 230DIM 32M	220-240 AC/DC 0-60Hz		230V		0-35	1.5		
EGR1LS1LTC-S32	REC LED SIGN SLAVE LTC 230 VAC 32M	220-240 AC 50/60Hz		230V		0-35	1.5		
EGR1LS1-S32	REC LED SIGN SLAVE 230 VAC 32M	220-240 AC/DC 0-60Hz		230V		0-35	1.5		
EGR3LS1-S32	REC LED SIGN M3 32M	220-240 AC 50Hz				3	5-35	1.5	
DAEGR3LS1-S32	REC LED SIGN M3 32M DALI	220-240 AC 50Hz				3	5-35	1.5	

60 hrs charge at first commissioning, 24 hrs re-charge thereafter  
 Black versions available on request  
 Add '-00' for product without legends

### Single sided

Part No.	Legends
<b>ISO 7010 legend format</b>	
XEN2EG32	
XEN3EG32	
XEN6EG32	
XEN5EG32	
XEN0G32	
<b>Arabic legend format</b>	
XBN1EG32	

ISO 7010 pictogram legends are shown.  
 Euro format & Special legends are available to order see pages 138-141.

### Accessories

Order code	Description	Colour
EG-T4SG	Alu Cover discs, 2+2 self contained	
EG-T4VG	Alu Cover discs, 2+2 slave	

### Suspension kit accessories

Order code	Description
EG-TKIT50	Pendant 500
EG-TKIT100	Pendant 1000
EG-WKIT150	Wire suspension kit

### Flag mounted

Part No.	Legends
<b>ISO 7010 legend format</b>	
XEN602EG32	
XEN603EG32	
XEN606EG32	
XEN605EG32	

