


On-load tap-changer type UBBD, 25 tap positions, coarse/fine-switching.
 Max effective No. of turns in pos 1.
 The tap-changer is delivered set in pos 13, the preceding pos. was 13A.

Lindningskopplare typ UBBD, 25 lägen, grov/fin-koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 13, föregående läge var 13A.

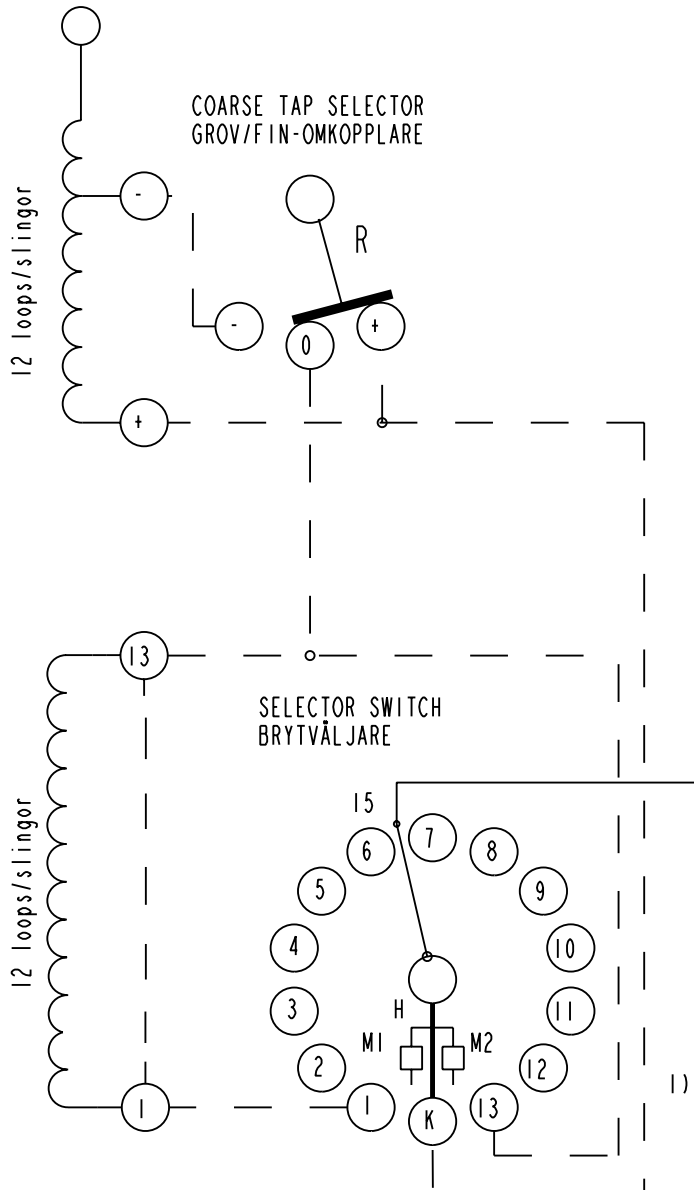

H Main contact
Huvudkontakt

M1, M2 Transition contacts
Motståndskontakter

Pos Läge	R connects förbinder	H connects förbinder
1		1 - 15
2		2 - 15
3		3 - 15
4		4 - 15
5		5 - 15
6		6 - 15
7	0+	7 - 15
8		8 - 15
9		9 - 15
10		10 - 15
11		11 - 15
12		12 - 15
13A		13 - 15
13		K - 15
13B		1 - 15
14		2 - 15
15		3 - 15
16	0-	4 - 15
17		5 - 15
18		6 - 15
19		7 - 15
20		8 - 15
21		9 - 15
22		10 - 15
23		11 - 15
24		12 - 15
25		13 - 15

1) OUTPUT TERMINAL
STRÖMAVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Dashed lines show in delivery not included leads belonging to cleats and leads.

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktsutförande. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19

Sheet	Cont	Year	Week	Appd	Year	Week
Rev Ind	Revision					
Accepted by qual control R. Yngvesson		Accepted for prod by		Description (English) CONNECTION DIAGRAM UBBD		DATA ORIGINAL
Design checked by B-O. Stenestam		Drawn by L. Bergman		Description (own language) KOPPLINGSSCHEMA UBBD		File name 0389-10
Drawing checked by M. Hedlund		Issued by Dept COM/TKO 97 32				Lang Sheet 1
		Asea Brown Boveri		5492 0389-10		Rev Ind Cont -