


ASENNUSOHJE
INSTALLATIONSANVISNING
INSTALLASJONSANVISNING
INSTALLATION INSTRUCTION
UZSTĀDĪŠANAS INSTRUKCIJA
INSTALIAVIMOINSTRUKCIJA
РУКОВОДСТВО ПО МОНТАЖУ
INSTRUKCJA INSTALACJI
PAIGALDUSJUHEND




ABB

FIM 1200

HÄLYTIN
SIGNALLAMPA MED SUMMER
ALARM
ALARM UNIT
SIGNALINIS BLOKAS
TRAUKSMES VIENĪBA
СИГНАЛИЗАТОР
BUCZEK Z LAMPKĄ
SIGNAALSEDE

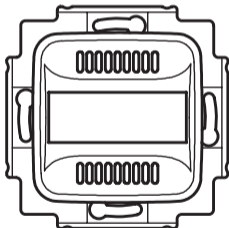


Käyttöjännite; Driftsspänning; Driftspenning; Operating voltage; Darbinė įtampa; Darba spriegums; Рабочее напряжение; Napięcie pracy; Toitepinge	9,5 - 28 Vac / 9,5 - 35 Vdc
Virrankulutus; Strömförbrukning; Strømfor- bruk; Current consumption; Srovės sąnaudos; Strāvas patēriņš; Потребляемый ток; Pobór prądu; Voolutarve	60 mA ac / 30 mA dc
Ääni; Ljud; Lyd; Sound; Skaņa; Garsas; Skaņa; Звук; Sygnał dźwiękowy; Hääl	2,3 kHz 78 dB / 30 cm
Kotelointiluokka; Kapslingsklass; Tetthets- klasse; Protection class; Saugumo klasė; Aizsardzības klase; Класс защиты; Stopień ochrony; Kaitseaste	IP20
Käyttölämpötila; Drifttemperatur; Drift- temperatur; Operating temperature; Darbinė temperatūra; Darba temperatūra; Диапазон рабочих температур; Temperatura pracy; Kasutustemperatuur	5 °C - 40 °C

  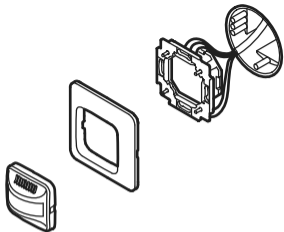

J1

J3

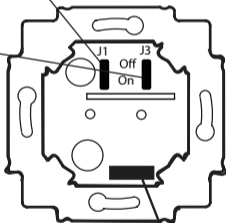

Off



Buzzer



 
LED




On



Buzzer



LED

 

NC NC

1	2	3	4
---	---	---	---

24 V ac/dc

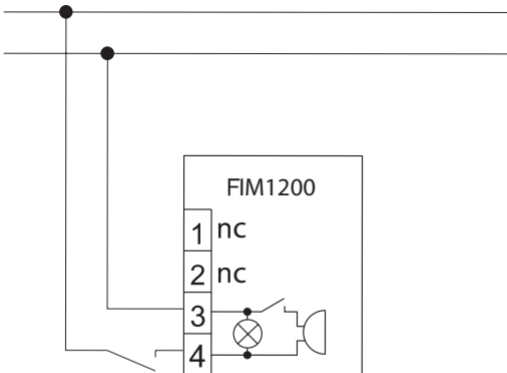


ABB Oy, Asennustuotteet
P.O. Box 16
FIN-06101 PORVOO
FINLAND

INT.TEL. + 358 102211
INT.FAX. + 358 102254255
www.abb.fi/asennustuotteet

