


Movion®

Modular & versatile



Escape route lighting - Recessed

- Round shaped design fitting any ceiling
- Specially designed lens for optimal light distribution - long and wide beam
- Quick installation and parallel wiring option with the smart loop-in, loop-out system

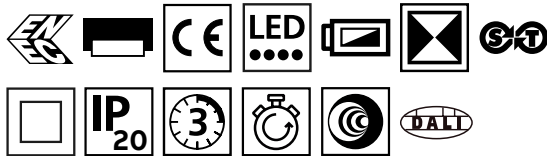

Luminaire

Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Light optics	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
511013121/50	EL800R-M3/ST ER	230-240 AC 50/60Hz	1 x LED 1W	101	Escape route	3.33 / 3.19	3	5-35	0.31
511013221/50	EL800R-M3/DALI ER	230-240 AC 50/60Hz		101		3.33 / 3.19	3	5-35	0.31
511013321/50	EL800R-M3/COM ER	230-240 AC 50/60Hz		101		3.33 / 3.19	3	5-35	0.31
511012821/50	EL800R-230 ER	220-240 AC/DC 0-60Hz		124		3.21 / 3.05	230V	0-40	0.21
511012621/50	EL800R-230/LTC ER	220-240 AC 50/60Hz		124		3.21 / 3.05	230V	0-40	0.21
511013122/50	EL800R-M3/ST OA	230-240 AC 50/60Hz		109	Open area	3.33 / 3.19	3	5-35	0.31
511013222/50	EL800R-M3/DALI OA	220-240 AC 50/60Hz		109		3.33 / 3.19	3	5-35	0.31
511013322/50	EL800R-M3/COM OA	230-240 AC 50/60Hz		109		3.33 / 3.19	3	5-35	0.31
511012822/50	EL800R-230 OA	220-240 AC/DC 0-60Hz		134		3.21 / 3.05	230V	0-40	0.21
511012622/50	EL800R-230/LTC OA	220-240 AC 50/60Hz		134		3.21 / 3.05	230V	0-40	0.21

Accessories

Order code	Description	Product type
11160111/50	RENO 2200-3300	Renovation kit for recess mounted, white escape route lighting

See spacing tables on pages 134-138

IP Rating	Product type
IP20	flush mount from above
IP42	flush mount from below

