


## Silver-Scape

Practical & everyday

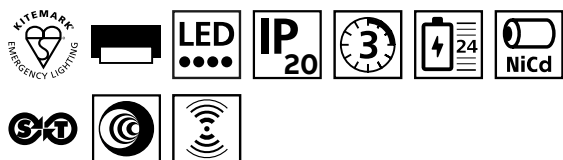


### Recessed emergency luminaire

- Suitable for application in suspended ceilings
- Polycarbonate enclosure with wing fixings for recessed application
- Optically engineered diffuser
- Complies to IEC 60598.2.22

### Recessed unit


Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / Environment duration (hrs) temp. (°C)	Weight (kg)
CTRRB3LS1X	RECS D B/HEAD 2W M3 LED WHT CT	220-240 AC 50/60Hz	1 x LED	241	6.1 / 3.9	3 0-30	1.09
IR2RRB3LS1X	RECS D B/HEAD 2W M3 LED WHT IR2	220-240 AC 50/60Hz	2W		6.1 / 3.9	3 0-30	1.09
LTCRRB1LS1X	LED 2W LTC SILVERSCAPE RECESS	220-240 AC 50/60Hz			4.6 / 4.4	230V 0-40	0.9
RB8LS1X	LED 2W 50V ACDC SILVERSCAPE RECESS	24-50 AC/DC 0-60Hz			3.4 / 2.1	Central Battery 0-40	0.79
RRB1LS1X	LED 2W HF SILVERSCAPE RECESS	110-230 AC/DC 0-60Hz			3.4 / 3.2	230V 0-40	0.81
STRRB3LS1X	RECS D B/HEAD 2W M3 LED WHT SLFTST	220-240 AC 50/60Hz			6.1 / 3.9	3 0-30	1.09

Slave versions available with LTC  
Order recess unit and diffuser panel separately

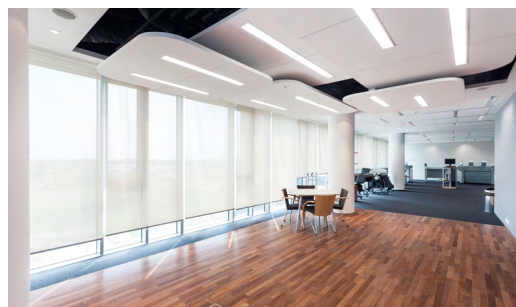

### Accessories

Order code	Description
RB00	Recessed diffuser panel
RB011	Rb metal diffuser trim - white
RB041	Rb metal diffuser diff trim - gold/brass
RB051	Rb metal diffuser diff trim - stainless steel
RB061	Rb metal diffuser diff trim - silver

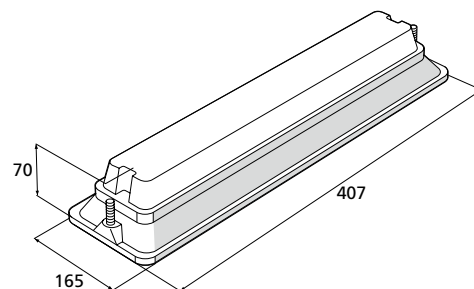

Cable entry via 20 mm knockouts on rear of unit.  
Ceiling cutout 380 mm x 136 mm.