

产品认证证书

II型自愿认证

证书编号: CQC2020010304294316

发证日期: 2021年10月14日

有效期至: 2031年10月14日

委托人名称 ABB France
及注册地址 11 Rue d' Arsonval 69680, Chassieu, FRANCE

制造商名称 ABB France
及注册地址 11 Rue d' Arsonval 69680, Chassieu, FRANCE

生产企业名称 ABB 新会低压开关有限公司
及生产地址 广东省江门市新会区今古洲工业开发区

产品名称和系列、规格、型号 接触器
AF*26**-30-**-*; AF*30**-30-**-*; AF*38**-30-**-*; 规格参数详见附件

产品标准和技术要求 GB/T 14048.4-2020

认证模式 产品型式试验+初次工厂检查+获证后监督

上述产品符合 CQC12-000001-2020 认证规则的要求, 特发此证。

本证书为变更证书, 证书首次颁发日期: 2020年08月14日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

可通过扫描下方二维码或登录国家认监委网站 (www.cnca.gov.cn) 查验证书信息



授权签字人

签发

刘江

谢肇煦

中国质量认证中心



<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

C(2) 0096438

CERTIFICATE OF PRODUCT CERTIFICATION

TYPE II CQC CERTIFICATION

CERTIFICATE NO.: CQC2020010304294316

Valid from: Oct.14,2021

Valid until: Oct.14,2031

NAME AND REGISTERED ADDRESS OF THE APPLICANT ABB France
11 Rue d' Arsonval 69680, Chassieu, FRANCE

NAME AND REGISTERED ADDRESS OF THE MANUFACTURER ABB France
11 Rue d' Arsonval 69680, Chassieu, FRANCE

NAME AND LOCATION OF THE FACTORY ABB Xinhui Low Voltage Switchgear Co.,Ltd.
Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China

PRODUCT NAME, MODEL AND SPECIFICATION Contactor
AF*26**-30-**-*; AF*30**-30-**-*; AF*38**-30-**-*; See the Appendix

THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS GB/T 14048.4-2020

TYPE OF CERTIFICATION SCHEMES Type Testing of Product + Initial Factory Inspection + Follow up Factory Inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC12-000001-2020.

Date of original issued: Aug.14,2020

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

The certificate information is available through the QR code below or CNCA's website: www.cnca.gov.cn



SIGN BY

刘江

SIGNATURE

谢肇熙

CHINA QUALITY CERTIFICATION CENTRE



<http://www.cqc.com.cn>

Section 9, No.188, Nansihuan Xilu, Beijing 100070 P.R.China

Tel: +86 10 83886666

C(2) 0096438

产品认证证书

II型自愿认证

证书编号: CQC2020010304294316

第 1 页 共 4 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 96438

上报参数:

AF*26**-30**-*, AF*30**-30**-*, AF*38**-30**-*

Uimp: 6kV;

Ui: 690V;

Ith: 55A(4P), 50A(3P);

AF*26(3P):

AC-1:Ue/Ie:690V/45A;

AC-3, AC-3e:Ue/Ie:220-230-240V/26A, 380-400V/26A, 415V/26A, 440V/26A, 500V/23A,
690V/17A, 400V/30A;

AC-8a:Ue/Ie:400V/30A;

AF*30(3P):

AC-1:Ue/Ie:690V/50A;

AC-3, AC-3e:Ue/Ie:220-230-240V/33A, 380-400V/32A, 415V/32A, 440V/32A,
500V/28A, 690V/21A;

AC-8a:Ue/Ie:400V/40A;

AF*38(3P):

AC-1:Ue/Ie:690V/50A;

AC-3, AC-3e:Ue/Ie:220-230-240V/40A, 380-400V/38A, 415V/38A,
440V/38A, 500V/33A, 690V/24A;

AC-8a:Ue/Ie:400V/50A;

AF*26(4P):

AC-1:Ue/Ie:690V/45A;

AF*38(4P):

AC-1:Ue/Ie:690V/55A;

使用类别: AC-1, AC-3, AC-3e, AC-8a;

极数: 3P, 4P(AFC26, AFC38);

Us:

AF:

NP 常规功耗:

24-60V 50/60Hz/20-60V DC, 48-130V 50/60Hz/DC,



中国质量认证中心



产品认证证书

II型自愿认证

证书编号: CQC2020010304294316

第 2 页 共 4 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 96438

100-250V 50/60Hz/DC, 250-500V 50/60Hz/DC;

LP 低功耗:


12-20V DC, 20-60V 50/60Hz/24-60V DC, 48-130V 50/60Hz/DC, 100-250V 50/60Hz/DC;

AFC:

220-230V 50Hz/230-240V 60Hz, 24V 50/60Hz, 110V 50Hz/110-120V 60Hz,

230-240V 50Hz/240-260V 60Hz;

IP20

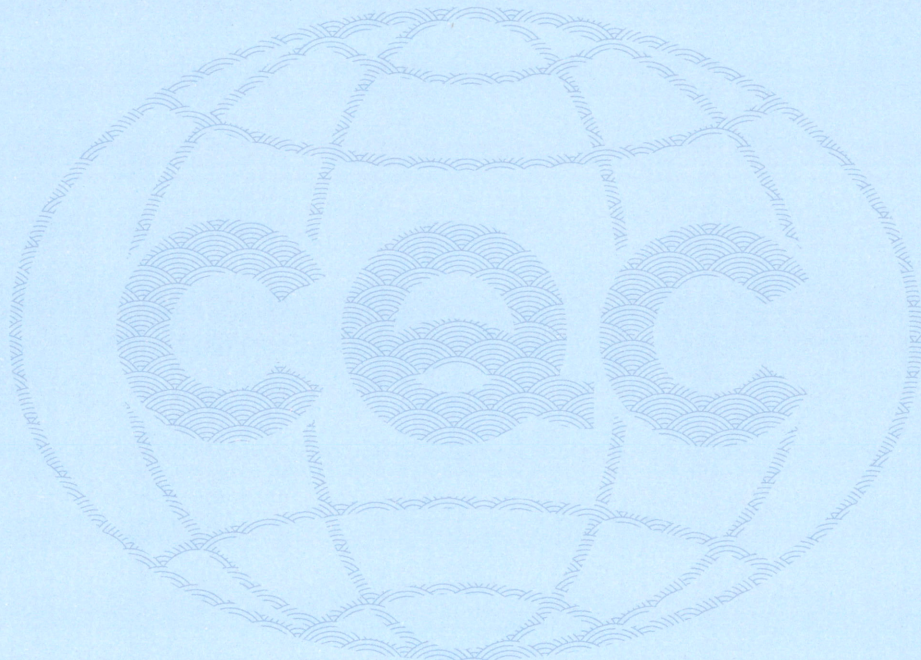

中国质量认证中心



产品认证证书

II型自愿认证

证书编号: CQC2020010304294316

第3页 共4页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 96438

型号解释:

AF C 26 Z B - 30 - 00 RT - 21
1 2 3 4 5 6 7 8 9

1 = 系列名称; Main designation: AF

2 = 产品类型

空白: contactor with electronically controlled electromagnet, 电子控制电磁铁接触器

C: contactor with conventional electromagnet, 常规电磁铁接触器

3 = 400V, AC-3(e)应用类别下, 额定工作电流; range size 26: 26A; 30: 32A; 38: 38A

4 = 线圈类型 Coil type

空白: 线圈常规功耗 Blank: Normal power coil (NP), 电压代号为 11/12/13/14/80/81/84/88

Z 线圈低功耗; Z: Low power coil (LP), 电压代号为 20/21/22/23 (ZB 和 ZB RT 只适用代号 21/22/23)

5 = 产品应用类型 application type

空白: 工业用途; Blank: Industrial

B: 轨道交通; B: railway/rolling stock

6 = 主触点对数

30: 3 对常开主触点, 0 对常闭主触点

22: 2 对常开主触点, 2 对常闭主触点; (AFC26/AFC38 适用)

40: 4 对常开主触点, 0 对常闭主触点; (AFC26/AFC38 适用)

7 = 辅助触点对数

00: 0 对辅助触点; no auxiliary pole provided

8 = 接线方式: Connection type

空白=螺钉接线; Blank=Screw type connection



中国质量认证中心



产品认证证书

II型自愿认证

证书编号: CQC2020010304294316

第 4 页 共 4 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 96438

RT= 环形垫片螺钉接线; RT=Ring Tongue connection

K=插入式端子; push in terminal (仅适用于 AFC 3P 产品)

9 = 控制线圈代号 coil code AF 系列见表 4, table4 , AFC 系列 表 4b , table 4b

表 4 table4

额定工作电压 Rated voltage (V)		线圈代号
DC	AC 50/60Hz	Code
20-60	24-60	11
48-130	48-130	12
100-250	100-250	13
250-500	250-500	14
12-20	/	20
20-60	24-60	21
48-130	48-130	22
100-250	100-250	23

表 4b Table 4b

Control Voltage 控制电压	Coil code 线圈代号
220-230V 50Hz / 230-240V 60HZ	80
24V 50Hz / 60HZ	81
110V 50Hz / 110-120V 60HZ	84
230-240V 50Hz / 240-260V 60HZ	88



中国质量认证中心

